

- Replacement for up to 15W halogen bulbs
- Up to 82% energy saving
- Lifetime of 25,000 hrs



Order Code 52144

General Data

Lamp Socket G4

Design

Geometric Data

Length (mm) 41

Diameter (mm) 35

Weight (g) 18

Electric Data

Wattage (W) 2

Wattage Equivalent (W) Up to 15W

Voltage (V) 12V DC/AC

Power Factor >0.65

Operating Frequency (Hz) 50-60

Photometric Data

Luminous Flux (lm) 90

Luminous Flux 90° cone (lm) tbd

CRI ≥ 80

CCT (K) 2700

Luminous Intensity (cd) 200

Beam Angle (°) 35


Lifespan

Lifetime (hrs) 25,000

Switching Cycle 40,000

Dimmability No

Energy Efficiency Class A+

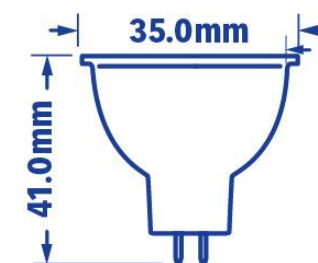



Order Code 52144

Product Description LED MR11 GU4 2.0W 2700K WW 90LM 35DEG

Technical Packaging Details

Barcode	023942521440
EAN 128	(02)00023942521440(37)06(91)14
EAN 14	50023942521445
Pack Dimensions (HxWxL)	90 x 135 x 36
Pack Weight	TBC
Carton Qty (Shipping Unit)	6
Carton Dimensions (HxWxL)	145*110*188
Cartons/Pallet	198
Layers/Pallet	6
Units/Pallet	1188

Photometric Diagram

52144

