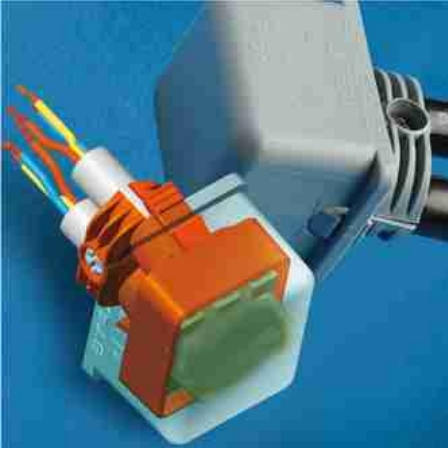


5633/6///86

Minature Paguro gel connector junction box grey, 2 cable entry 8-10mm with 4 pole terminal block


PRODUCT SPECIFICATIONS

Minimum cable diameter (mm)	8
Maximum cable diameter (mm)	10
Gel material	Sealing bi-component syliconic gel
Fixing system	Cable
Cable entries	2
Number of poles	4
Terminal type	Screw - wp
Body material	Nylon PA66-RV
Colour	Grey
Max conductor size (Sq mm)	2.5
Max current (A)	16
Max voltage (V)	250
Minimum temp rating °C	-30
Max temp rating °C	130
IP rating	68