

**PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION**

**Part Number:** [90059-0007](#)  
**Status:** **Active**  
**Overview:** C-Grid III™  
**Description:** 2.54mm Pitch C-Grid® Micro Shunt, Low Profile, 5.08µm Tin (Sn) Plating

**Documents:**

[3D Model](#) [Product Specification PS-90059 \(PDF\)](#)  
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

**Agency Certification**

CSA LR19980  
 UL E29179

**General**

Product Family Accessories  
 Series [90059](#)  
 Component Type Shunt  
 Overview [C-Grid III™](#)  
 Product Name C-Grid®, C-Grid III™, SL™  
 UPC 800753722040

**Physical**

Circuits (Loaded) 2  
 Color - Resin Black  
 Flammability 94V-0  
 Gender Female  
 Lock to Mating Part None  
 Material - Metal Phosphor Bronze  
 Material - Plating Mating Tin  
 Material - Plating Termination Tin  
 Material - Resin Polyester  
 Net Weight 1.136/g  
 Number of Rows 1  
 Packaging Type Bag  
 Plating min - Mating 5.080µm  
 Plating min - Termination 5.080µm  
 Temperature Range - Operating -55°C to +125°C  
 Termination Interface: Style Surface Mount


**Electrical**

Current - Maximum per Contact 1.5A

**Material Info**

**Reference - Drawing Numbers**

Product Specification PS-90059, RPS-90059-002  
 Sales Drawing SDA-90059

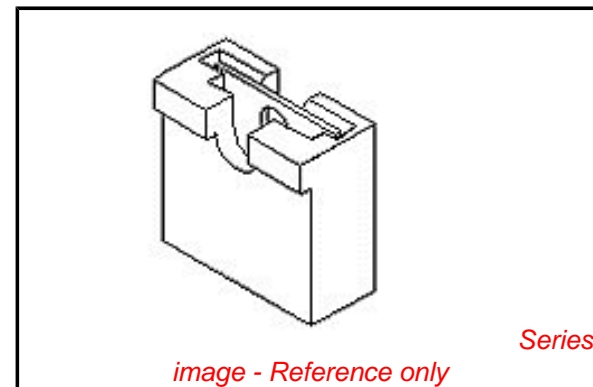

**EU RoHS**

**ELV and RoHS  
 Compliant**  
**REACH SVHC  
 Contains SVHC: No**  
**Low-Halogen Status  
 Not Low-Halogen**

**China RoHS**



**Need more information on product  
 environmental compliance?**

Email [productcompliance@molex.com](mailto:productcompliance@molex.com)  
 For a multiple part number RoHS Certificate of  
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any  
 non-product compliance questions.

**Search Parts in this Series**

[90059Series](#)

**Use With**

(0.64)/.025 square and round pins