

Fibox EURONORD

EURONORD range is designed to house DIN-rail mounted terminal blocks and various types of sensors. EURONORD enclosures are available in polycarbonate, ABS, polyester and aluminium. There are more than 160 different off-the-shelf versions available.



EURONORD



Quicklock



Ideal for housing terminals



RoHS compliant and
halogen-free

EURONORD

PC/ABS 0505


52 x 50 PC: IP 66/IP 67, IK 07/IK 08
 ABS: IP 66/IP 67, IK 07



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
PC 050504	7032500	52 x 50 x 40	Enclosure, PC • Grey cover
AB 050504	7083500	52 x 50 x 40	Enclosure, ABS • Grey cover

Accessories			
Order symbol	Code	Dimensions	Description
TM 0505	9512009	26 x 44	Mounting plate
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

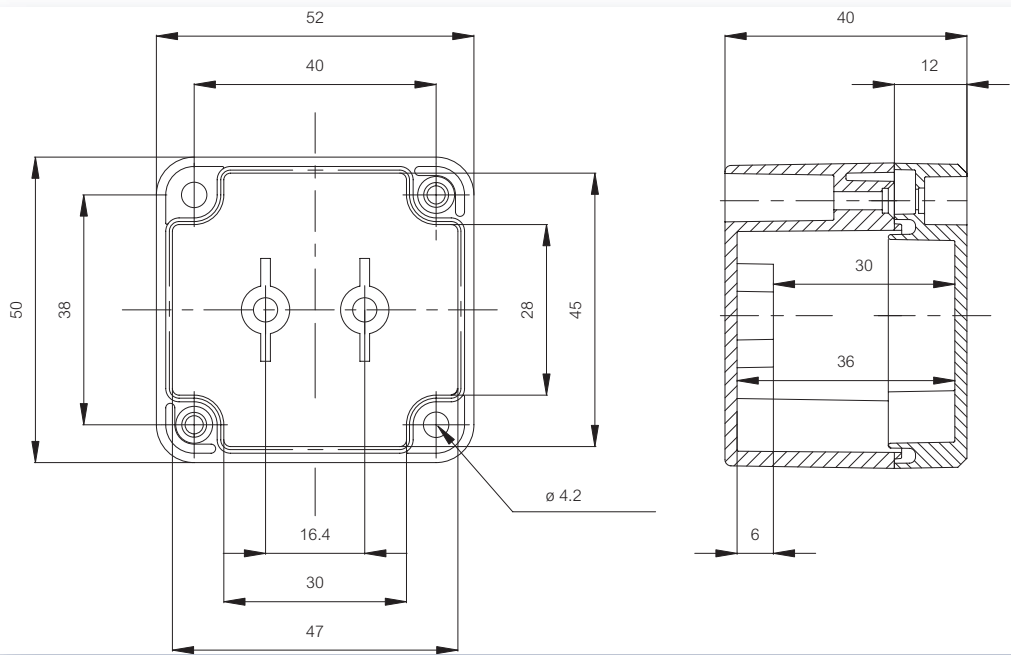



EURONORD PC/ABS 0507

65 x 50

PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 050705	7032520	65 x 50 x 45	Enclosure, PC • Grey cover
PCT 050705	7022521	65 x 50 x 45	Enclosure, PC • Transparent cover
AB 050705	7083520	65 x 50 x 45	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 0505	9512009	26 x 44	Mounting plate
TM 0507	9512010	26 x 57	Mounting plate
TRM 0507	9820001	15 x 48	DIN-15 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

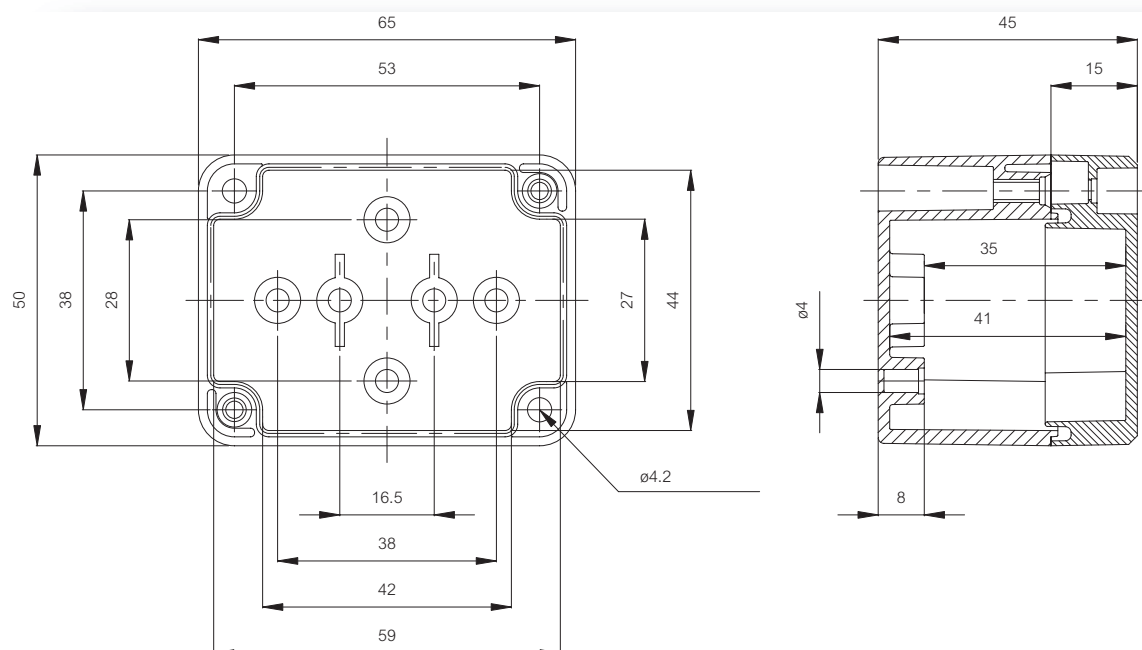

EURONORD

PC/ABS 0710


98 x 66 PC: IP 66/IP 67, IK 07/IK 08
 ABS: IP 66/IP 67, IK 07

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.



Enclosures			
Order symbol	Code	Dimensions	Description
PC 071004	7032530	98 x 66 x 41	Enclosure, PC ▪ Grey cover
PCT 071004	7022531	98 x 66 x 41	Enclosure, PC ▪ Transparent cover
PCQ 071004	7033531	98 x 66 x 41	Enclosure, PC, IP 65 ▪ Grey cover (quick-locking)
PCTQ 071004	7022530	98 x 66 x 41	Enclosure, PC, IP 65 ▪ Transparent cover (quick-locking)
AB 071004	7083530	98 x 66 x 41	Enclosure, ABS ▪ Grey cover
ABQ 071004	7083531	98 x 66 x 41	Enclosure, ABS, IP 65 ▪ Grey cover (quick-locking)

Accessories			
Order symbol	Code	Dimensions	Description
TF 28037	7028337		Wall fastening lug set ▪ incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) ▪ incl. mounting screws

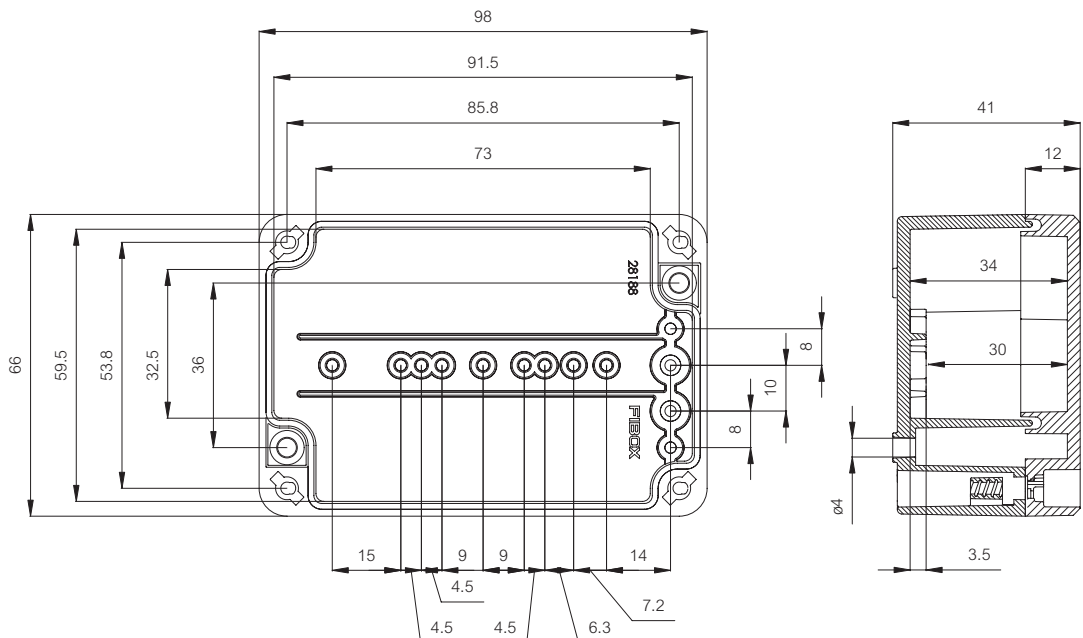



EURONORD PC/ABS 0808

82 x 80

PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 080806	7032540	82 x 80 x 55	Enclosure, PC • Grey cover
PC 080807	7032560	82 x 80 x 65	Enclosure, PC • Grey cover
PC 080809	7032550	82 x 80 x 85	Enclosure, PC • Grey cover
PC 080810	7032570	82 x 80 x 95	Enclosure, PC • Grey cover
PCT 080806	7022541	82 x 80 x 55	Enclosure, PC • Transparent cover
PCT 080807	7022561	82 x 80 x 65	Enclosure, PC • Transparent cover
PCT 080809	7022551	82 x 80 x 85	Enclosure, PC • Transparent cover
PCT 080810	7022571	82 x 80 x 95	Enclosure, PC • Transparent cover
AB 080806	7083540	82 x 80 x 55	Enclosure, ABS • Grey cover
AB 080807	7083560	82 x 80 x 65	Enclosure, ABS • Grey cover
AB 080809	7083550	82 x 80 x 85	Enclosure, ABS • Grey cover
AB 080810	7083570	82 x 80 x 95	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 0808	9512011	56 x 71	Mounting plate
TRM 0808	9820004	15 x 68	DIN-15 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

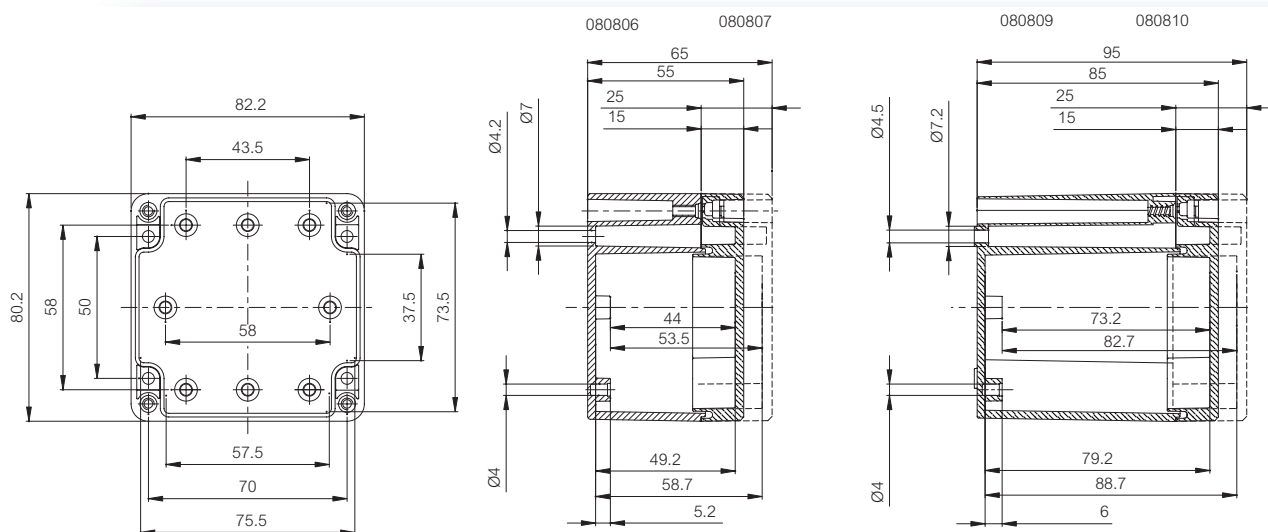

EURONORD

PC/ABS 0812

120 x 80 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.




Enclosures

Order symbol	Code	Dimensions	Description
PC 081206	7032580	120 x 80 x 55	Enclosure, PC • Grey cover
PC 081206H	7032590	120 x 80 x 60	Enclosure, PC • Grey cover
PC 081209	7032600	120 x 80 x 85	Enclosure, PC • Grey cover
PC 081209H	7032610	120 x 80 x 90	Enclosure, PC • Grey cover
PCT 081206	7022581	120 x 80 x 55	Enclosure, PC • Transparent cover
PCT 081206H	7022591	120 x 80 x 60	Enclosure, PC • Transparent cover
PCT 081209	7022601	120 x 80 x 85	Enclosure, PC • Transparent cover
PCT 081209H	7022611	120 x 80 x 90	Enclosure, PC • Transparent cover
AB 081206	7083580	120 x 80 x 55	Enclosure, ABS • Grey cover
AB 081206H	7083590	120 x 80 x 60	Enclosure, ABS • Grey cover
AB 081209	7083600	120 x 80 x 85	Enclosure, ABS • Grey cover
AB 081209H	7083610	120 x 80 x 90	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 0812	9512012	71 x 94	Mounting plate
TRM 0808	9820004	15 x 68	DIN-15 Mounting rail
TRM 0812	9820009	15 x 106	DIN-15 Mounting rail
ARH 12	9822001	35 x 105	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

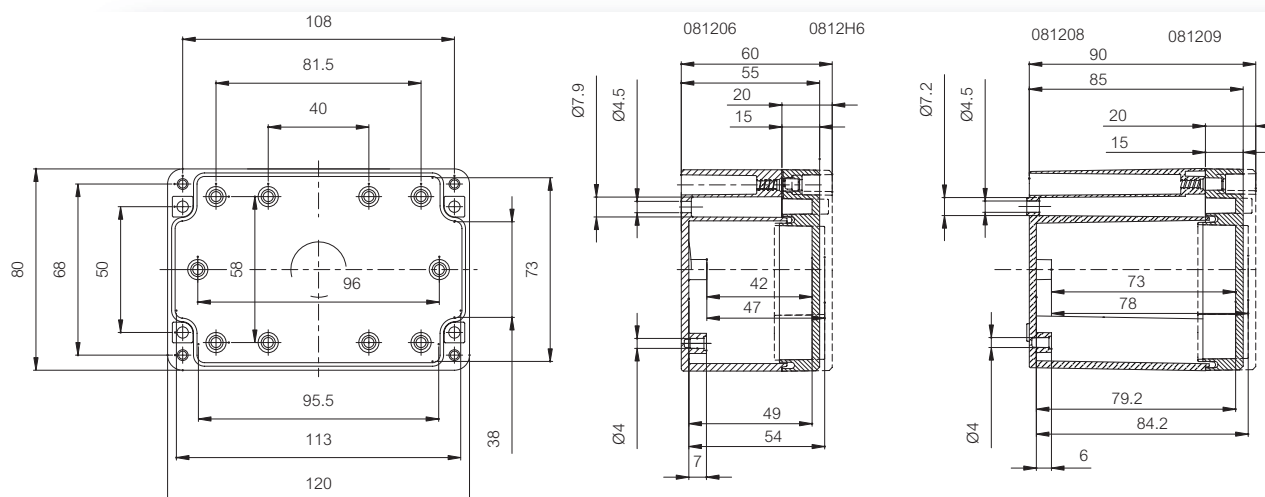



EURONORD PC/ABS 0816

160 x 80 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 081606	7032630	160 x 80 x 55	Enclosure, PC • Grey cover
PC 081607	7032620	160 x 80 x 65	Enclosure, PC • Grey cover
PC 081609	7032650	160 x 80 x 85	Enclosure, PC • Grey cover
PC 081610	7032640	160 x 80 x 95	Enclosure, PC • Grey cover
PCT 081606	7022631	160 x 80 x 55	Enclosure, PC • Transparent cover
PCT 081607	7022621	160 x 80 x 65	Enclosure, PC • Transparent cover
PCT 081609	7022651	160 x 80 x 85	Enclosure, PC • Transparent cover
PCT 081610	7022641	160 x 80 x 95	Enclosure, PC • Transparent cover
AB 081606	7083630	160 x 80 x 55	Enclosure, ABS • Grey cover
AB 081607	7083620	160 x 80 x 65	Enclosure, ABS • Grey cover
AB 081609	7083650	160 x 80 x 85	Enclosure, ABS • Grey cover
AB 081610	7083640	160 x 80 x 95	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 0816	9512013	71 x 134	Mounting plate
TRM 0808	9820004	15 x 68	DIN-15 Mounting rail
TRM 0816	9820013	15 x 146	DIN-15 Mounting rail
TRH 1216	9822028	35 x 146	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

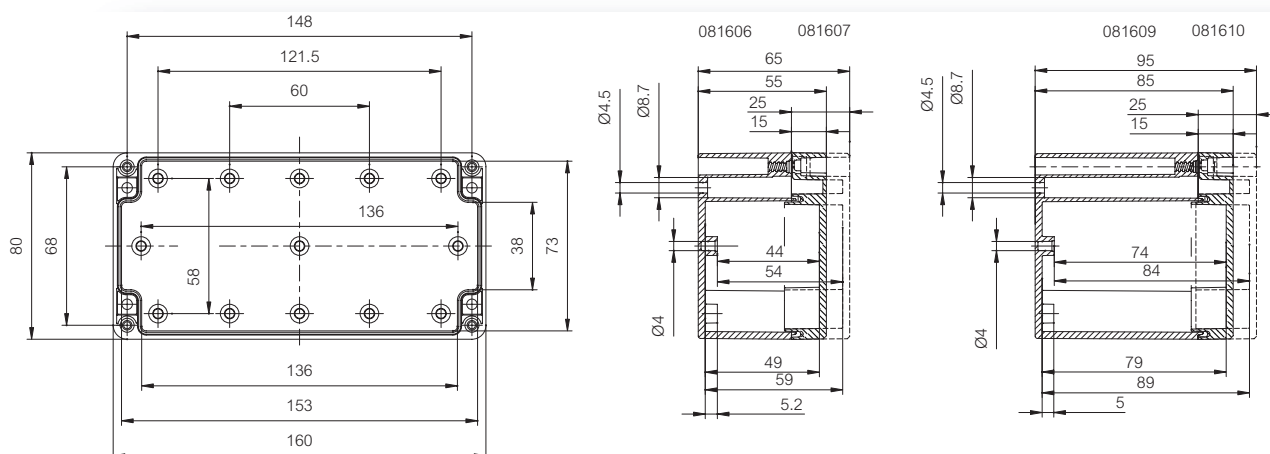

EURONORD

PC/ABS 1212

122 x 120 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.




Enclosures

Order symbol	Code	Dimensions	Description
PC 121207	7032660	122 x 120 x 65	Enclosure, PC • Grey cover
PC 121208	7032670	122 x 120 x 75	Enclosure, PC • Grey cover
PC 121210	7032680	122 x 120 x 95	Enclosure, PC • Grey cover
PC 121211	7032690	122 x 120 x 105	Enclosure, PC • Grey cover
PCT 121207	7022661	122 x 120 x 65	Enclosure, PC • Transparent cover
PCT 121208	7022671	122 x 120 x 75	Enclosure, PC • Transparent cover
PCT 121210	7022681	122 x 120 x 95	Enclosure, PC • Transparent cover
PCT 121211	7022691	122 x 120 x 105	Enclosure, PC • Transparent cover
AB 121207	7083660	122 x 120 x 65	Enclosure, ABS • Grey cover
AB 121208	7083670	122 x 120 x 75	Enclosure, ABS • Grey cover
AB 121210	7083680	122 x 120 x 95	Enclosure, ABS • Grey cover
AB 121211	7083690	122 x 120 x 105	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 1212	9512014	96 x 111	Mounting plate
TRM 0812	9820009	15 x 106	DIN-15 Mounting rail
TRM 1212	9820008	15 x 110	DIN-15 Mounting rail
TRH 1212	9822002	35 x 110	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

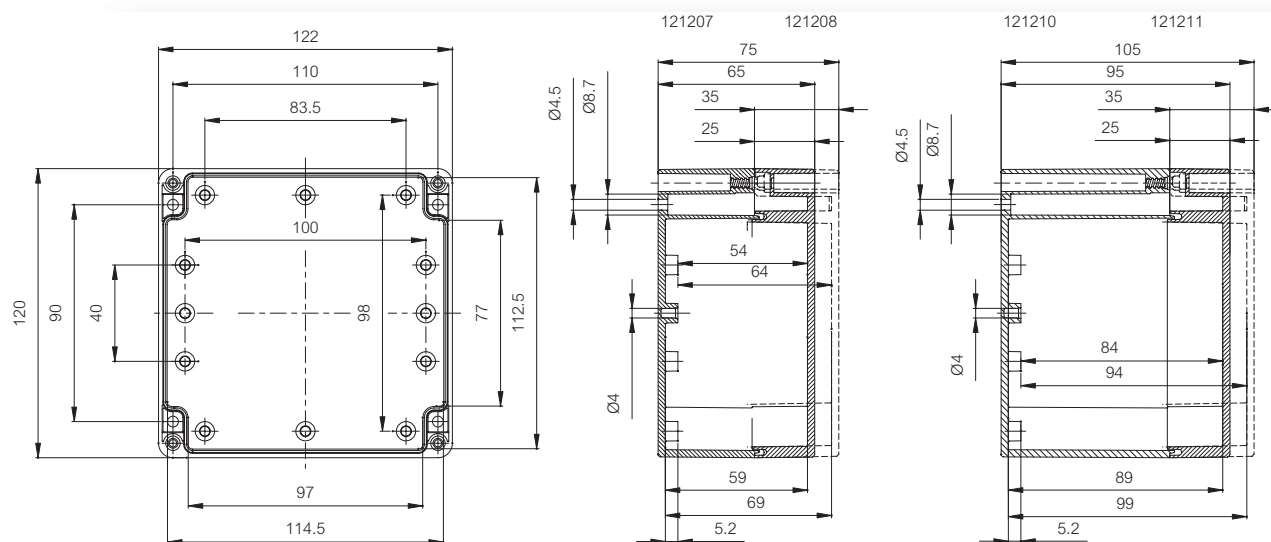



EURONORD PC/ABS 1216

160 x 120 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 121609	7032720	160 x 120 x 90	Enclosure, PC • Grey cover
PC 121614	7032730	160 x 120 x 140	Enclosure, PC • Grey cover
PCT 121609	7022721	160 x 120 x 90	Enclosure, PC • Transparent cover
PCT 121614	7022731	160 x 120 x 140	Enclosure, PC • Transparent cover
AB 121609	7083720	160 x 120 x 90	Enclosure, ABS • Grey cover
AB 121614	7083730	160 x 120 x 140	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 1216	9512036	111 x 134	Mounting plate
TRM 0816	9820013	15 x 146	DIN-15 Mounting rail
MIV 10	5514082	35 x 100	DIN-35 Mounting rail
TRH 1216	9822028	35 x 146	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

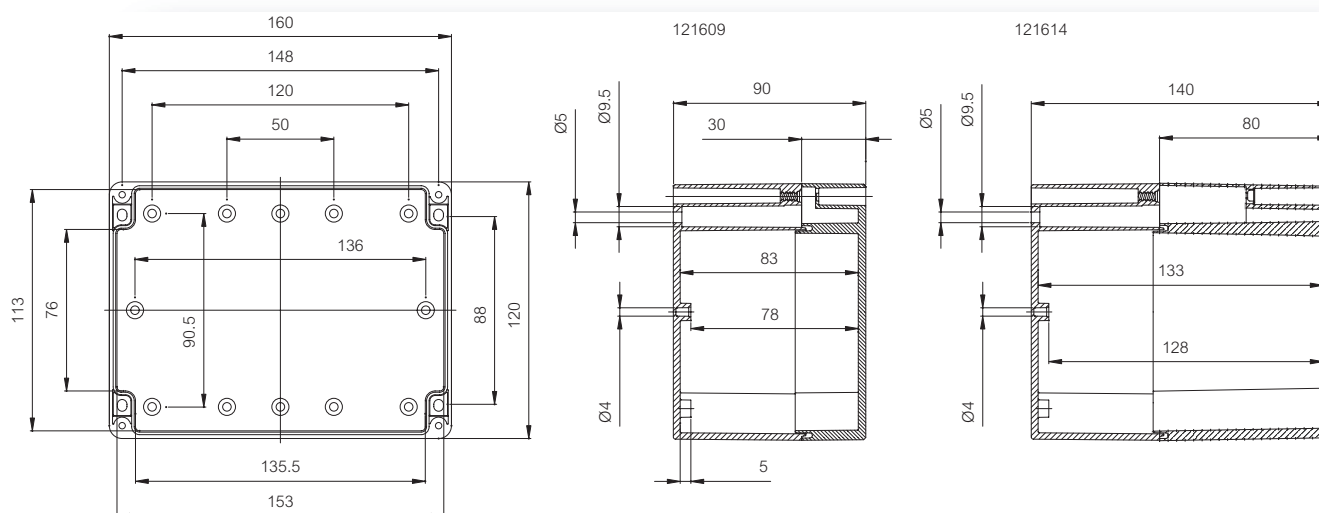

EURONORD

PC/ABS 1220

200 x 120 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.




Enclosures

Order symbol	Code	Dimensions	Description
PC 122008	7032760	200 x 120 x 75	Enclosure, PC • Grey cover
PC 122009	7032770	200 x 120 x 90	Enclosure, PC • Grey cover
PCT 122008	7022761	200 x 120 x 75	Enclosure, PC • Transparent cover
PCT 122009	7022771	200 x 120 x 90	Enclosure, PC • Transparent cover
AB 122008	7083760	200 x 120 x 75	Enclosure, ABS • Grey cover
AB 122009	7083770	200 x 120 x 90	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 1220	9512015	111 x 174	Mounting plate
MIV 10	5514082	35 x 100	DIN-35 Mounting rail
TRH 1220	9822006	35 x 186	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

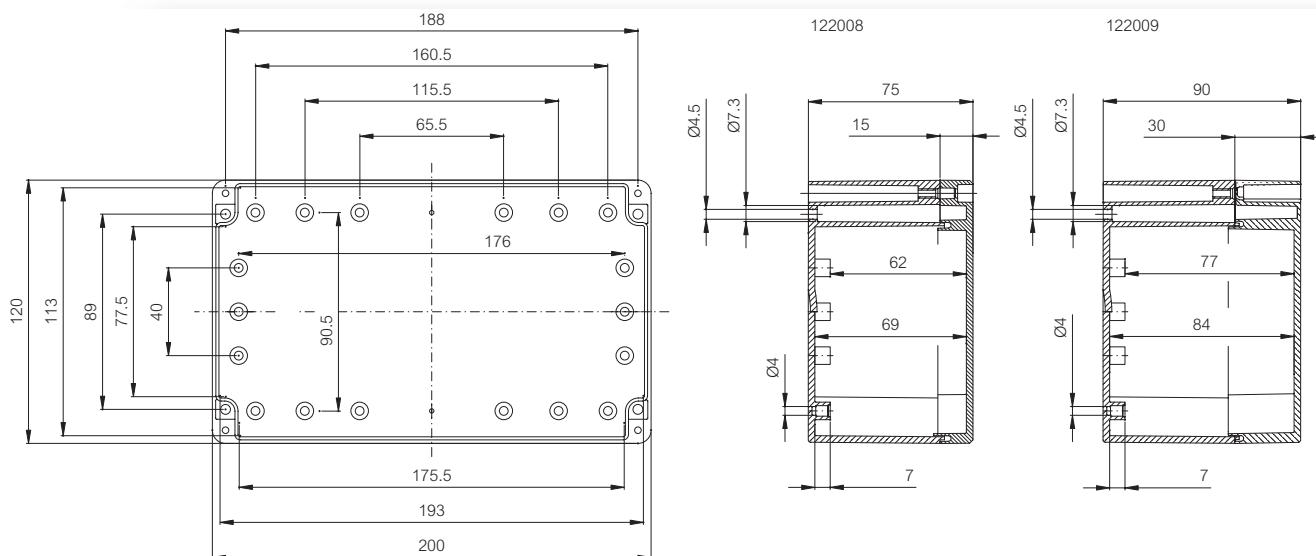



EURONORD PC/ABS 1224

244 x 124 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 122410	7032780	244 x 124 x 102	Enclosure, PC • Grey cover
PCT 122410	7022781	244 x 124 x 102	Enclosure, PC • Transparent cover
PCQ 122410	7033781	244 x 124 x 102	Enclosure, PC, IP 65 • Grey cover (quick-locking)
PCTQ 122410	7022780	244 x 124 x 102	Enclosure, PC, IP 65 • Transparent cover (quick-locking)
AB 122410	7083780	244 x 124 x 102	Enclosure, ABS • Grey cover
ABQ 122410	7083781	244 x 124 x 102	Enclosure, ABS, IP 65 • Grey cover (quick-locking)

Accessories

Order symbol	Code	Dimensions	Description
TM 1224	9512016	214 x 111	Mounting plate
TRM 0812	9820009	15 x 106	DIN-15 Mounting rail
MIN 20	6314578	15 x 225	DIN-15 Mounting rail
TRH 1212	9822002	35 x 110	DIN-35 Mounting rail
TRH 24	9822008	35 x 226	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

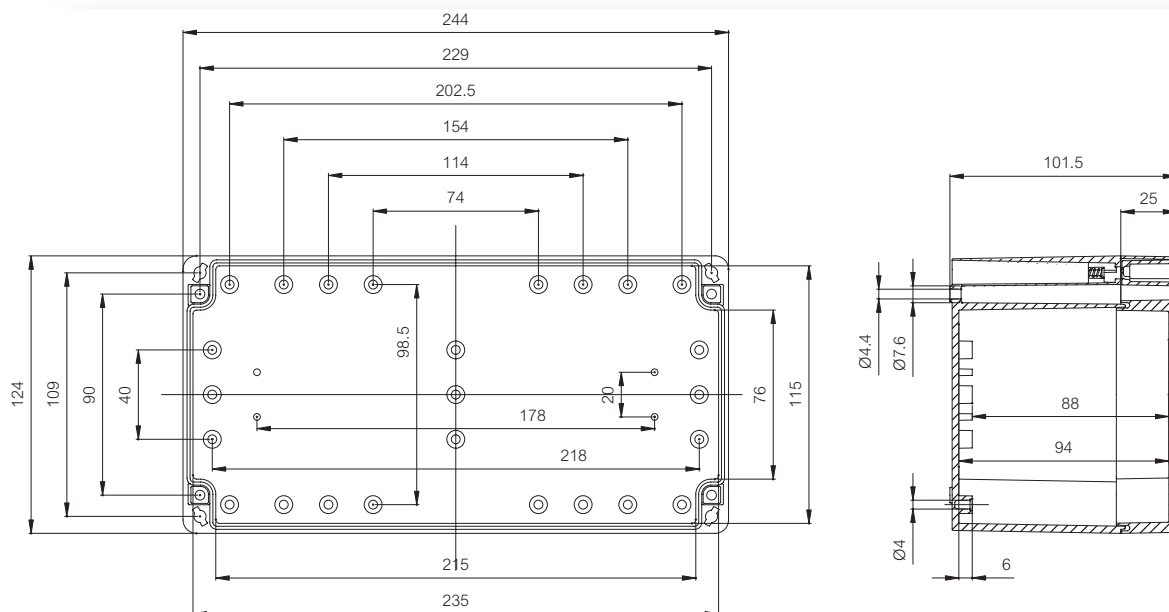

EURONORD

PC/ABS 1520

201 x 151 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.




Enclosures

Order symbol	Code	Dimensions	Description
PC 152008	7032820	201 x 151 x 80	Enclosure, PC • Grey cover
PCT 152008	7022821	201 x 151 x 80	Enclosure, PC • Transparent cover
AB 152008	7083820	201 x 151 x 80	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 1520	9512017	141 x 174	Mounting plate
TRH 1220	9822006	35 x 186	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

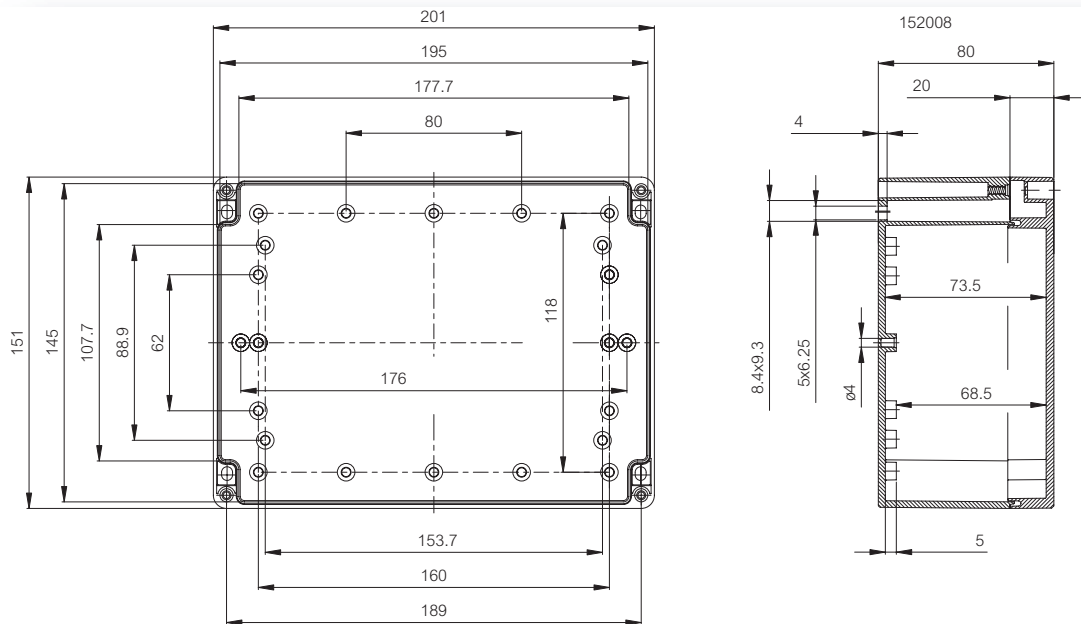




Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.

Order symbol	Code	Dimensions	Description
PC 153410	7032700	340 x 150 x 101	Enclosure, PC ▪ Grey cover
PC 153412	7032710	340 x 150 x 121	Enclosure, PC ▪ Grey cover
PCT 153410	7022701	340 x 150 x 101	Enclosure, PC ▪ Transparent cover
PCT 153412	7022711	340 x 150 x 121	Enclosure, PC ▪ Transparent cover
PCQ 153410	7033701	340 x 150 x 101	Enclosure, PC, IP 65 ▪ Grey cover (quick-locking)
PCQ 153412	7033711	340 x 150 x 121	Enclosure, PC, IP 65 ▪ Grey cover (quick-locking)
PCTQ 153410	7022700	340 x 150 x 101	Enclosure, PC, IP 65 ▪ Transparent cover (quick-locking)
PCTQ 153412	7022710	340 x 150 x 121	Enclosure, PC, IP 65 ▪ Transparent cover (quick-locking)
AB 153410	7083700	340 x 150 x 101	Enclosure, ABS ▪ Grey cover
AB 153412	7083710	340 x 150 x 121	Enclosure, ABS ▪ Grey cover
ABQ 153410	7083701	340 x 150 x 101	Enclosure, ABS, IP 65 ▪ Grey cover (quick-locking)
ABQ 153412	7083711	340 x 150 x 121	Enclosure, ABS, IP 65 ▪ Grey cover (quick-locking)

Order symbol	Code	Dimensions	Description
TM 1534	9512021	303 x 136	Mounting plate
TRH 34	9822022	35 x 307	DIN-35 Mounting rail
TRH 15	9822021	35 x 122	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set ▪ incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) ▪ incl. mounting screws

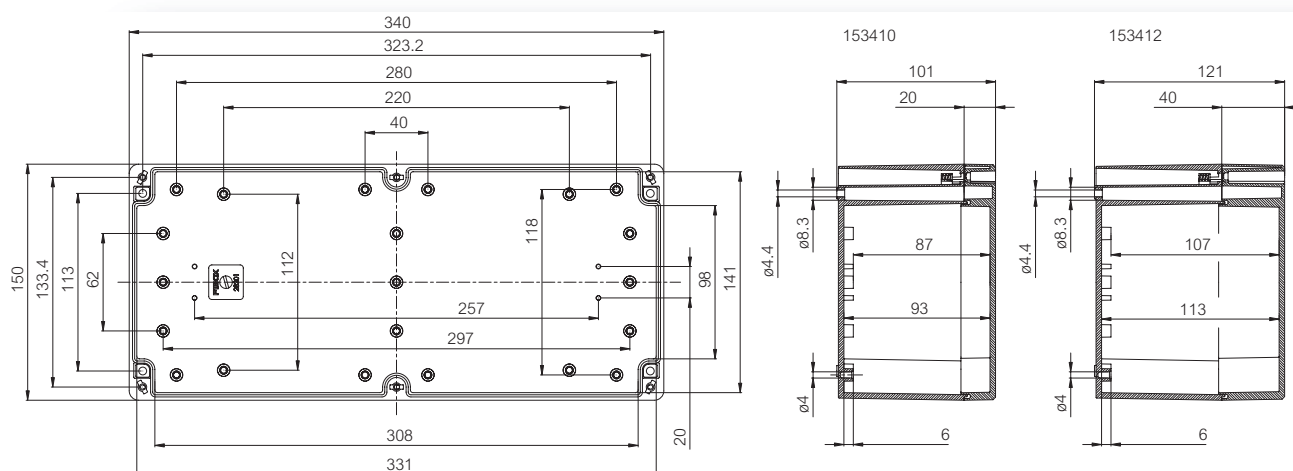

EURONORD

PC/ABS 1624

244 x 164 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07




Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 162409	7032810	244 x 164 x 90	Enclosure, PC • Grey cover
PC 162412	7032830	244 x 164 x 120	Enclosure, PC • Grey cover
PCT 162409	7022811	244 x 164 x 90	Enclosure, PC • Transparent cover
PCT 162412	7022831	244 x 164 x 120	Enclosure, PC • Transparent cover
PCQ 162409	7033811	244 x 164 x 90	Enclosure, PC, IP 65 • Grey cover (quick-locking)
PCQ 162412	7033831	244 x 164 x 120	Enclosure, PC, IP 65 • Grey cover (quick-locking)
PCTQ 162409	7022810	244 x 164 x 90	Enclosure, PC, IP 65 • Transparent cover (quick-locking)
PCTQ 162412	7022830	244 x 164 x 120	Enclosure, PC, IP 65 • Transparent cover (quick-locking)
AB 162409	7083810	244 x 164 x 90	Enclosure, ABS • Grey cover
AB 162412	7083830	244 x 164 x 120	Enclosure, ABS • Grey cover
ABQ 162409	7083811	244 x 164 x 90	Enclosure, ABS, IP 65 • Grey cover (quick-locking)
ABQ 162412	7083831	244 x 164 x 120	Enclosure, ABS, IP 65 • Grey cover (quick-locking)

Accessories

Order symbol	Code	Dimensions	Description
TM 1624	9512022	212 x 151	Mounting plate
MIN 20	6314578	15 x 225	DIN-15 Mounting rail
TRH 24	9822008	35 x 226	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

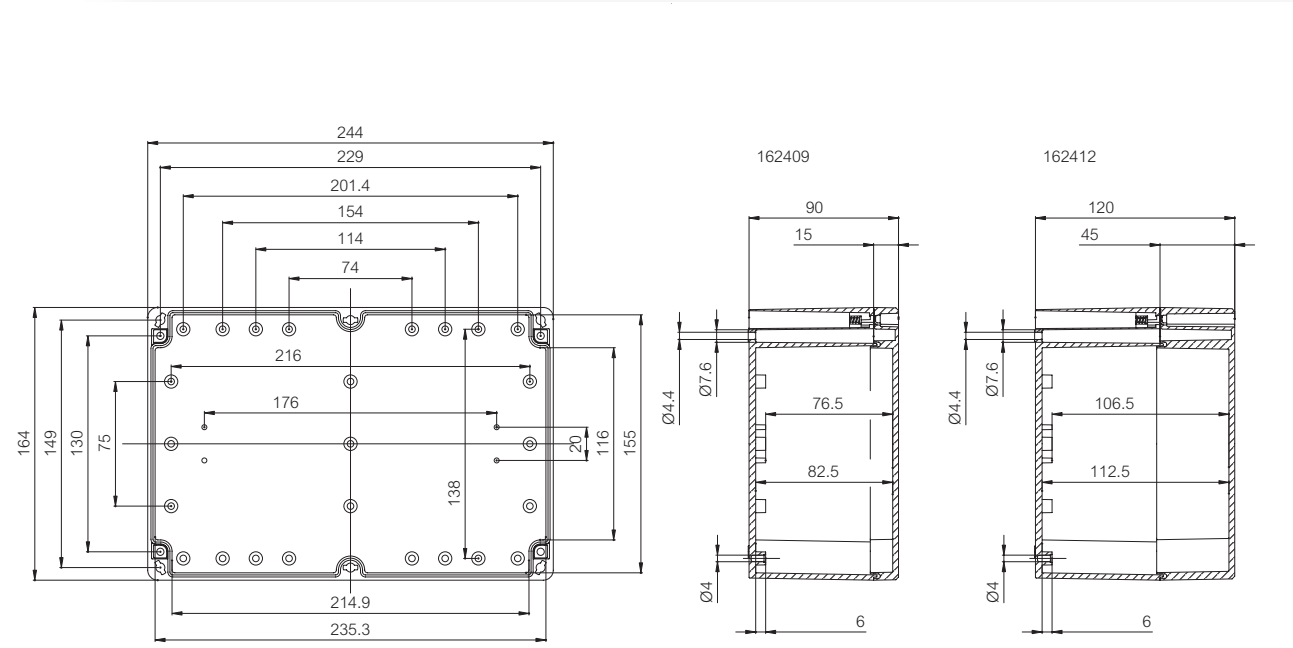



EURONORD PC/ABS 1625

250 x 160 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 162509	7032840	250 x 160 x 90	Enclosure, PC • Grey cover
PC 162513	7032860	250 x 160 x 125	Enclosure, PC • Grey cover
PC 162515	7032740	250 x 160 x 150	Enclosure, PC • Grey cover
PCT 162509	7022841	250 x 160 x 90	Enclosure, PC • Transparent cover
PCT 162513	7022861	250 x 160 x 125	Enclosure, PC • Transparent cover
PCT 162515	7022741	250 x 160 x 150	Enclosure, PC • Transparent cover
AB 162509	7083840	250 x 160 x 90	Enclosure, ABS • Grey cover
AB 162513	7083860	250 x 160 x 125	Enclosure, ABS • Grey cover
AB 162515	7083740	250 x 160 x 150	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 1625	9512018	151 x 224	Mounting plate
TRM 0816	9820013	15 x 146	DIN-15 Mounting rail
TRH 1216	9822028	35 x 146	DIN-35 Mounting rail
TRH 24	9822008	35 x 226	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

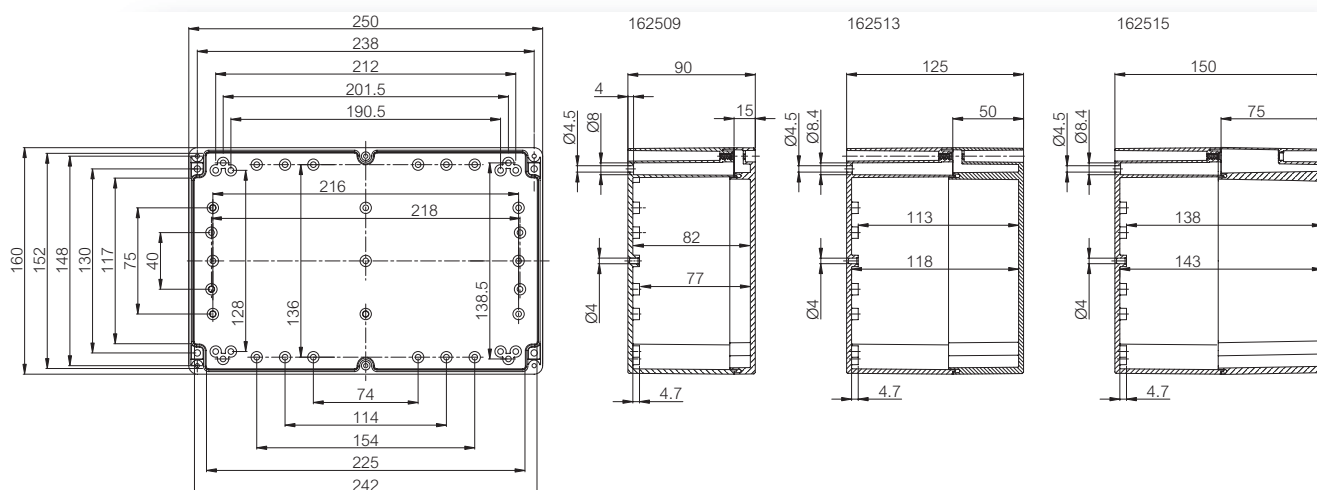

EURONORD

PC/ABS 1636

360 x 160 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07




Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 163610	7032750	360 x 160 x 101	Enclosure, PC • Grey cover
PCT 163610	7022851	360 x 160 x 101	Enclosure, PC • Transparent cover
PCQ 163610	7033751	360 x 160 x 101	Enclosure, PC, IP 65 • Grey cover (quick-locking)
PCTQ 163610	7022750	360 x 160 x 101	Enclosure, PC, IP 65 • Transparent cover (quick-locking)
AB 163610	7083750	360 x 160 x 101	Enclosure, ABS • Grey cover
ABQ 163610	7083751	360 x 160 x 101	Enclosure, ABS, IP 65 • Grey cover (quick-locking)

Accessories

Order symbol	Code	Dimensions	Description
TM 1636	9512023	318 x 146	Mounting plate
ARM 0615	9820011	15 x 140	DIN-15 Mounting rail
DH-3	8524032	35 x 140	DIN-35 Mounting rail
TRH 2036	9822023	35 x 340	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

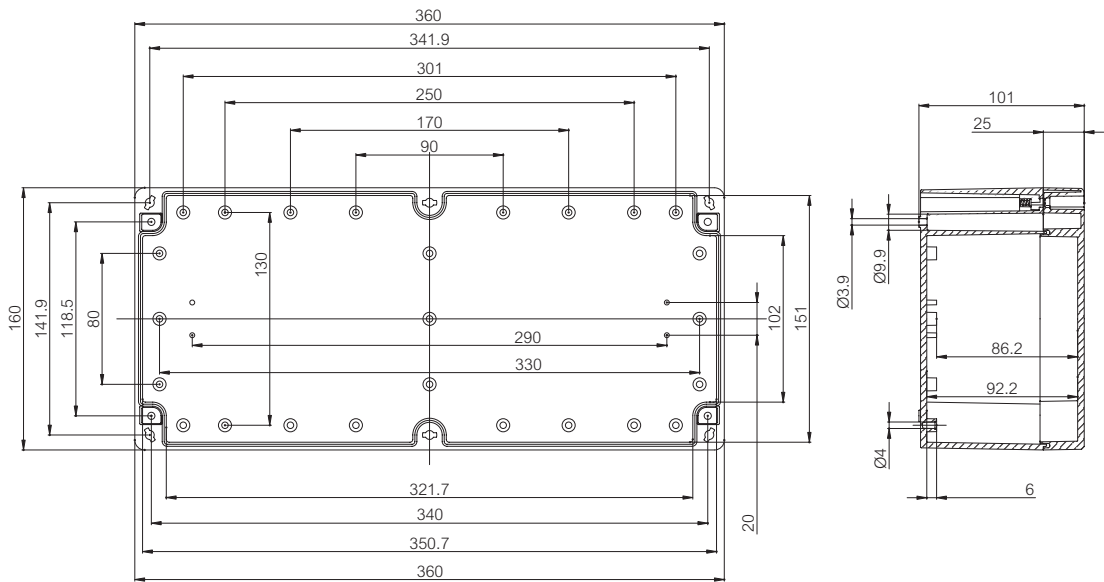



EURONORD PC/ABS 2036

360 x 200 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
PC 203615	7032790	360 x 200 x 151	Enclosure, PC • Grey cover
PCT 203615	7022791	360 x 200 x 151	Enclosure, PC • Transparent cover
PCQ 203615	7033791	360 x 200 x 151	Enclosure, PC, IP 65 • Grey cover (quick-locking)
PCTQ 203615	7022790	360 x 200 x 151	Enclosure, PC, IP 65 • Transparent cover (quick-locking)
AB 203615	7083790	360 x 200 x 151	Enclosure, ABS • Grey cover
ABQ 203615	7083791	360 x 200 x 151	Enclosure, ABS, IP 65 • Grey cover (quick-locking)

Accessories

Order symbol	Code	Dimensions	Description
TM 2036	9512024	318 x 186	Mounting plate
TRH 2036	9822023	35 x 340	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

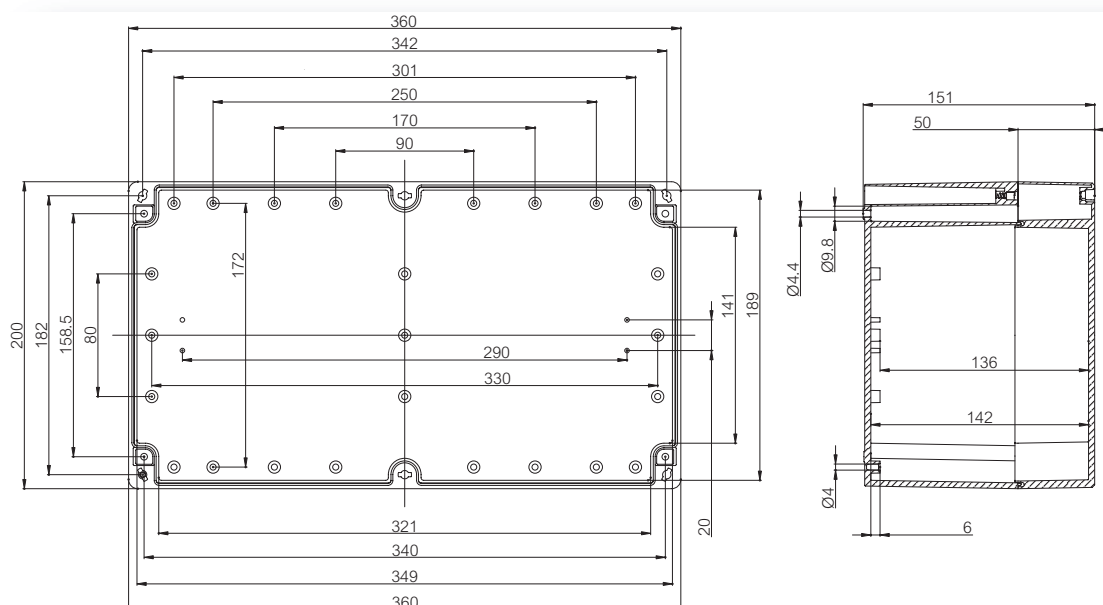

EURONORD

PC/ABS 2330

300 x 230 PC: IP 66/IP 67, IK 07/IK 08
ABS: IP 66/IP 67, IK 07

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.




Enclosures

Order symbol	Code	Dimensions	Description
PC 233009	7032870	300 x 230 x 87	Enclosure, PC • Grey cover
PC 233011	7032890	300 x 230 x 110	Enclosure, PC • Grey cover
PCT 233009	7022871	300 x 230 x 87	Enclosure, PC • Transparent cover
PCT 233011	7022891	300 x 230 x 110	Enclosure, PC • Transparent cover
AB 233009	7083870	300 x 230 x 87	Enclosure, ABS • Grey cover
AB 233011	7083890	300 x 230 x 110	Enclosure, ABS • Grey cover

Accessories

Order symbol	Code	Dimensions	Description
TM 2330	9512019	221 x 274	Mounting plate
TRM 0816	9820013	15 x 146	DIN-15 Mounting rail
TRH 1216	9822028	35 x 146	DIN-35 Mounting rail
TRH 2330	9822013	35 x 285	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

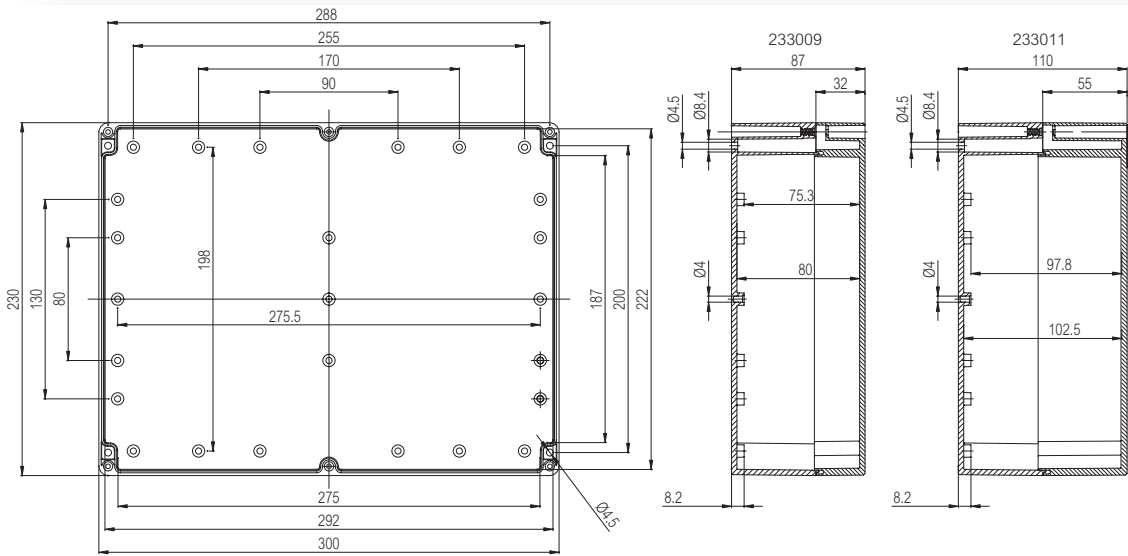



EURONORD

ABS 3640

400 x 360

ABS: IP 66/IP 67, IK 07


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws. Q-versions: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and quick-locking cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AB 364015	7083880	400 x 360 x 151	Enclosure, ABS • Grey cover
ABQ 364015	7083881	400 x 360 x 151	Enclosure, ABS, IP 65 • Grey cover (quick-locking)

Accessories

Order symbol	Code	Dimensions	Description
TM 3640	9512025	383 x 315	Mounting plate
TRH 40	9822024	35 x 380	DIN-35 Mounting rail
TF 28037	7028337		Wall fastening lug set • incl. screws
TH A	9802001		Grey plastic hinges (2 pcs) • incl. mounting screws

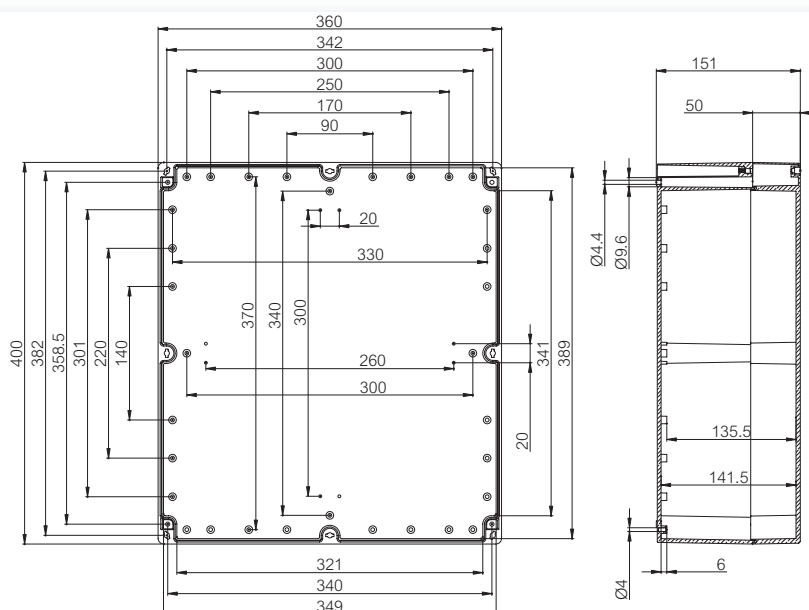

PC/ABS ACCESSORIES

Order symbol	Code	Description
--------------	------	-------------

Mounting plates (Galvanized steel, sheet thickness 1,5 mm)

TM 0505	9512009	26 x 44
TM 0507	9512010	26 x 57
TM 0808	9512011	56 x 71
TM 0812	9512012	71 x 94
TM 0816	9512013	71 x 134
TM 1212	9512014	96 x 111
TM 1216	9512036	111 x 134
TM 1220	9512015	111 x 174
TM 1224	9512016	214 x 111
TM 1520	9512017	141 x 174
TM 1534	9512021	303 x 136
TM 1624	9512022	212 x 151
TM 1625	9512018	151 x 224
TM 1636	9512023	318 x 146
TM 2036	9512024	318 x 186
TM 2330	9512019	221 x 274
TM 3640	9512025	383 x 315

DIN-15 Mounting rails (Galvanized steel, rail height 5,0 mm)

TRM 0507	9820001	15 x 48
TRM 0808	9820004	15 x 68
TRM 0812	9820009	15 x 106
TRM 1212	9820008	15 x 110
ARM 0615	9820011	15 x 140
TRM 0816	9820013	15 x 146
MIN 20	6314578	15 x 225

DIN-35 Mounting rails (Galvanized steel, rail height 7,5 mm)

MIV 10	5514082	35 x 100
ARH 12	9822001	35 x 105
TRH 1212	9822002	35 x 110
TRH 15	9822021	35 x 122
DH-3	8524032	35 x 140
TRH 1216	9822028	35 x 146
TRH 1220	9822006	35 x 186
TRH 1520	9822020	35 x 170
TRH 24	9822008	35 x 226
TRH 2330	9822013	35 x 285
TRH 34	9822022	35 x 307
TRH 2036	9822023	35 x 340
TRH 40	9822024	35 x 380

Hinges and wall mounting

TH A	9802001	Grey plastic hinges (2 pcs) • incl. mounting screws
TF 28037	7028337	Wall fastening lug set • incl. screws

Cover screws

MR 28005EU	7028005	Cover screw
MRS 38036	7038036	Cover screw set • 2xMR 28005EU+2xMR 28036
MRS 38005	7038005	Cover screw set • 4xMR 28005EU+4xMR 28036
MRS 38215Q	7038215	4 x Short QuickLock screws
MRS 38216Q	7038216	4 x Long QuickLock screws
MRS 38217	7038217	4 x Long threaded screws

Mounting screws and other accessories

MR 28036EU	7028036	Mounting screw
MRS 48036	7048036	4 x mounting screws
MRS 28084 SET	7700101	Brass insert set for PC/ABS
MB 28018	7028018	Decoration plug • for PC/ABS enclosures
SB 28088	7028088	Sealing bush



EURONORD PC/ABS

technical information

Property	Polycarbonate (PC)	ABS
Ingress Protection (EN 60529)	IP 66/IP 67 IP 65 quicklock	IP 66/IP 67 IP 65 quicklock
Impact Resistance (EN 62262)	IK 07 (side surface) IK 08 (front surface)	IK 07
Temperature Range Celsius (short term) Fahrenheit	-40° . . 120°C -40° . . 250°F	-40° . . 80°C -40° . . 175°F
Temperature Range Celsius (continuous) Fahrenheit	-40° . . 80°C -40° . . 175°F	-40° . . 60°C -40° . . 140°F
Electrical Insulation	Totally insulated ☐	Totally insulated ☐
Light Grey Parts Colour	RAL 7035 Industry Grey	RAL 7035 Industry Grey
Transparent Clear PC Cover	Clear transparent	Clear transparent
Cover Screws	Ferritic Stainless Steel	Ferritic Stainless Steel
Cover Screws (quicklock)	Zinc Die-Cast	Zinc Die-Cast
Gasket	PUR	PUR
Enclosure Flammability Rating	UL 94-5V	UL 94HB
Glow Wire Test (IEC 695-2-1) Self -extinguishing (PC)	960°C	650°C
Non-toxicity	Halogen Free	Halogen Free
UV resistance	UL 508 720 hours in "Weather- ometer"	
Chemical Resistance *	Good	Good

Data subject to change without notice.

* Consult separate raw material data for more detailed information

Conformity to standards

USA Enclosures for Electrical Equipment
PC(all)+PCQ 071004: UL Type 1, 4, 4X, 12 or 13; UL File
E75645 Vol 1 Sec 6; UL 746C-5VA flame test (UL 50/508)
PCQ: NEMA 1, 3, 3S, 12 or 13
ABS: NEMA 1, 4, 4X, 12 or 13
ABSQ: NEMA 1, 3, 3S, 12 or 13

Canada Industrial Control Equipment
Enclosures for Electrical Equipment/ULc

Europe Empty enclosures for low-voltage switchgear and
controlgear assemblies EN 62208:2003 (50298:1998)

Europe Safety of Information Technology Equipment
EN 60950

RoHS directive 2002/95/EC

Russia GostR - Gost Russian certificate of conformity

EURONORD

AL 0505

50 x 45


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 050503	7011020	50 x 45 x 32	Enclosure • Aluminium

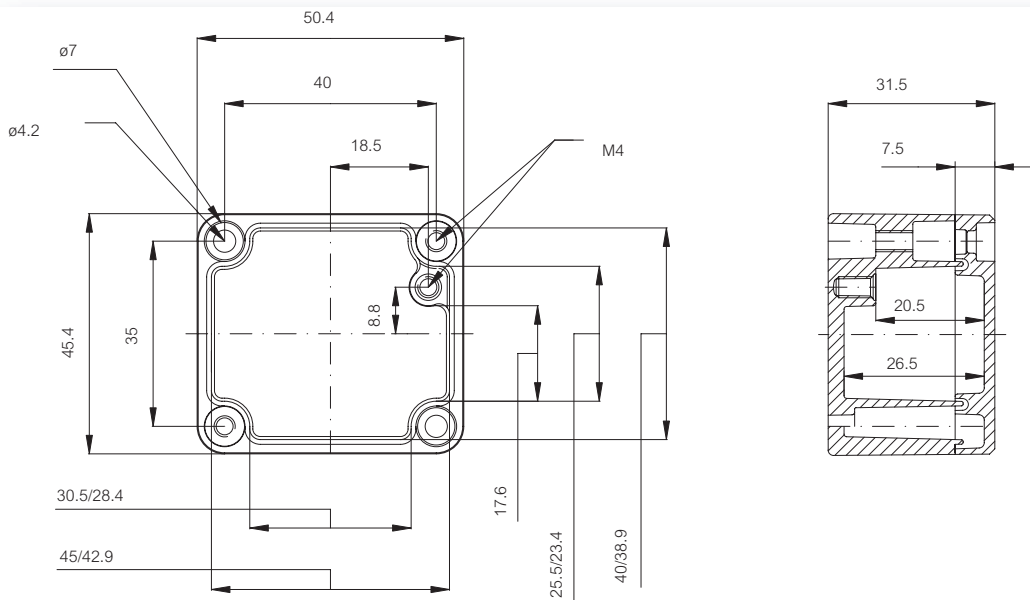



EURONORD AL 0606

66 x 60

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 060605	7011060	66 x 60 x 46	Enclosure ▪ Aluminium

Accessories

Order symbol	Code	Dimensions	Description
TRM 0507	9820001	15 x 48	DIN-15 Mounting rail
MIV 5	5514081	35 x 50	DIN-35 Mounting rail
MR 75003	7075003		Selftapping taptite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) ▪ incl. screws

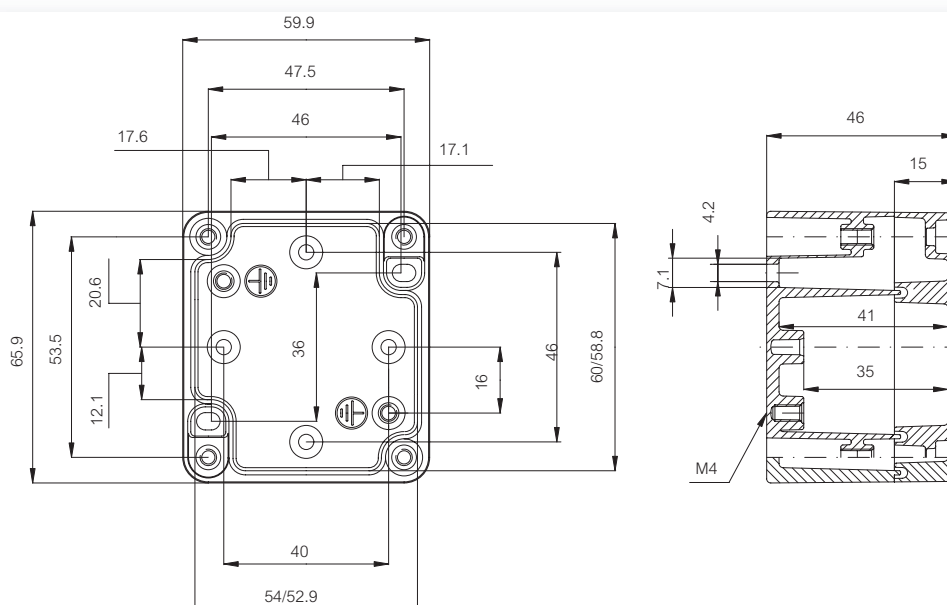

EURONORD

AL 0610

100 x 66


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 061005	7011080	100 x 66 x 46	Enclosure • Aluminium

Accessories			
Order symbol	Code	Dimensions	Description
ARM 0610	9820005	15 x 88	DIN-15 Mounting rail
MR 75003	7075003		Selftapping taptite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

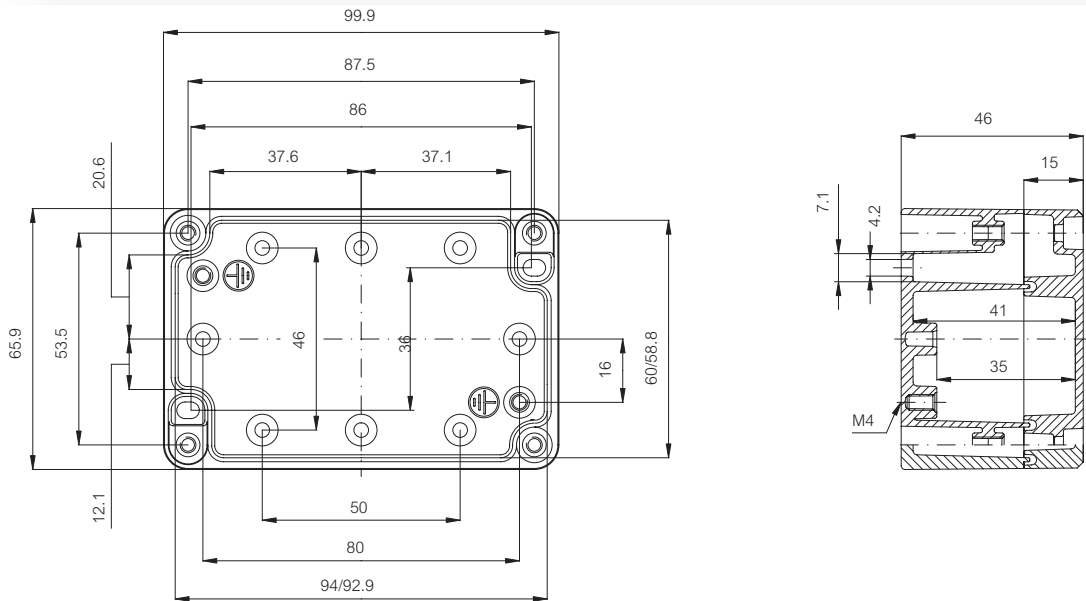



EURONORD

AL 0615

152 x 66

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 061505	7011100	152 x 66 x 46	Enclosure • Aluminium

Accessories

Order symbol	Code	Dimensions	Description
ARM 0615	9820011	15 x 140	DIN-15 Mounting rail
ARH 16	9822003	35 x 140	DIN-35 Mounting rail
MR 75003	7075003		Selftapping taptite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

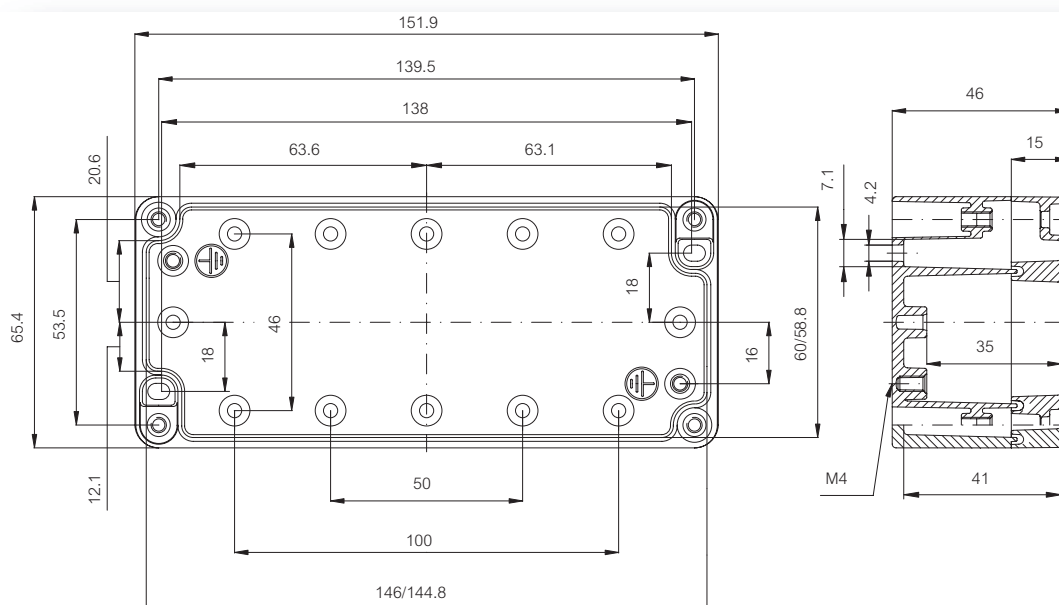

EURONORD

AL 0808

82 x 77


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 080806	7011130	82 x 77 x 57	Enclosure • Aluminium

Accessories			
Order symbol	Code	Dimensions	Description
AM 0808	9823015	69 x 64	Mounting plate
ARM 0808	9820002	15 x 65	DIN-15 Mounting rail
TRM 0808	9820004	15 x 68	DIN-15 Mounting rail
MR 75003	7075003		Selftapping tapite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

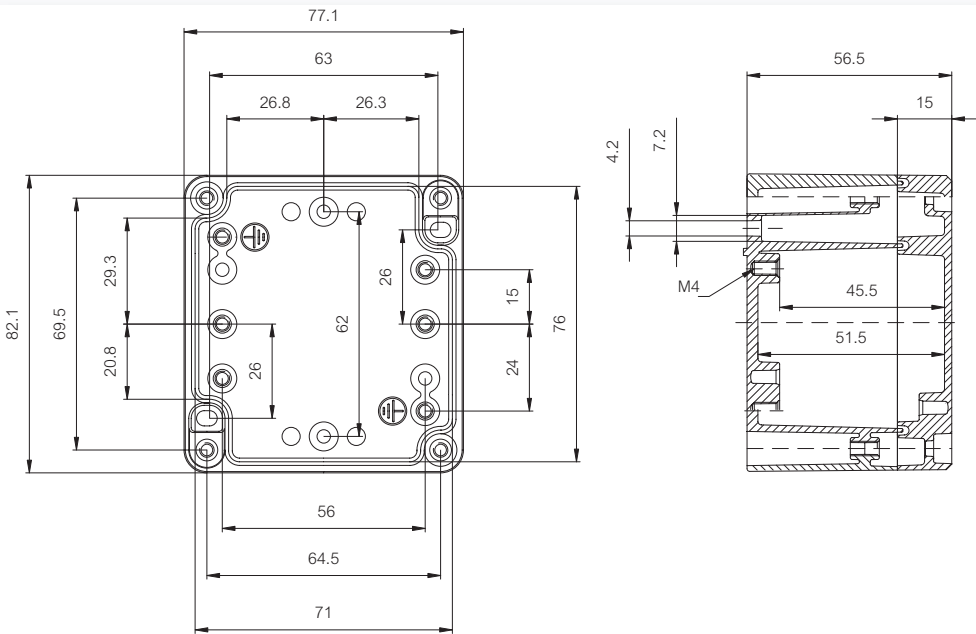



EURONORD

AL 0813

127 x 81

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 081306	7011150	127 x 81 x 57	Enclosure • Aluminium
ALC 081306	7021150	127 x 81 x 57	Enclosure • Aluminium "CLASSIC"

Accessories

Order symbol	Code	Dimensions	Description
AM 0813	9511043	69 x 114	Mounting plate
ARM 0813	9820010	15 x 115	DIN-15 Mounting rail
MR 75003	7075003		Selftapping taptite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

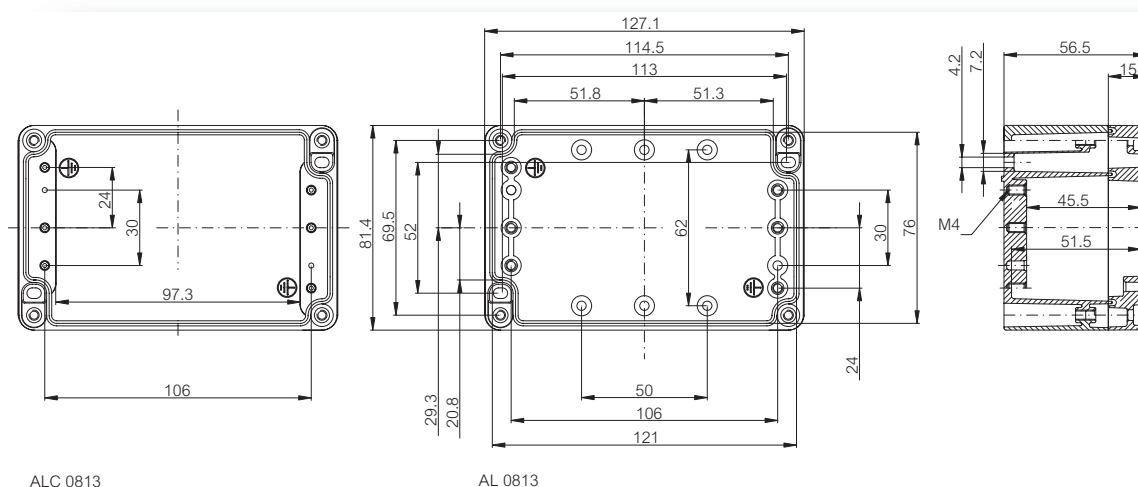

EURONORD

AL 0818

177 x 81


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 081806	7011170	177 x 81 x 57	Enclosure • Aluminium
ALC 081806	7021170	177 x 81 x 57	Enclosure • Aluminium "CLASSIC"

Accessories			
Order symbol	Code	Dimensions	Description
AM 0818	9823017	69 x 164	Mounting plate
ARM 0818	9820014	15 x 165	DIN-15 Mounting rail
EKV 12	3770647	35 x 160	DIN-35 Mounting rail
MR 75003	7075003		Selftapping taptite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

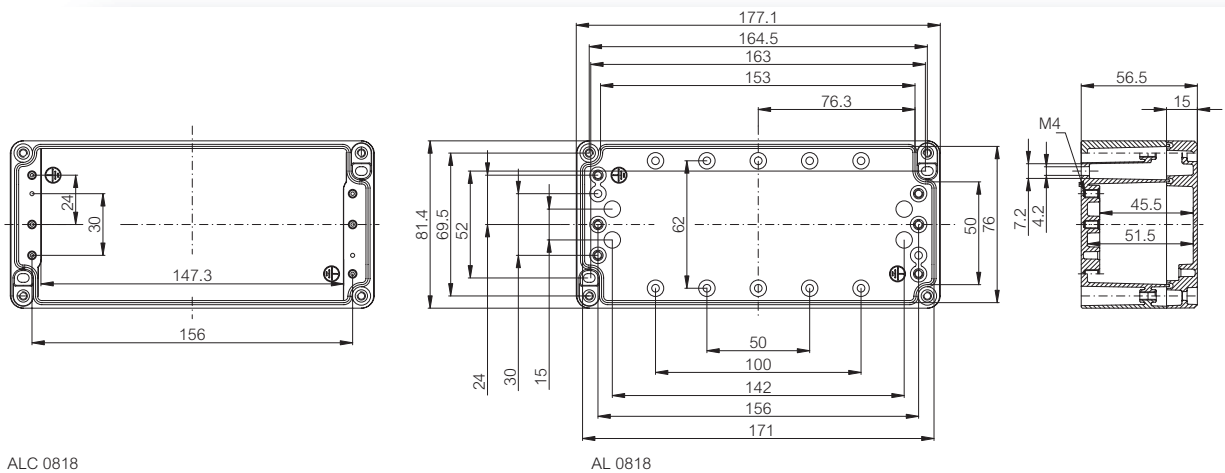



EURONORD

AL 0825

252 x 81

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 082506	7011190	252 x 81 x 57	Enclosure • Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 0808	9823015	69 x 64	Mounting plate
AM 0813	9511043	69 x 114	Mounting plate
AM 0818	9823017	69 x 164	Mounting plate
AM 0825	9511007	69 x 240	Mounting plate
ARM 0808	9820002	15 x 65	DIN-15 Mounting rail
ARM 0825	9820019	15 x 240	DIN-15 Mounting rail
ARH 26	9822011	35 x 240	DIN-35 Mounting rail
MR 75003	7075003		Selftapping taptite screw M3
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

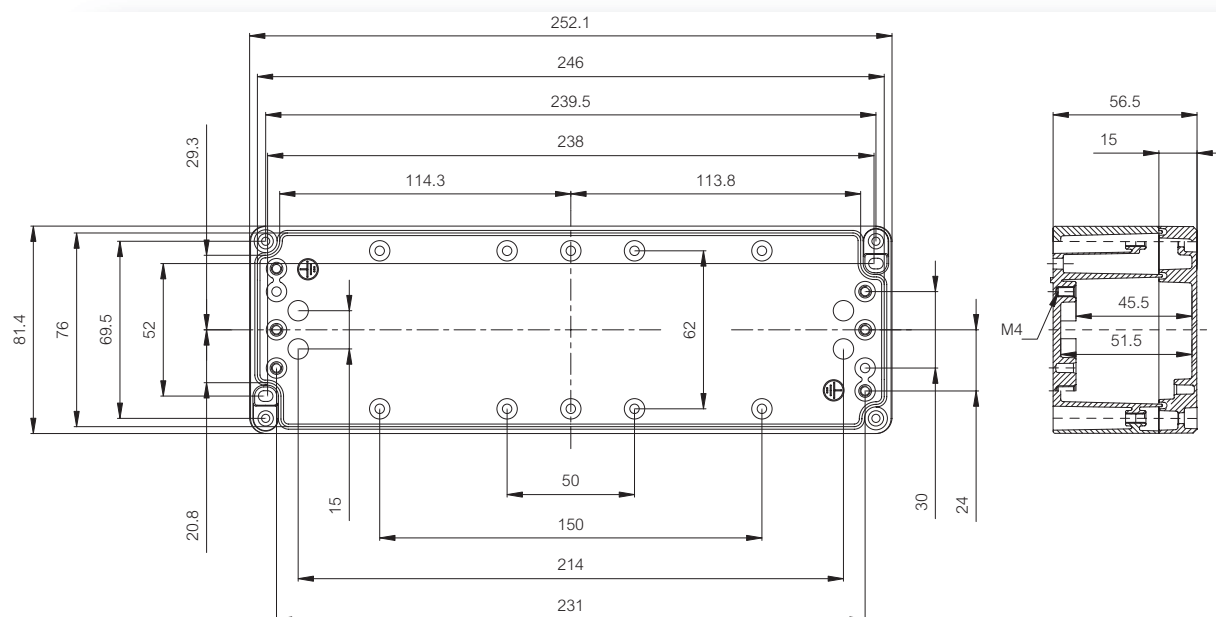

EURONORD

AL 1212


125 x 124

AL: IP 66/IP 67, IK 08

Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.



Enclosures			
Order symbol	Code	Dimensions	Description
AL 121208	7011210	125 x 124 x 81	Enclosure • Aluminium
Accessories			
Order symbol	Code	Dimensions	Description
AM 1212	9511150	107 x 110	Mounting plate
ARH 12	9822001	35 x 105	DIN-35 Mounting rail
MR 75005	7075005		Selftapping taptite screw M5
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

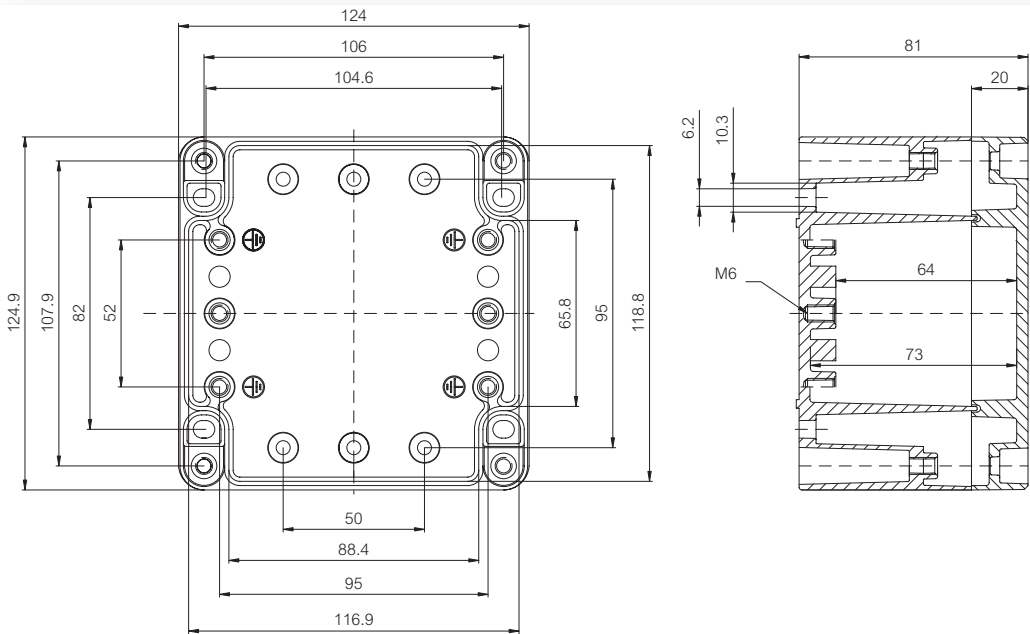



EURONORD

AL 1222

222 x 125

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 122208	7011230	222 x 125 x 81	Enclosure ▪ Aluminium
ALC 122208	7021230	222 x 125 x 81	Enclosure ▪ Aluminium "CLASSIC"

Accessories

Order symbol	Code	Dimensions	Description
AM 1222	9511095	107 x 207	Mounting plate
ARH 22	9822007	35 x 203	DIN-35 Mounting rail
MR 75005	7075005		Selftapping taptite screw M5
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

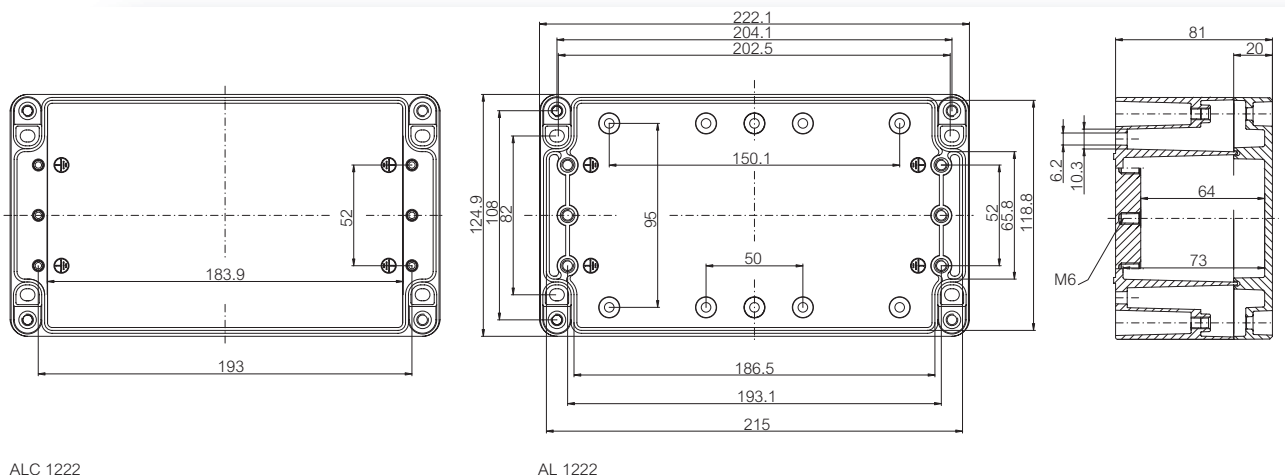

EURONORD

AL 1236


362 x 125

AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 123608	7011250	362 x 125 x 81	Enclosure • Aluminium
Accessories			
Order symbol	Code	Dimensions	Description
AM 1212	9511150	107 x 110	Mounting plate
AM 1222	9511095	107 x 207	Mounting plate
AM 1236	9511174	107 x 347	Mounting plate
ARH 12	9822001	35 x 105	DIN-35 Mounting rail
ARH 36	9822015	35 x 343	DIN-35 Mounting rail
MR 75005	7075005		Selftapping taptite screw M5
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

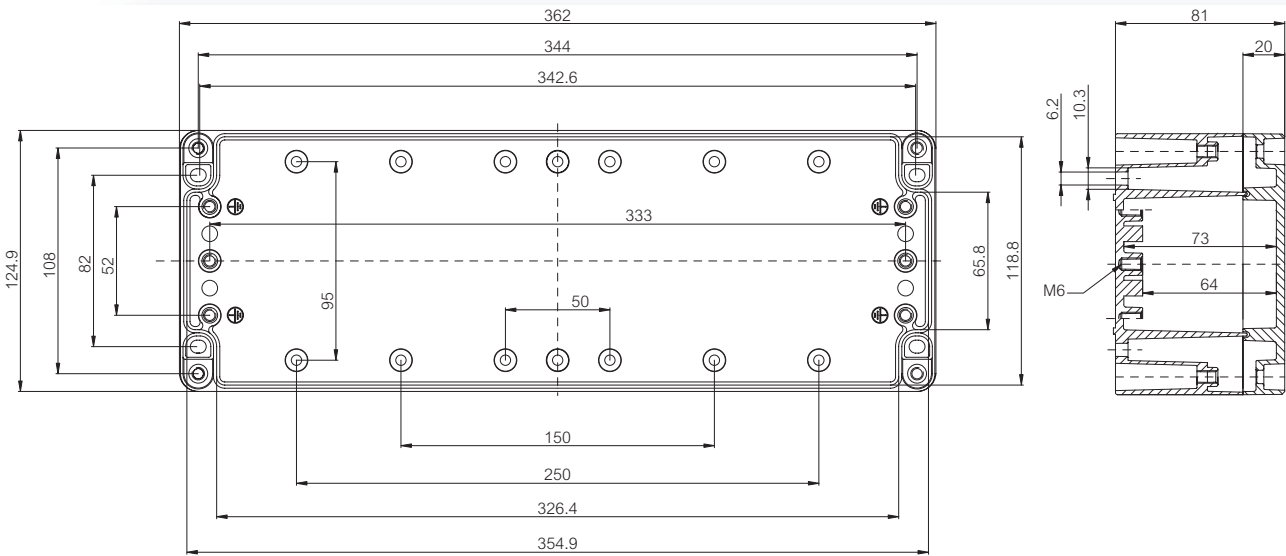



EURONORD

AL 1616

163 x 162

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 161609	7011270	163 x 162 x 91	Enclosure • Aluminium
ALC 161609	7021270	163 x 162 x 91	Enclosure • Aluminium "CLASSIC"

Accessories

Order symbol	Code	Dimensions	Description
AM 1616	9511149	146 x 146	Mounting plate
ARM 0615	9820011	15 x 140	DIN-15 Mounting rail
ARH 16	9822003	35 x 140	DIN-35 Mounting rail
MR 75005	7075005		Selftapping taptite screw M5
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

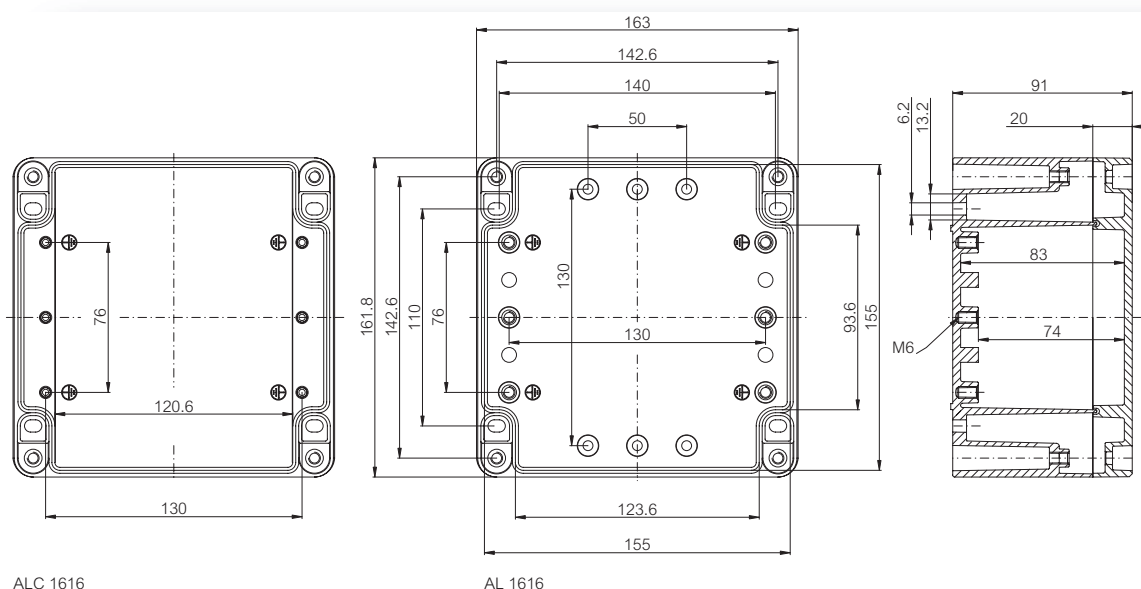

EURONORD

AL 1626

263 x 162


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with PUR gasket and ferritic stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 162609	7011290	263 x 162 x 91	Enclosure • Aluminium
ALC 162609	7021290	263 x 162 x 91	Enclosure • Aluminium "CLASSIC"

Accessories			
Order symbol	Code	Dimensions	Description
AM 1626	9511096	146 x 244	Mounting plate
ARM 0825	9820019	15 x 240	DIN-15 Mounting rail
ARH 26	9822011	35 x 240	DIN-35 Mounting rail
MR 75005	7075005		Selftapping tapite screw M5
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

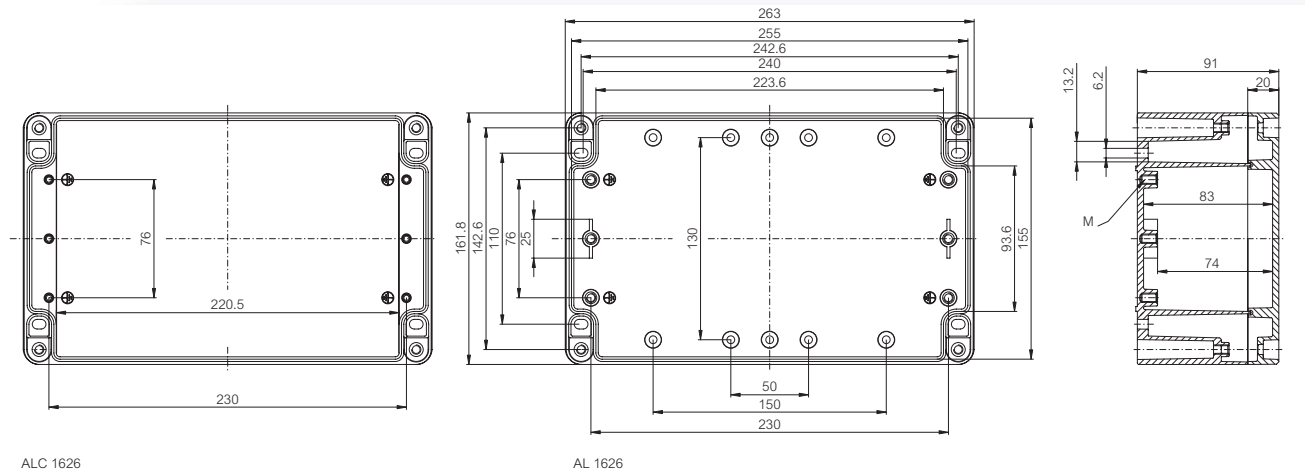



EURONORD AL 1636

360 x 160

AL: IP 66/IP 67, IK 08

Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.


Enclosures

Order symbol	Code	Dimensions	Description
AL 163609	7011310	360 x 160 x 90	Enclosure ▪ Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 1636	9511175	146 x 346	Mounting plate
ARH 1636	9822029	35 x 340	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

FIBOX Aluminium AL 163609

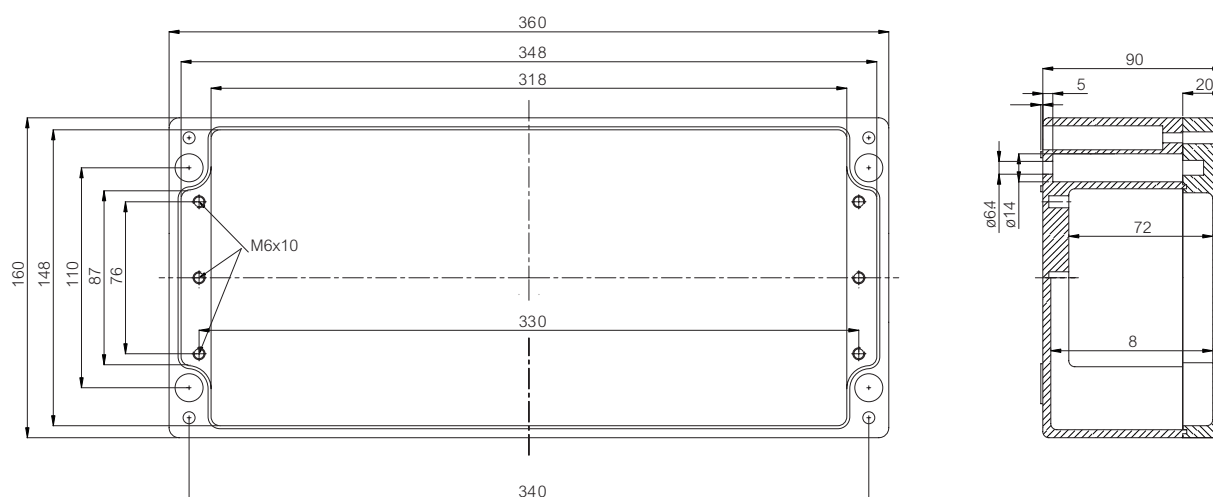

EURONORD

AL 1656


560 x 160

AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 165609	7011330	560 x 160 x 90	Enclosure ▪ Aluminium
Accessories			
Order symbol	Code	Dimensions	Description
AM 1656	9511014	146 x 545	Mounting plate
ARH 1656	9822018	35 x 540	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

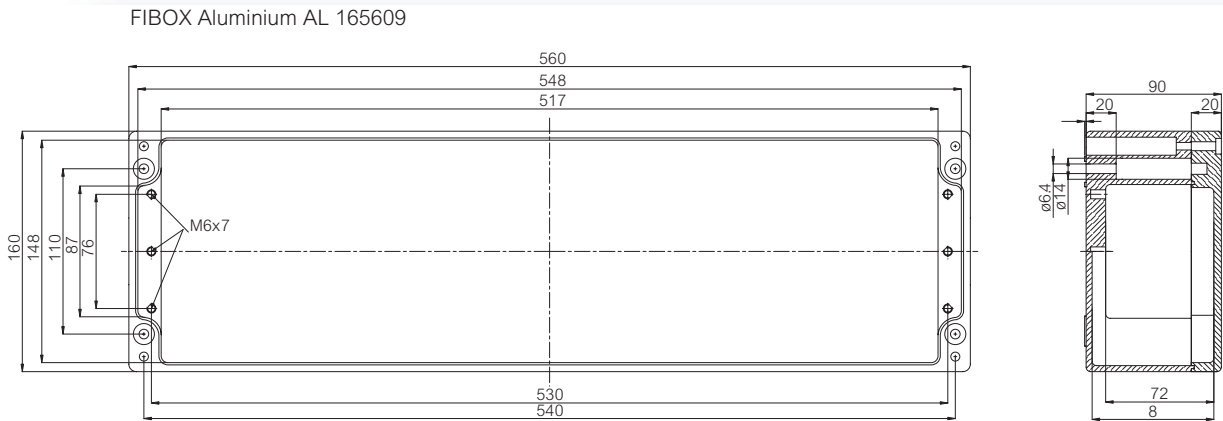



EURONORD AL 2320

230 x 200

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 232011	7011350	230 x 200 x 110	Enclosure • Aluminium
AL 232018	7011360	230 x 200 x 180	Enclosure • Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 2320	9511015	215 x 184	Mounting plate
ARH 2320	9822005	35 x 180	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

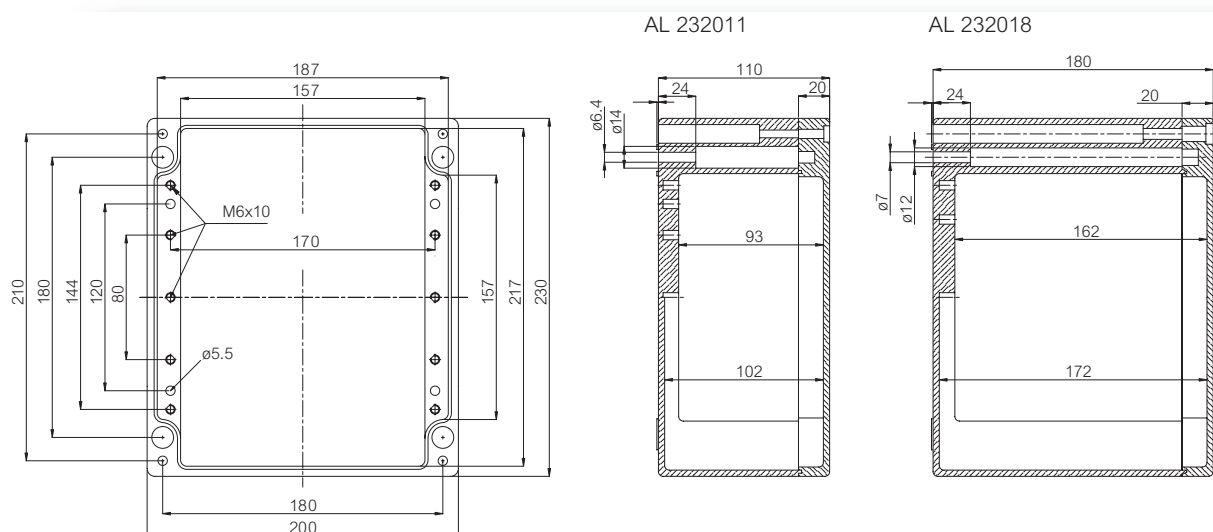

EURONORD

AL 2328

280 x 230


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 232811	7011370	280 x 230 x 110	Enclosure • Aluminium
Accessories			
Order symbol	Code	Dimensions	Description
AM 2328	9511016	215 x 264	Mounting plate
ARH 2328	9822012	35 x 260	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

FIBOX ALUMINIUM AL 232811

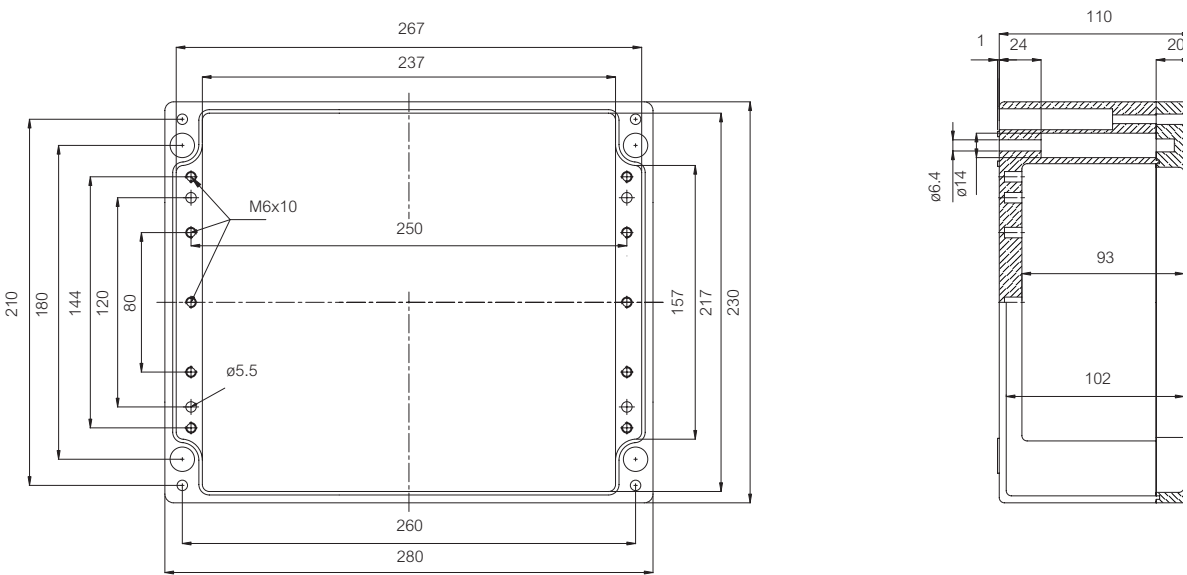



EURONORD AL 2333

330 x 230

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 233311	7011380	330 x 230 x 110	Enclosure • Aluminium
AL 233318	7011390	330 x 230 x 180	Enclosure • Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 2333	9511017	215 x 315	Mounting plate
ARH 2333	9822014	35 x 310	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

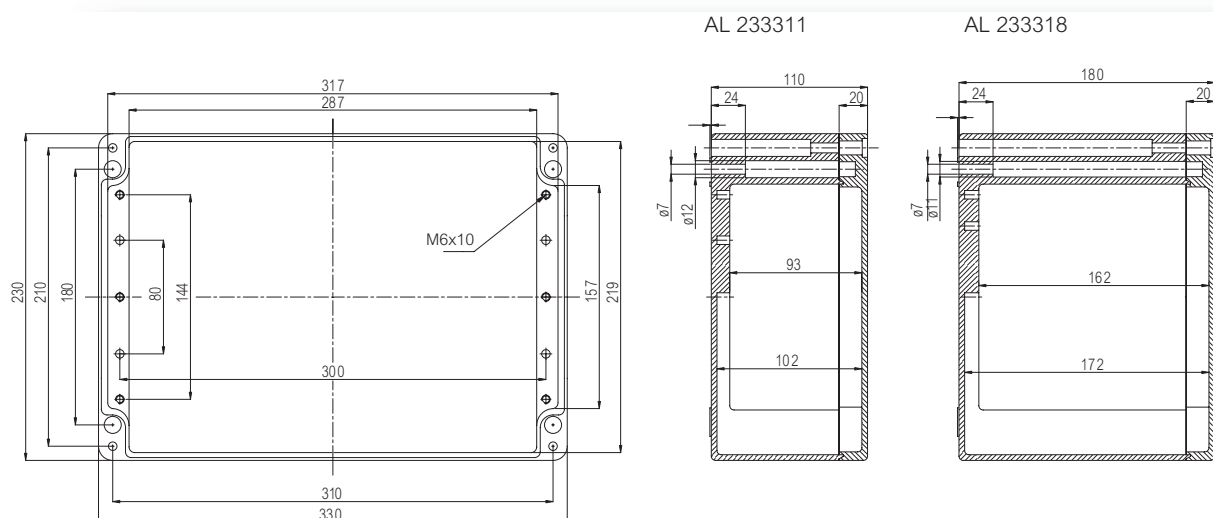

EURONORD

AL 2340

401 x 230


AL: IP 66/IP 67, IK 08



Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
AL 234011	7011400	401 x 230 x 110	Enclosure • Aluminium

Accessories			
Order symbol	Code	Dimensions	Description
AM 2340	9511018	215 x 385	Mounting plate
ARH 40	9822017	35 x 383	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

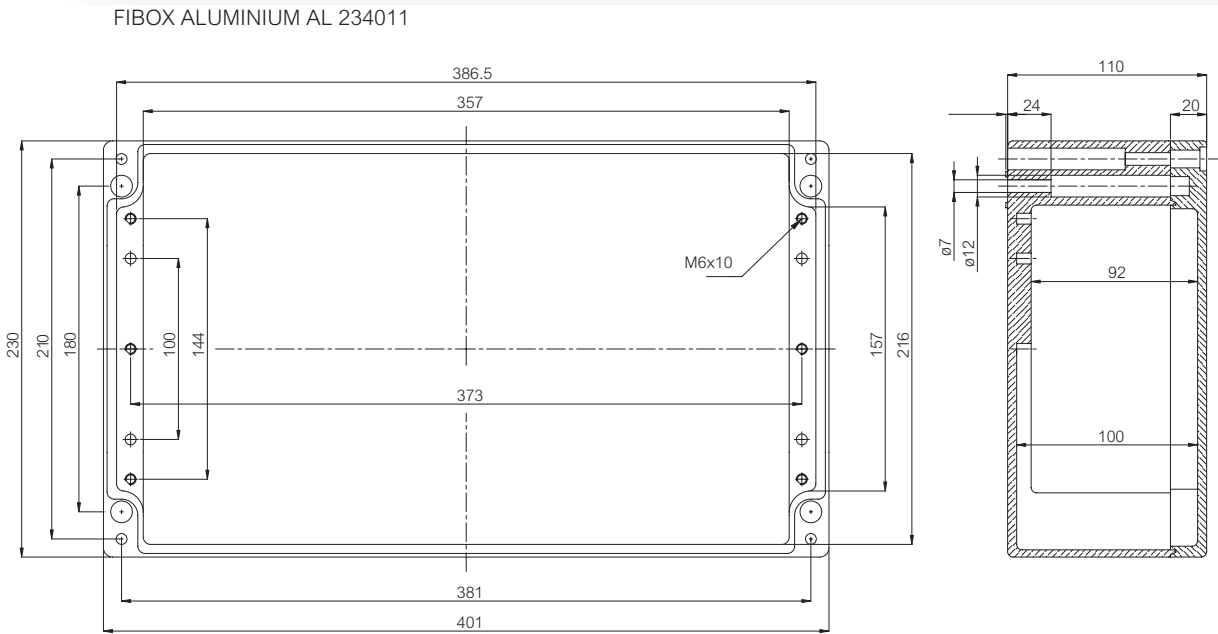



EURONORD AL 2360

600 x 230

AL: IP 66/IP 67, IK 08

Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.


Enclosures

Order symbol	Code	Dimensions	Description
AL 236011	7011420	600 x 230 x 110	Enclosure ▪ Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 2360	9511019	215 x 586	Mounting plate
ARH 60	9822019	35 x 580	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

FIBOX ALUMINIUM AL 236011

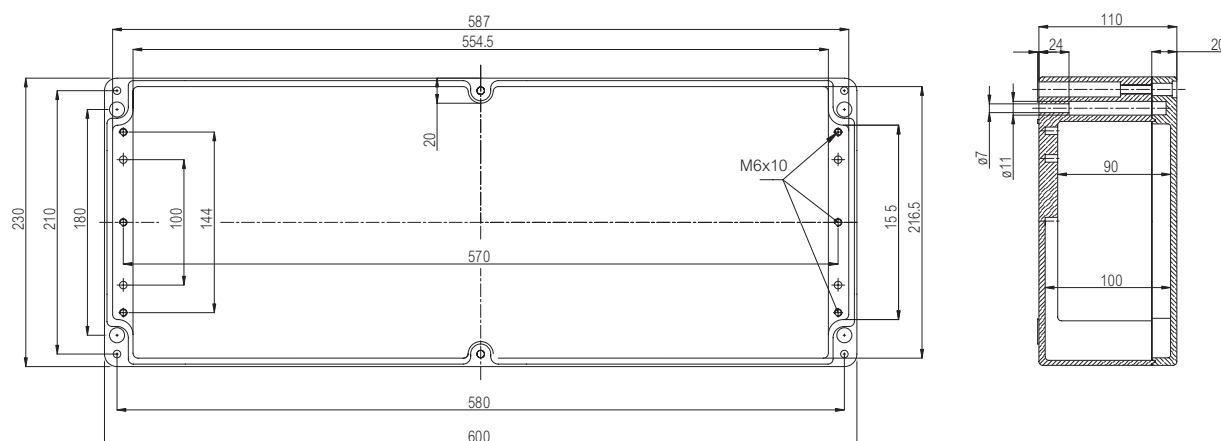

EURONORD

AL 3140

403 x 310

AL: IP 66/IP 67, IK 08




Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 314011	7011450	403 x 310 x 110	Enclosure • Aluminium
AL 314018	7011460	403 x 310 x 180	Enclosure • Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 3140	9511020	294 x 387	Mounting plate
ARH 40	9822017	35 x 383	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

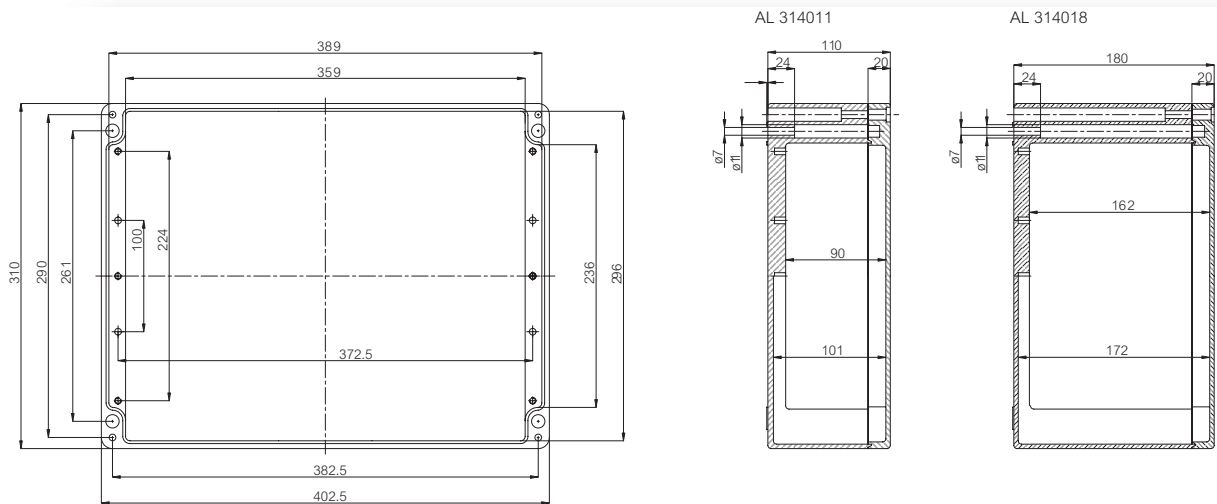



EURONORD AL 3160

600 x 310

AL: IP 66/IP 67, IK 08


Including: Base with screws for mounting plate/DIN-rail, cover with neoprene gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
AL 316011	7011470	600 x 310 x 110	Enclosure • Aluminium
AL 316018	7011480	600 x 310 x 180	Enclosure • Aluminium

Accessories

Order symbol	Code	Dimensions	Description
AM 3160	9511021	293 x 585	Mounting plate
ARH 60	9822019	35 x 580	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

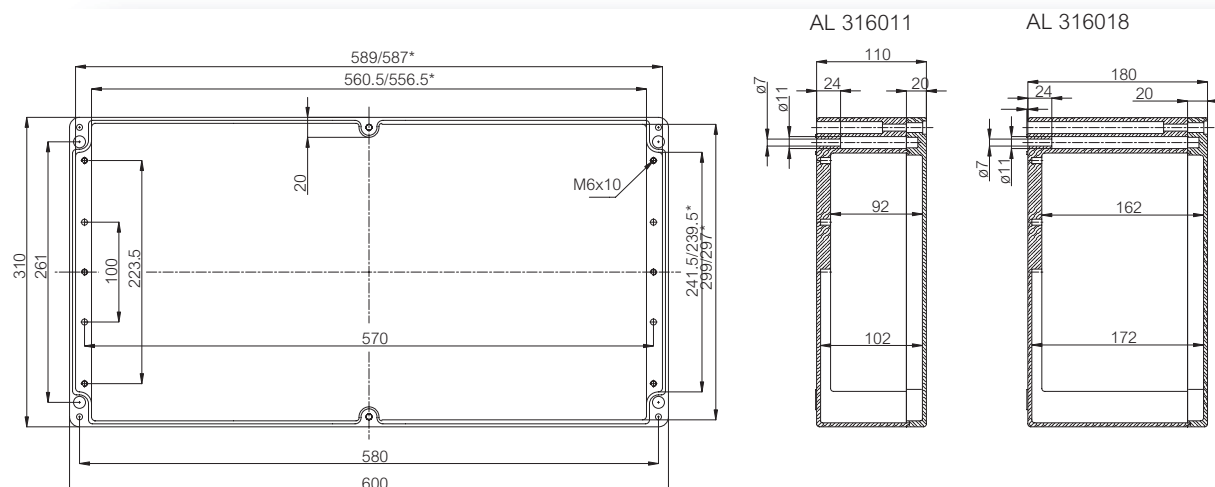

AL ACCESSORIES

Order symbol	Code	Description
--------------	------	-------------

Mounting plates (Galvanized steel, sheet thickness 1,5 mm)

AM 0808	9823015	69 x 64
AM 0813	9511043	69 x 114
AM 0818	9823017	69 x 164
AM 0825	9511007	69 x 240
AM 1212	9511150	107 x 110
AM 1222	9511095	107 x 207
AM 1236	9511174	107 x 347
AM 1616	9511149	146 x 146
AM 1626	9511096	146 x 244
AM 1636	9511175	146 x 346
AM 1656	9511014	146 x 545
AM 2320	9511015	215 x 184
AM 2328	9511016	215 x 264
AM 2333	9511017	215 x 315
AM 2340	9511018	215 x 385
AM 2360	9511019	215 x 586
AM 3140	9511020	294 x 387
AM 3160	9511021	293 x 585

DIN-15 Mounting rails (Galvanized steel, rail height 5,0 mm)

ARM 0808	9820002	15 x 65
ARM 0610	9820005	15 x 88
ARM 0813	9820010	15 x 115
ARM 0615	9820011	15 x 140
ARM 0818	9820014	15 x 165
ARM 0825	9820019	15 x 240

DIN-35 Mounting rails (Galvanized steel, rail height 7,5 mm)

ARH 12	9822001	35 x 105
ARH 16	9822003	35 x 140
ARH 2320	9822005	35 x 180
ARH 22	9822007	35 x 203
ARH 26	9822011	35 x 240
ARH 2328	9822012	35 x 260
ARH 2333	9822014	35 x 310
ARH 1636	9822029	35 x 340
ARH 36	9822015	35 x 343
ARH 40	9822017	35 x 383
ARH 1656	9822018	35 x 540
ARH 60	9822019	35 x 580

Hinges and wall mounting



PH A & AH A/B	9801047	Hinge set
MRS 28545WH	7028545	Wire hinge • one pair with screw, M6x30
MRS 28540	7028540	Wall fastening lug (2 pcs) • incl. screws
MRS 28541	7028541	Wall fastening lug (2 pcs) • incl. screws

Cover screws

MR 10425	7010425	Cover screw M4 • stainless
MR 10635	7010635	Cover screw M6 • stainless

Mounting and earth screws

MR 28548ZN	7028548	Mounting screw M4x6
MR 28549ZN	7028549	Mounting screw M6x8
MR 75003	7075003	Selftapping taptite screw M3
MR 75005	7075005	Selftapping taptite screw M5
MR 28550	7028550	Earth screw • for AL 050503
MR 28546CU	7010408	Earth screw • for small AL-enclosures up to 0825
MR 28547CU	7010610	Earth screw • for big AL-enclosures from 1212
MRS 28546	7028546	Earth screw set (2 pcs)
MRS 38546	7038546	Screw set for small AL-enclosures up to 0825 • incl. 2 earth and 4 mounting screws
MRS 38547	7038547	Screw set for big AL-enclosures from 1212 • incl. 2 earth and 4 mounting screws

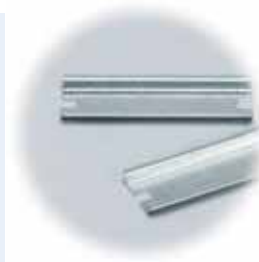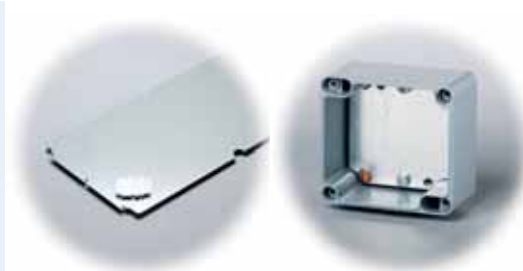

EURONORD AL technical information

Property	Aluminium
Ingress Protection (EN 60529)	IP 66/IP 67
Impact Resistance (EN 62262)	IK 08
Temperature Range Celsius	-50° . . 140°C
(short term) Fahrenheit	-60 . . 285°F
Temperature Range Celsius	-50° . . 80°C
(continuous) Fahrenheit	-60° . . 175°F
Polyester powder paint colour	RAL 7001
Cover Screws (0505 - 1626)	Ferritic Stainless Steel
Cover Screws (1636 - 3160)	Stainless steel
Gasket	PUR
Chemical Resistance *	Good

Data subject to change without notice.

*Consult separate raw material data for more detailed information

Confirmity to standards

USA Enclosures for Electrical Equipment
UL Type 1, 4, 4X, 12 or 13; UL File E75645 Vol 1 Sec 6

Canada Industrial Control Equipment
Enclosures for Electrical Equipment/ULc

Europe Empty enclosures for low-voltage switchgear and
controlgear assemblies EN 62208:2003 (50298:1998)

Europe Safety of Information Technology Equipment EN
60950
RoHS directive 2002/95/EC

EURONORD

P 0808

80 x 75


P: IP 66/IP 67, IK 08



Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
P 080806	7094140	80 x 75 x 55	Enclosure • Polyester

Accessories			
Order symbol	Code	Dimensions	Description
PM 0808	9823000	64 x 69	Mounting plate
TRM 0808	9820004	15 x 68	DIN-15 Mounting rail
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

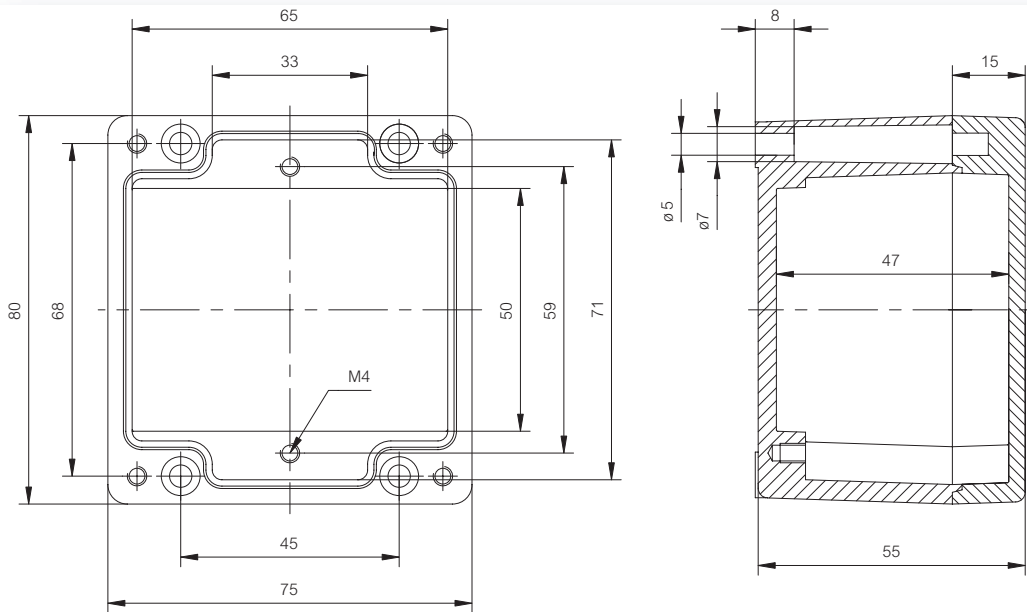



EURONORD

P 0811

110 x 75

P: IP 66/IP 67, IK 08


Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 081106	7094150	110 x 75 x 55	Enclosure • Polyester

Accessories

Order symbol	Code	Dimensions	Description
PM 0811	9823001	64 x 99	Mounting plate
PRM 0811	9820006	15 x 99	DIN-15 Mounting rail
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

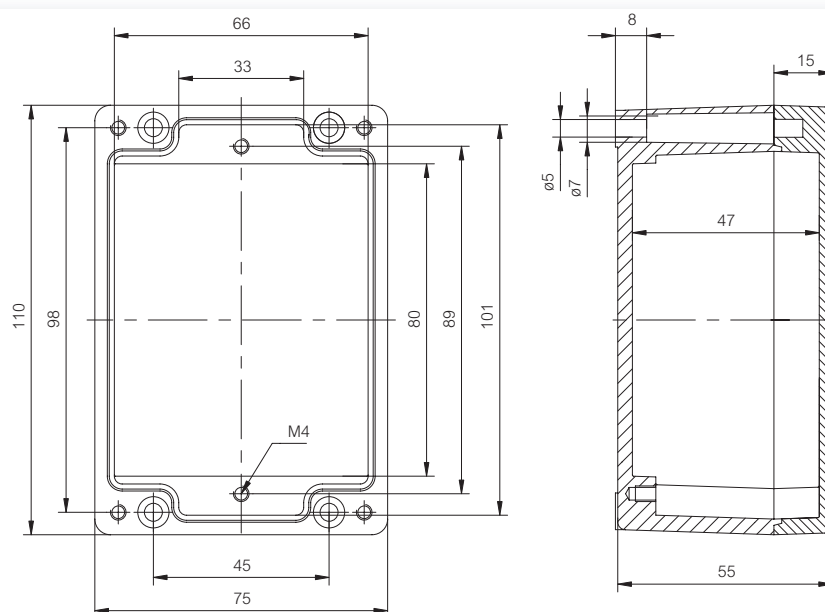

EURONORD

P 0816

160 x 75


P: IP 66/IP 67, IK 08



Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
P 081606	7094170	160 x 75 x 55	Enclosure • Polyester

Accessories			
Order symbol	Code	Dimensions	Description
PM 0816	9823002	64 x 149	Mounting plate
PRM 0816	9820012	15 x 149	DIN-15 Mounting rail
TRM 0816	9820013	15 x 146	DIN-15 Mounting rail
TRH 1216	9822028	35 x 146	DIN-35 Mounting rail
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

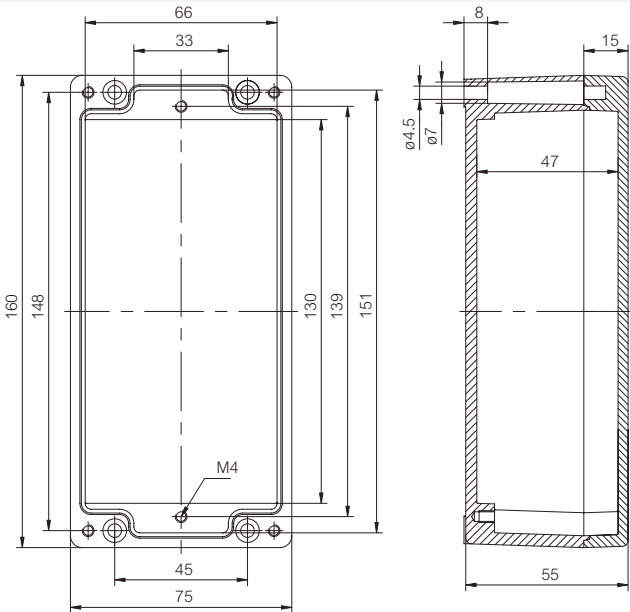



EURONORD

P 0819

190 x 75

P: IP 66/IP 67, IK 08


Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 081906	7094190	190 x 75 x 55	Enclosure • Polyester

Accessories

Order symbol	Code	Dimensions	Description
PM 0819	9823003	64 x 179	Mounting plate
PRM 0819	9820015	15 x 179	DIN-15 Mounting rail
MRS 28540	7028540	11 x 42	Wall fastening lug (2 pcs) • incl. screws

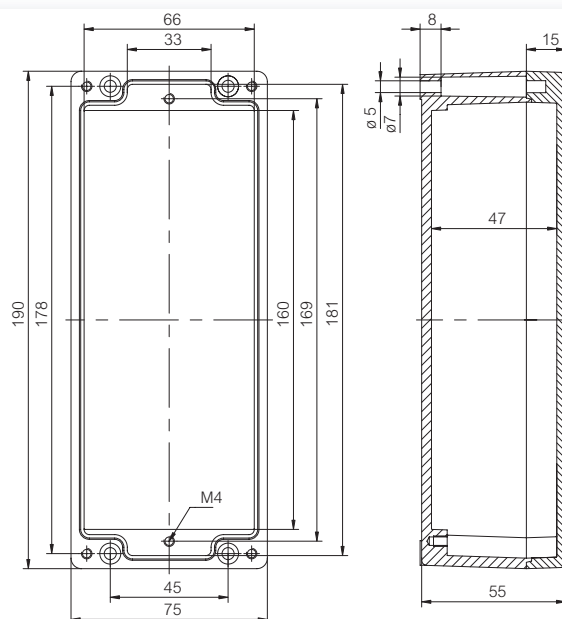

EURONORD

P 1212

122 x 120


P: IP 66/IP 67, IK 08



Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
P 121209	7094220	122 x 120 x 90	Enclosure • Polyester

Accessories			
Order symbol	Code	Dimensions	Description
AM 1212	9511150	107 x 110	Mounting plate
ARH 12	9822001	35 x 105	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

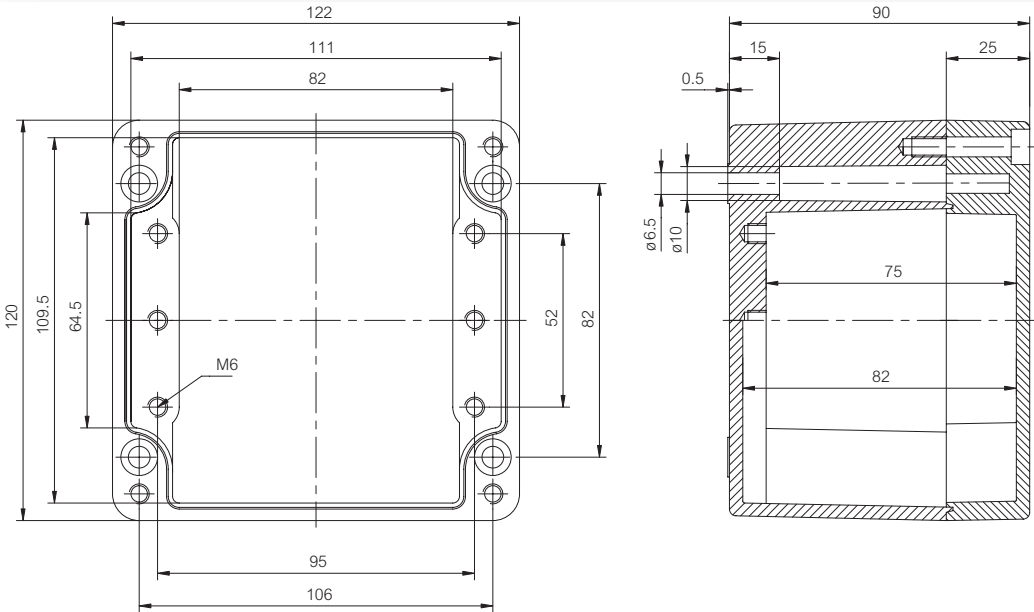



EURONORD

P 1222

220 x 120

P: IP 66/IP 67, IK 08


Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 122209	7094240	220 x 120 x 90	Enclosure • Polyester

Accessories

Order symbol	Code	Dimensions	Description
AM 1222	9511095	107 x 207	Mounting plate
ARH 22	9822007	35 x 203	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

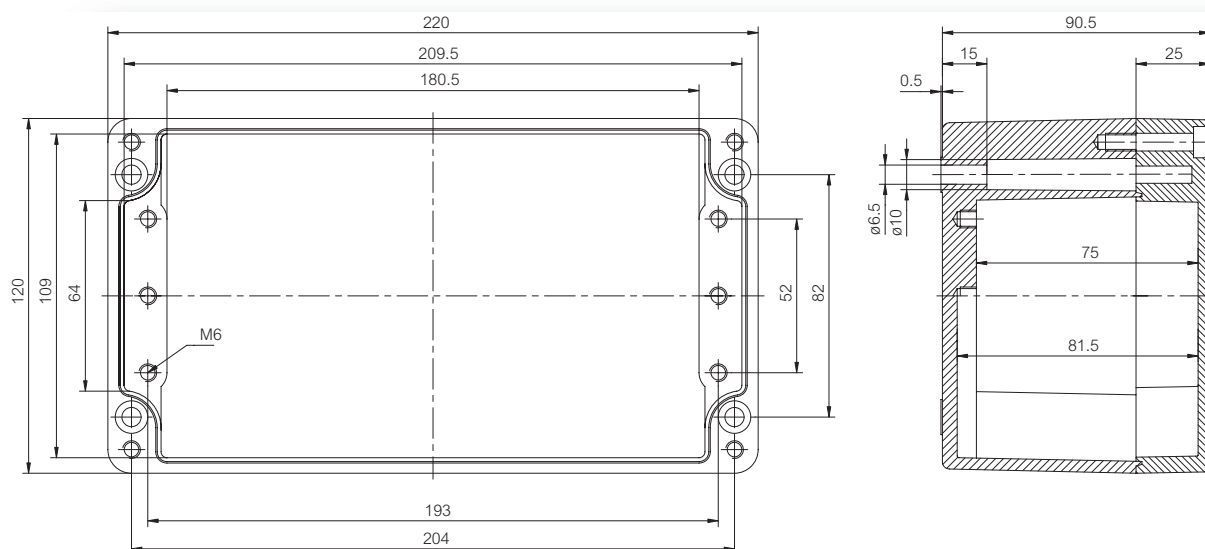

EURONORD

P 1616


160 x 160

P: IP 66/IP 67, IK 08



Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
P 161609	7094280	160 x 160 x 91	Enclosure • Polyester
Accessories			
Order symbol	Code	Dimensions	Description
PM 1616	9823006	146 x 146	Mounting plate
ARM 0615	9820011	15 x 140	DIN-15 Mounting rail
ARH 16	9822003	35 x 140	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

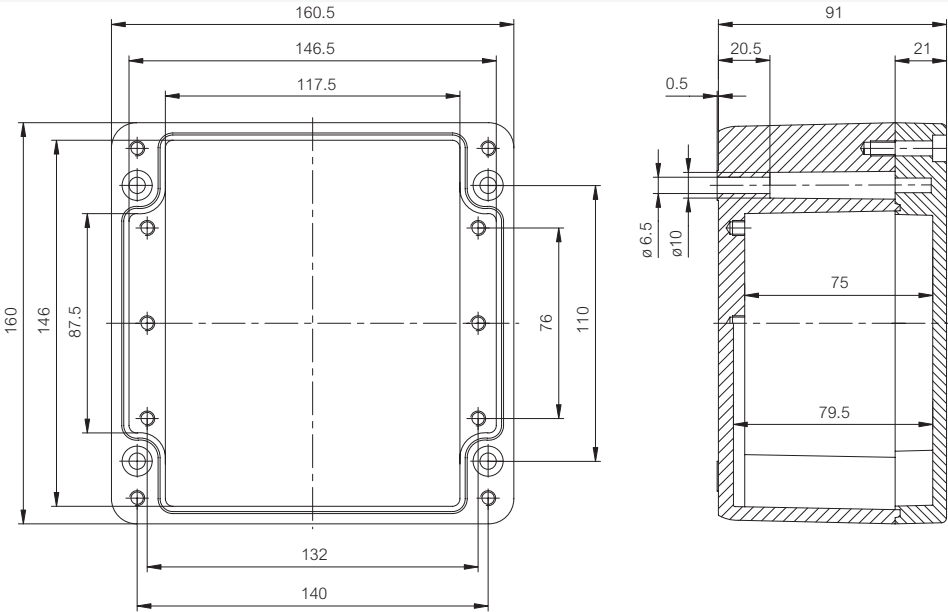



EURONORD

P 1626

260 x 160

P: IP 66/IP 67, IK 08


Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 162609	7094300	260 x 160 x 92	Enclosure ▪ Polyester

Accessories

Order symbol	Code	Dimensions	Description
PM 1626	9823007	146 x 244	Mounting plate
ARH 26	9822011	35 x 240	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

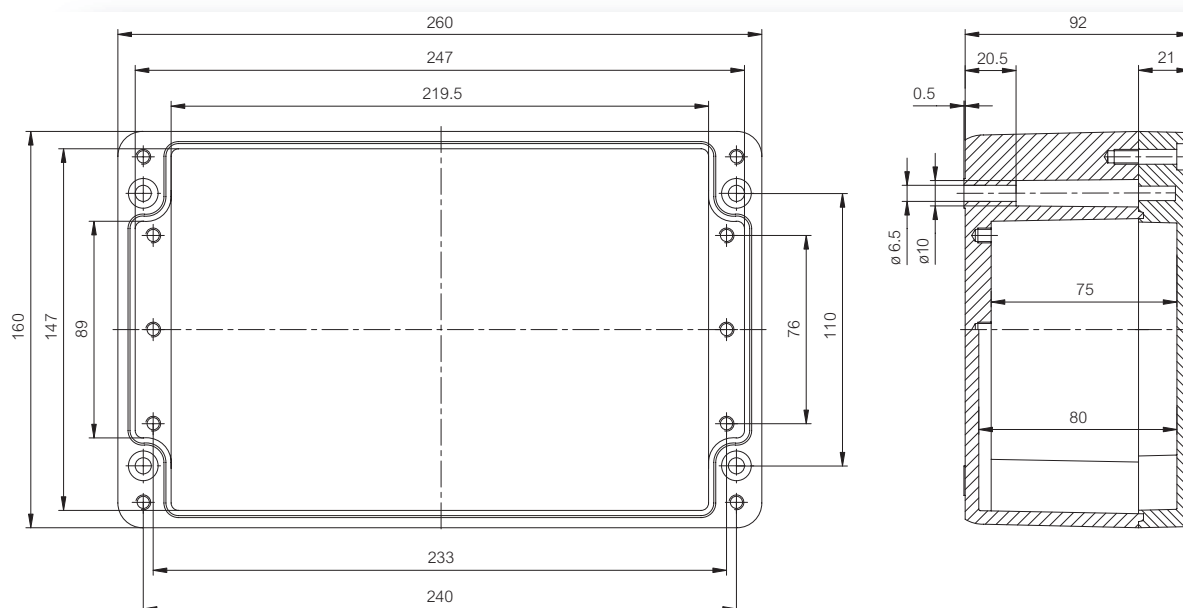

EURONORD

P 1636


361 x 160

P: IP 66/IP 67, IK 08



Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures			
Order symbol	Code	Dimensions	Description
P 163609	7094320	361 x 160 x 91	Enclosure • Polyester
Accessories			
Order symbol	Code	Dimensions	Description
AM 1236	9511174	107 x 347	Mounting plate
AM 1636	9511175	146 x 346	Mounting plate
ARH 36	9822015	35 x 343	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

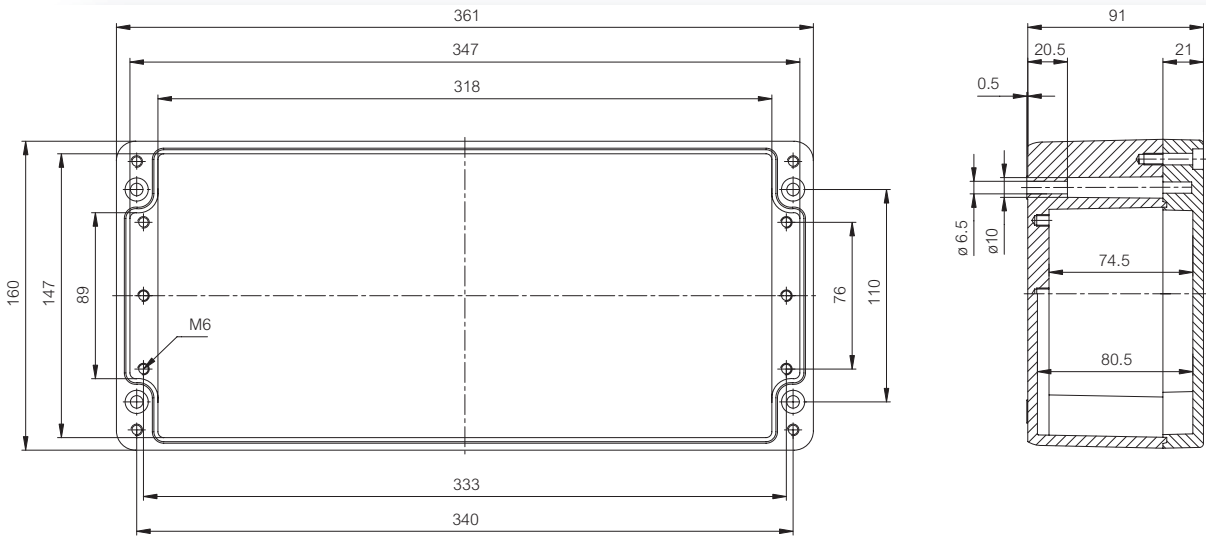



EURONORD

P 2526

256 x 251

P: IP 66/IP 67, IK 08


Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 252612	7094370	256 x 251 x 121	Enclosure ▪ Polyester

Accessories

Order symbol	Code	Dimensions	Description
PM 2526	9823009	231 x 240	Mounting plate
PRH 2526	9821007	35 x 238	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

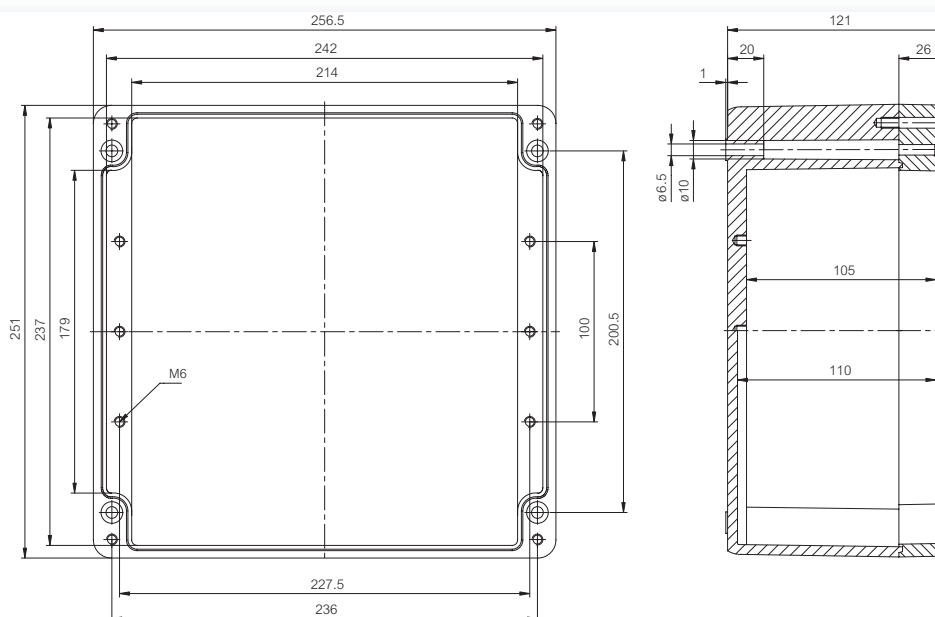

EURONORD

P 2540

402 x 250

P: IP 66/IP 67, IK 08




Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 254012	7094400	402 x 250 x 120	Enclosure • Polyester

Accessories

Order symbol	Code	Dimensions	Description
PM 2540	9823010	231 x 383	Mounting plate
AM 2340	9511018	215 x 385	Mounting plate
ARH 40	9822017	35 x 383	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) • incl. screws
PH A & AH A/B	9801047		Hinge set

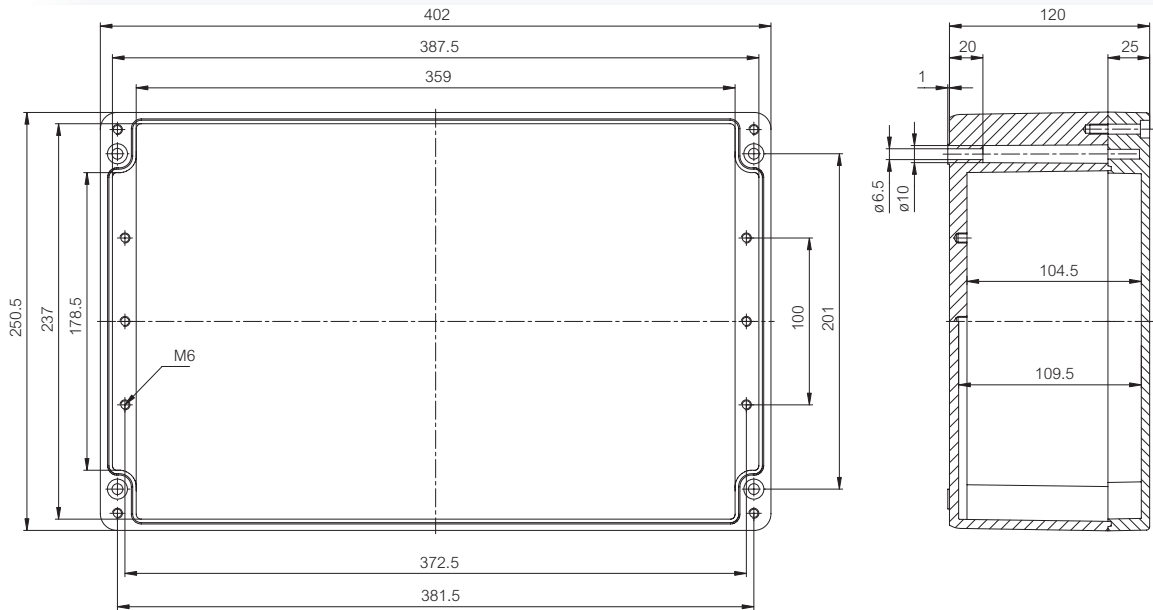



EURONORD

P 4040

406 x 401

P: IP 66/IP 67, IK 08


Including: Base, cover with EPDM gasket and stainless steel cover screws.

Enclosures

Order symbol	Code	Dimensions	Description
P 404012	7094450	406 x 401 x 120	Enclosure ▪ Polyester

Accessories

Order symbol	Code	Dimensions	Description
PM 4040	9823011	390 x 385	Mounting plate
ARH 40	9822017	35 x 383	DIN-35 Mounting rail
MRS 28541	7028541	15 x 50	Wall fastening lug (2 pcs) ▪ incl. screws
PH A & AH A/B	9801047		Hinge set

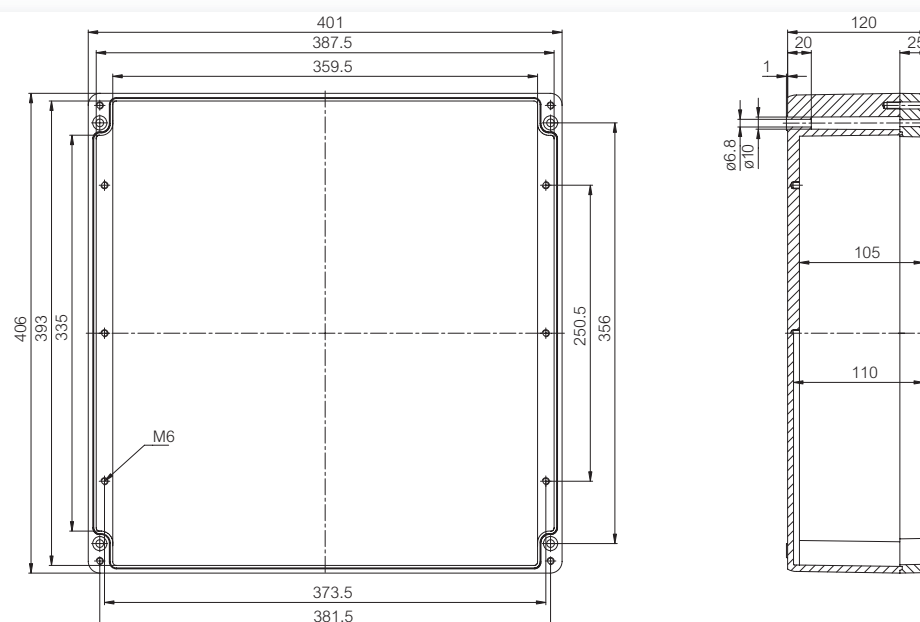

P ACCESSORIES

Order symbol	Code	Description
--------------	------	-------------

Mounting plates (Galvanized steel, sheet thickness 1,5 mm)

PM 0808	9823000	64 x 69
PM 0811	9823001	64 x 99
PM 0816	9823002	64 x 149
PM 0819	9823003	64 x 179
AM 1212	9511150	107 x 110
AM 1222	9511095	107 x 207
PM 1616	9823006	146 x 146
PM 1626	9823007	146 x 244
AM 1636	9511175	146 x 346
PM 2526	9823009	231 x 240
PM 2540	9823010	231 x 383
PM 4040	9823011	390 x 385

DIN-15 Mounting rails (Galvanized steel, rail height 5,0 mm)

TRM 0808	9820004	15 x 68
PRM 0811	9820006	15 x 99
ARM 0615	9820011	15 x 140
PRM 0816	9820012	15 x 149
PRM 0819	9820015	15 x 179

DIN-35 Mounting rails (Galvanized steel, rail height 7,5 mm)

ARH 12	9822001	35 x 105
ARH 16	9822003	35 x 140
ARH 22	9822007	35 x 203
PRH 2526	9821007	35 x 238
ARH 26	9822011	35 x 240
ARH 36	9822015	35 x 343
ARH 40	9822017	35 x 383

Hinges and wall mounting

PH A & AH A/B	9801047	Hinge set
MRS 28540	7028540	Wall fastening lug (2 pcs) • incl. screws
MRS 28541	7028541	Wall fastening lug (2 pcs) • incl. screws



EURONORD P technical information

Property	Polyester (GRP)
----------	-----------------

Ingress Protection (EN 60529)	IP 66/IP 67
Impact Resistance (EN 62262)	IK 08
Temperature Range Celsius	-50° . . .120°C
(short term) Fahrenheit	-60 . . . 250°F
Temperature Range Celsius	-40° . . .80°C
(continuous) Fahrenheit	-40° . . .175°F
Electrical Insulation	Totally insulated ☑
Colour	RAL 7001
Cover Screws	Stainless steel
Gasket	EPDM
Enclosure Flammability Rating	UL 94-5V
Glow Wire Test (IEC 695-2-1)	960°C
Self -extinguishing (PC)	
Non-toxicity	Halogen Free
Chemical Resistance *	Good

Data subject to change without notice.

*Consult separate raw material data for more detailed information

Confirmity to standards

USA Enclosures for Electrical Equipment
P: NEMA 1, 4, 4X, 12 or 13

Canada Industrial Control Equipment
Enclosures for Electrical Equipment/ULc

Europe Empty enclosures for low-voltage switchgear and
controlgear assemblies EN 62208:2003 (50298:1998)

Europe Safety of Information Technology Equipment
EN 60950

RoHS directive 2002/95/EC