

4-Port USB 2.0 Hub

GUH285W6



- 4 USB 2.0 ports for easy expansion
- Supports a high-speed data transfer rate
- Plug-n-Play, hot swappable

- Backward compatible with USB 1.1 specifications
- LEDs allow for easy status monitoring
- A - B cable tucks away when not in use
- 3 Year Limited Warranty


IOGEAR's 4-Port USB 2.0 Hub provides 4 Hi-Speed USB 2.0 ports for your USB connectivity needs. This device is USB 2.0 compliant and provides a high-speed data transfer rate. Compact and lightweight, the Hub is stylish and functional. The tuck-away USB cable design avoids cable clutter and makes the hub easy to carry and convenient to store. The side panel port design offers more convenience and flexibility. The Hub also supports USB 1.1 devices since it is backward compatible with USB 1.1 specifications. It is very easy to use, Plug-n-Play, and hot swappable. The Hub is backed by IOGEAR's 3 Year Limited Warranty.



4-Port USB 2.0 Hub

How does it work?

- Expand your computer with 4 USB 2.0 ports with data transfer speeds of up to 480 Mbps
- Easy cable management for convenient storage, designed to fit into any laptop carrying case

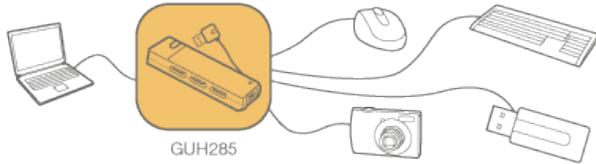

Product Requirements

- Windows® 2000, XP & Vista
- Mac OS X v10.3.9 or later
- Available USB port (USB 2.0 port for Hi-Speed mode)

Package Contents

- 1 x GUH285 - Hi-Speed USB 2.0 Hub
- 1 x Warranty / Registration Card

Specifications

Function	GUH285W6	Dimensions	GUH285W6
Data Rate	Up to 480 Mbps	POP Information	
Operating System Support	Windows 2K, XP, Vista / Mac OS X v10.3.9 or later	10" Peg Hook	12
LEDs		6" Peg Hook	8
Power On	Yes	Unit Dimensions	
Ports	4 USB 2.0 ports	Width	3.7 in.
Power		Height	0.35 in.
Amps	500 mAh/port	Length	1.18 in.
Operating Temperature	32°F ~ 113°F (0°C ~ 45°C)	Inner Pack	
Storage Temperature	14°F ~ 158°F (-10°C ~ 70°C)	Width	9.45 in.
USB Specification	USB 2.0/1.1/1.0 compliant	Height	6.85 in.
Cable Type	USB Type A	Depth	4.69 in.
		Inner Pack Qty.	12 pcs
		Unit Package Dimensions	
		Width	4.53 in.
		Height	6.3 in.
		Depth	0.87 in.
		Master Carton	
		Width	10.24 in.
		Height	8.11 in.
		Depth	10.4 in.
		Master Carton Qty.	24 pcs
		Weight	
		Master Carton Wt.	5.4 lbs
		Inner Pack Wt.	2.2 lbs
		Unit Pack Wt.	0.2 lb
		Unit Wt.	0.05 lb