
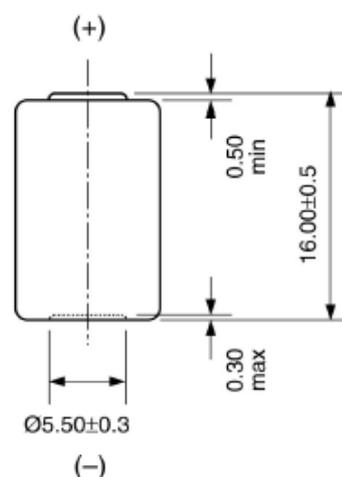


Model No.: **GP11A**

Description	: Alkaline High Voltage Battery
Nominal Voltage	: 6Volts
Nominal Dimensions	: Ø10.0mm×16.0mm
Terminal	: Nickel plated flat contacts - protruded red(+); recessed black (-)
Jacket	: Metal jacket
Internal Connection	: Pressure
Applications	: Remote controller
Average Weight	: 4.0g
Date Code	: Unless otherwise specified, each batteries will carry a numeric year code and analogue month code
Shelf Life	: Not less than 90% of the service capacity within first year. , not less than 85% of the service capacity with third year storage at 22 ± 3 °C 40-80 %RH
Insulation	: 5MΩ min.
Resistance	
Close Circuit Voltage	: 4.7 Volts (min.)(load resistor 200Ω at 22 ± 3 °C for 0.1 to 2 seconds)
Current Drain	: Under 15mA pulse, 0.5mA continuous
Nominal Service Life	: 74hrs (at 10kΩ load) (to 3.0V at 22 ± 3 °C)
Average Service Capacity	: 38mAh(at 10kΩ load) (to 3.0V at 22 ± 3 °C)


Cross References:

GP	Eveready	Duracell	Varta
11A	---	---	---

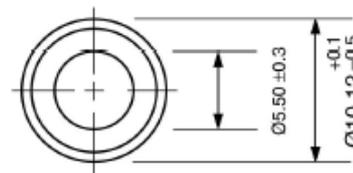

Unit : mm

Typical Discharge characteristics at 22 ± 3 °C

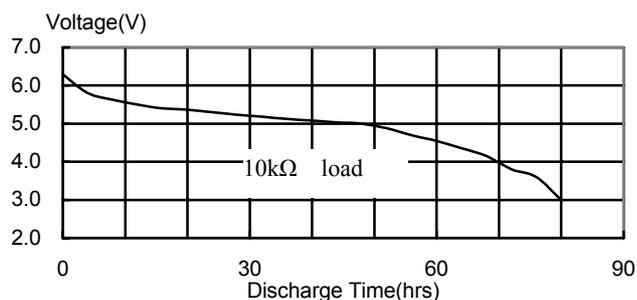

The information (subject to change without prior notice) contained in this document is for reference only and should not be used as a basis for product guarantee or warranty. For applications other than those described here, please consult your nearest GP Sales and Marketing Office or Distributors.