

Non-NEMA Twist-Lock® Devices


20 Ampere, 250, 125/250 Volts and 3ØY 120/208 Volts AC

Insulgrip® Plugs, Flanged Inlets, Connector Bodies and Receptacles



For Replacement Use Only

 IP20
SUITABILITY



20A 250V
Non-NEMA
Not UL Listed



20A 125/250V
Non-NEMA
Not UL Listed

Connector Bodies

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.360"-.930" (9-24)	HBL7314GCB	HBL7314C
Corrosion resistant, yellow nylon.	.360"-.930" (9-24)	—	HBL73CM14C

Note: See page B-51 for accessories.

Single Flush Receptacles

Description	Catalog Number
Black nylon face, back wired.	HBL7310BG HBL7310B

Note: See page B-50 for accessories.

Flanged Receptacles

Description	Catalog Number
Nylon casing, back wired.	— HBL3326C

Note: See page B-50 for accessories.

For Replacement Use Only

IP20
SUITABILITY



20A 3Ø 250V AC
Non-NEMA
Not UL Listed



20A 3Ø Y
120/208V AC
Non-NEMA
Not UL Listed

Connector Bodies

Description	Cord Dia.	Catalog Number	
Black and white nylon.	.350"-.1.150" (9-29)	HBL7413GCB	HBL7413C

Note: See page B-53 for accessories.

Single Flush Receptacles

Description	Catalog Number
Black urea face, back wired.	HBL7410BG HBL7410B
Mounted on a 4" (101.6) round metal cover.	— HBL7417B

Note: See page B-52 for accessories.

Flanged Receptacles


Description	Catalog Number
Nylon casing, back wired.	— HBL7409C

Note: See page B-52 for accessories.


The devices shown on this page are not listed by Underwriters Laboratories Inc. and are for replacement use only in existing installations.



HBL7314C

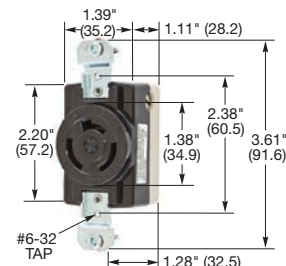


HBL7310B

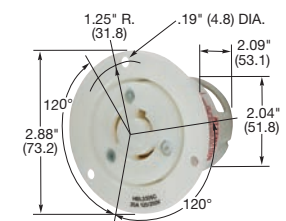


HBL3326C



HBL7413GCB

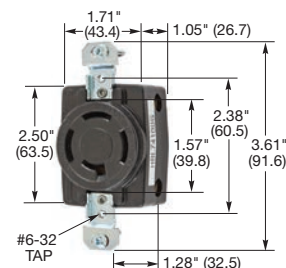

HBL7410BG

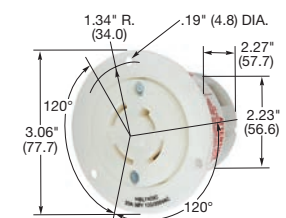

HBL7409C

Dimensions in Inches (mm)

CAUTION: To avoid electrical shock, review premises carefully and do not use if slot or blade configuration (design) is already in a circuit having a rating differing from the rating of this device.