

HandiMark® Label Maker Materials

www.BradyID.com/handimark

Portable Printers




Brady continues to manufacture and fully stock the complete range of labels and accessories for the HandiMark® Portable Label Maker!



Durable Tapes

Easy to load ribbons

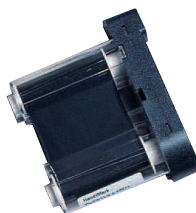

HandiMark® Printer Accessories

Catalog #	Description
42006	HandiMark AC Power Supply
TLSHM-QUICKCH	HandiMark Quick Charger
42008	Spare Battery (Std. Battery)
42007	Standard Battery Charger
42073	Super Charge (Quick charger and spare battery)
42072	Mega Charge (Quick charger, spare battery and AC Power Supply)
42009	Alcohol Cleaning Strips (5 per pkg.)
49199	Soft Case
42010	Spare Hard Carrying Case
42004	PC Connecting Cable


**Includes rechargeable battery & battery charger, hard carrying case, 1 roll of 2" sample tape, black ribbon, cleaning strip, tutorial and symbols reference chart.*

US Patent Numbers: 5,918,989; 5,951,177; 6,113,293; 6,142,686; D409,230

HandiMark® Print Ribbons

Super-tough, smear-proof, easy-to-load ribbons last for years outdoors.

Catalog #	Size	Color
42011	2" x 75' (51 mm x 23 m)	Black
42012	2" x 75' (51 mm x 23 m)	White
42013	2" x 75' (51 mm x 23 m)	Red
42014	2" x 75' (51 mm x 23 m)	Blue
42015	2" x 75' (51 mm x 23 m)	Green
42123	2" x 65' (51 mm x 20 m)	Yellow
42016	2" x 75' (51 mm x 23 m)	Magenta

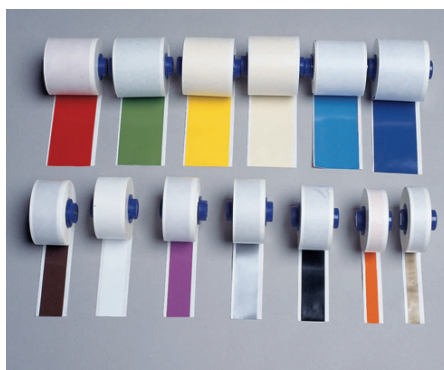

Outdoor Grade Vinyl Tape (B-595)

Labels adhere well to pipes, walls, equipment, doors and most clean, dry surfaces. Withstands temperatures from 180°F to -40°F

Catalog #	B-#	Color	Label Width Inch (mm)	Label Height Inch (mm)	Labels Per Roll
142269	B-595	White	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142270	B-595	White	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142271	B-595	White	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142272	B-595	Yellow	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142273	B-595	Yellow	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142274	B-595	Yellow	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142287	B-595	Black	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142288	B-595	Black	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142289	B-595	Black	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142281	B-595	Blue	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142282	B-595	Blue	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142283	B-595	Blue	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142302	B-595	Clear	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142303	B-595	Clear	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142304	B-595	Clear	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142296	B-595	Gold	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142297	B-595	Gold	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142298	B-595	Gold	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142275	B-595	Green	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142276	B-595	Green	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142277	B-595	Green	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142290	B-595	Gray	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142291	B-595	Gray	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142292	B-595	Gray	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142284	B-595	Orange	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142285	B-595	Orange	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142286	B-595	Orange	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)
142278	B-595	Red	0.500 (13.0)	50 ft. (15.2 m)	1 Roll (cont.)
142279	B-595	Red	1.000 (25.0)	50 ft. (15.2 m)	1 Roll (cont.)
142280	B-595	Red	2.000 (51.2)	50 ft. (15.2 m)	1 Roll (cont.)