



Alcoknobs *Machined Aluminum Series*

KFS SERIES

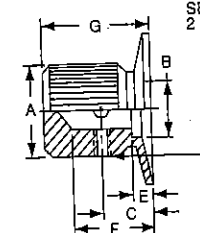

KFS400B1/8

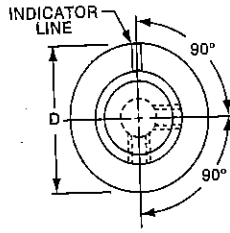

NO. 6-32
SET SCREW
2 PLACES,
EXCEPT
KFS400B1/8:
NO. 4-40
SET SCREW
2 PLACES


1/8" SHAFT=.126" (3.20)
1/4" SHAFT=.251" (6.38)

Straight Knurl with Indicator on Skirt								
Model	Color	A	B	C	D	E	F	G
KFS400B1/8	Black Matte	.380(9.65)	.382(9.70)	.256(6.50)	.500(12.7)	.098(2.49)	.469(11.9)	0.591(15.0)
KFS500B1/8	Black Matte	.500(12.7)	.382(9.70)	.252(6.48)	.630(16.0)	.161(4.09)	.469(11.9)	.630(16.0)
KFS600B1/8	Black Matte	.618(15.7)	.280(7.11)	.382(9.70)	1.00(25.4)	.161(4.09)	.630(16.0)	0.811(20.6)



KHF SERIES



KHF500A1/4

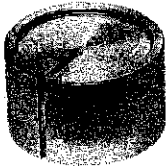

KHF900A1/4

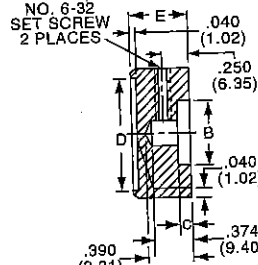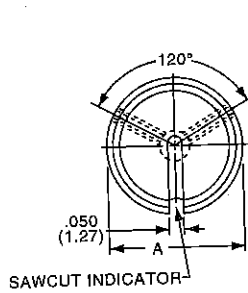



1/8" SHAFT=.126" (3.20)
1/4" SHAFT=.251" (6.37)

Plain Body with Top and Side Sawcut Indicator						
Model	Color	A	B	C	D	E
KHF500A1/4	Natural	.500(12.7)	.374(9.50)	.118(3.00)	.342(8.69)	.563(14.3)
KHF700A1/4	Natural	.740(18.8)	.590(15.0)	.118(3.00)	.592(15.0)	.563(14.3)
KHF900A1/4	Natural	.937(23.8)	.708(18.0)	.118(3.00)	.779(19.8)	.563(14.3)
KHF1250A1/4	Natural	1.23(31.8)	.984(25.0)	.118(3.00)	1.08(27.5)	.563(14.3)

KLN SERIES



KLN500A1/4

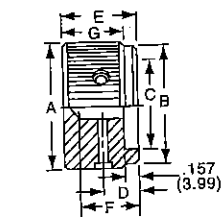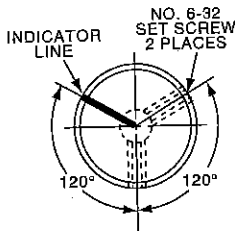

1/8" SHAFT=.126" (3.20)
1/4" SHAFT=.251" (6.38)

Straight Knurl with Top and Side Indicator								
Model	Color	A	B	C	D	E	F	G
KLN500A1/8	Natural	.500(12.7)	0.445(11.3)	.374(9.50)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN500A1/4	Natural	.500(12.7)	0.445(11.3)	.374(9.50)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN500B1/8	Black	.500(12.7)	0.445(11.3)	.374(9.50)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN500B1/4	Black	.500(12.7)	0.445(11.3)	.374(9.50)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN500S1/8	Smoke	.500(12.7)	0.445(11.3)	.374(9.50)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN500S1/4	Smoke	.500(12.7)	0.445(11.3)	.374(9.50)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN700A1/4	Natural	.740(18.8)	.685(17.4)	.591(15.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN700B1/4	Black	.740(18.8)	.685(17.4)	.591(15.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN700S1/4	Smoke	.740(18.8)	.685(17.4)	.591(15.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN900A1/4	Natural	.937(23.8)	.882(22.4)	0.709(18.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN900B1/4	Black	.937(23.8)	.882(22.4)	0.709(18.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN900S1/4	Smoke	.937(23.8)	.882(22.4)	0.709(18.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN1250A1/4	Natural	1.25(31.8)	1.20(30.5)	.984(25.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN1250B1/4	Black	1.25(31.8)	1.20(30.5)	.984(25.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)
KLN1250S1/4	Smoke	1.25(31.8)	1.20(30.5)	.984(25.0)	.281(7.14)	.625(15.9)	.512(13.0)	.527(13.4)

Thomas & Betts

Quality & Innovation From **AUGAT**® Name Brand Products