


Hook Clamp

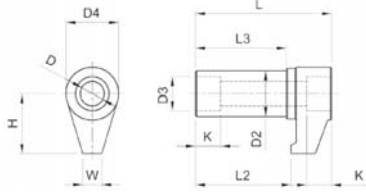

Material
 Steel, supplied with spring.
 Technical Notes
 Suitable hole tolerance H7

489231

d (mm)	h (mm)	w (mm)	d2 (mm)	d4 (mm)	d3 (mm)	l2 (mm)	L (mm)	l3 (mm)	k (mm)	Order Code	Price Each
M8	18	10	16	19	13	21	36	19	11	137-8312	
M10	25	8	19	22	14	40	57	38	14	137-8311	
M12	25	15	25	26	19	36	57	34	19	137-8310	
M16	35	15	28	28	22	45	70	43	16	137-8309	