

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [35407-6902](#)
Status: **Active**
Description: 2.28mm Sealed Terminal, Female, 2.00mm² AVSS, 0.25mm Material Thickness, Pre-Tin Plated

Documents:
[Drawing \(PDF\)](#)
[Product Specification PS-35408-001 \(PDF\)](#)
[Product Specification PS-35519-001 \(PDF\)](#)
[Packaging Specification PK-35407-003 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Crimp Terminals
Series	35407
Application	Power
Crimp Quality Equipment	Yes
Product Name	N/A
UPC	800756579245

Physical

Gender	Female
Material - Metal	High Performance Alloy (HPA)
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.320/g
Packaging Type	Reel
Plating min - Mating	0.813µm
Plating min - Termination	0.813µm
Termination Interface: Style	Crimp or Compression
Wire Insulation Diameter	1.90mm max.
Wire Size AWG	14
Wire Size mm²	N/A

Material Info

Reference - Drawing Numbers

Packaging Specification	PK-35407-003
Product Specification	PS-35408-001, PS-35519-001
Sales Drawing	SD-35407-001

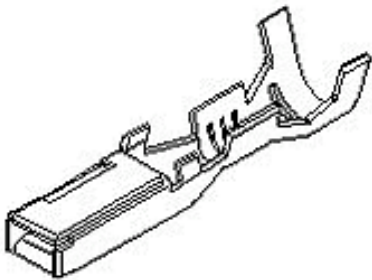


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[35407Series](#)

Mates With
[35420](#)

Use With
[35825](#)