


T-Nuts

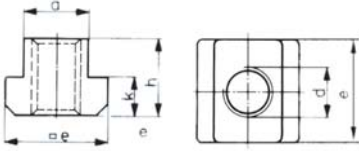

Material
Heat-treated steel, to tensile strength class 10.

Technical Notes
Please note T-Nuts are square, length and width are both equal to dimension e.

489286

Bolt Diameter x T-slot (mm)	A (mm)	E (mm)	H (mm)	K (mm)	Order Code	Price Each
M8 x 10	9.7	15	12	6	137-8406	
M8 x 12	11.7	18	14	7	137-8404	
M10 x 12	11.7	18	14	7	137-8403	
M12 x 14	13.7	22	16	8	137-8402	
M12 x 16	15.7	25	18	9	137-8401	
M14 x 16	15.7	25	18	9	137-8400	
M12 x 18	17.7	28	20	10	137-8398	
M16 x 18	17.7	28	20	10	137-8397	
M16 x 20	19.7	32	24	12	137-8396	
M16 x 22	21.7	35	28	14	137-8395	
M20 x 22	21.7	35	28	14	137-8394	
M20 x 24	23.7	40	32	16	137-8393	
M24 x 28	23.7	44	36	18	137-8392	