



Celestion Gold

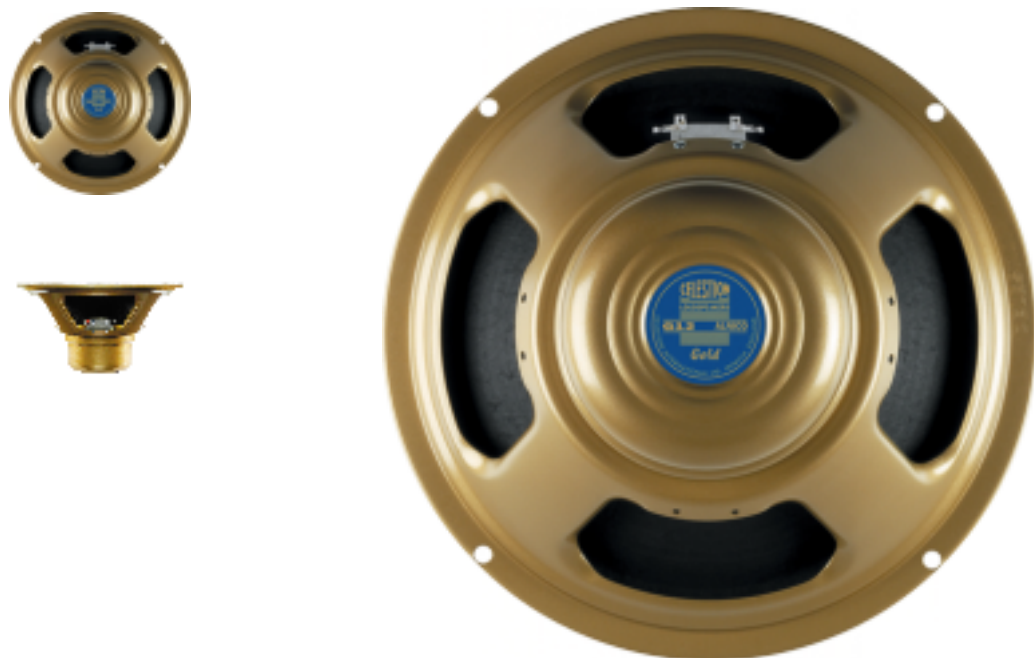

Building on the platform of the Blue, the Gold is a higher-powered, Alnico-magnet speaker that recreates the unmistakable sonic signature of a 'well played-in' original. Over time, the high frequencies of a Blue soften and become less chalky as the cone becomes more flexible – a much sought after characteristic that the Gold exhibits straight out of the box. Also present in the Gold sound from the outset is an added warmth and complexity in the midrange which, coupled with the classic Alnico qualities of a laid-back attack, rounded low end and brilliant bell-like highs, deliver huge rhythm voicings and saturated vocal lead tones.

The Gold is a wonderfully expressive and revealing loudspeaker, affording guitarists an unprecedented degree of dynamic control. It has already become a favourite for many working players worldwide whether picking and bending with Brad Paisley, or rocking hard with Danny Spitz of Anthrax.

8 Frequency Response

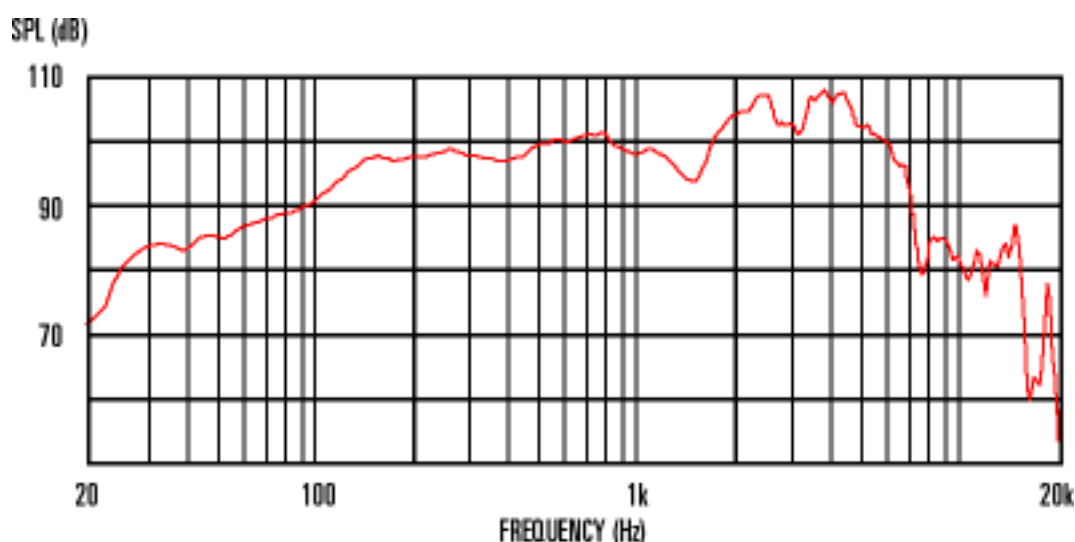

General Specifications

Nominal diameter	12", 305mm
Power rating	50Wrms
Nominal impedance	Available 8 or 15
Sensitivity	100dB
Chassis type	Pressed steel
Voice coil diameter	1.75", 44.5mm
Voice coil material	Round copper
Magnet type	Alnico
Frequency range	75-5000Hz
Resonance frequency, Fs	75Hz
DC resistance, Re	Available 6.4 or 11.8

Mounting Information

Cut-out diameter	11.1", 283mm
Diameter	12.2", 309mm
Magnet structure diameter	5.0", 128mm
Mounting slot dimensions	0.31", 7.9mm Ø
Mounting slot PCD	11.7", 297mm
Number of mounting slots	4
Overall depth	6.5", 165mm
Unit weight	9.3lb, 4.2kg