

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19160-0009](#)
Status: **Active**
Overview: [Splices](#)
Description: Closed-End Insulated Splice for 12-22 AWG Wire

Documents:
[Drawing \(PDF\)](#) [Packaging Specification PK-19408-109 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA	LR18689
UL	E32244

General

Product Family	Splices
Series	19160
Crimp Quality Equipment	Yes
Mil-Spec	N/A
MolexKits	Yes
Overview	Splices
Product Name	Closed-End Insulated
UPC	800753110182

Physical

Barrel Type	Closed
Color - Resin	Natural
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	0.689/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	6.86mm max.
Wire Size AWG	12, 14, 16, 18, 20, 22

Electrical

Voltage - Maximum	600V
-------------------	------

Material Info

Old Part Number	NC-2212
-----------------	---------

Reference - Drawing Numbers

Packaging Specification	PK-19408-109
Product Specification	PS-19902-013
Sales Drawing	SD-19160-001

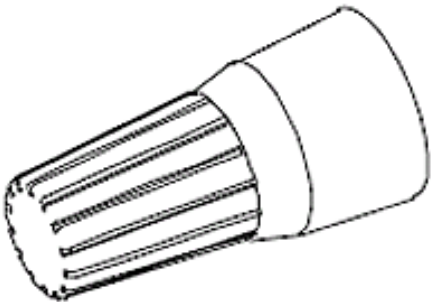


image - Reference only

Series

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19160Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Hand Crimp Tool	0640010900
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640050900
Crimp Head for the AT-200™ Pneumatic Hand Tool	0640053600