














Industrial Portfolio Changes

	Type	Brand	Size	Bulb	Action
	1151	Energizer Industrial	2AA	Krypton	Upgrade to LED Re-Brand to Eveready, Bulk Pk New Type: 1151L
	1251	Energizer Industrial	2D	Krypton	Upgrade to LED Re-Brand to Eveready, Bulk Pk New Type: 1251L
	E250Y	Energizer Industrial	2D	Krypton	Retain, No Changes
	E251Y	Energizer Industrial	2D	Krypton	Discontinue
	IN215WB-S	Eveready Contractor	2AA	Krypton	Upgrade to LED New Type: EVINL21S
	IN251WB-S	Eveready Contractor	2D	Krypton	Upgrade to LED New Type: EVINL25S
	INL2AAE	Energizer Industrial	2AA	LED	Discontinue
	INL2DE	Energizer Industrial	2D	LED	Discontinue

Industrial Portfolio Changes

	Type	Brand	Size	Bulb	Action
	MS2AALED	Energizer Intrinsically Safe	2AA	LED	Retain, no changes
	MS2DLED	Energizer Intrinsically Safe	2D	LED	Retain, no changes
	INRUB21EH	Energizer Industrial	2AA	LED	Retain, no changes
	INRUB22E	Energizer Industrial	2AAA	LED	Discontinue
	1259	Energizer (MSHA)	2D	PR3	Discontinue

EVEREADY® Industrial Economy 2AA LED Flashlight

Features & Benefits

- LED bulb produces bright white light for a variety of tasks on the job site
- Constructed from non-conductive materials
- Chemical-resistant polypropylene body resists staining and corrosion
- Convenient built-in hanging ring
- Water resistant and drop tested for reliability
- Individually labeled for sale in 12ct case
- Operates on 2AA batteries (not included)



Pricing Information

Type Name:	1151L
Unit Price:	\$2.50
SRP:	\$4.99
Margin:	49.9% (\$2.49)

FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD
Light Output	Run Time	Beam Distance	Impact Resistant	Water Resistant
30 lumens	43 hours	36 meters	1 meter	IPX4

EVEREADY® Industrial Economy 2AA LED Flashlight

Product Description

EVR IND BULK FLASHLIGHT 2AA

Type Name 1151L
OTC Material Number E1203101
Country of Origin China

UNIT OF SALE INFORMATION

Unit UPC 039800120311
Unit Dimensions 6.000"H x 1.400"L x 1.400"W
Unit Volume 0.007 cu ft
Unit Weight 0.090 lbs
Unit List Price \$2.50

CASE INFORMATION


Case UPC 30039800120312
Case Dimensions 6.400"H x 6.500"L x 4.900"W
Case Volume 0.118 cu ft
Case Weight 1.900 lbs
Units per Case 12
Case List Price \$30.00

PALLET INFORMATION

Pallet Dimensions 43.40"H x 48.00"L x 40.00"W
Pallet Volume 48.222 cu ft
Pallet Weight 711.200 lbs
Pallet Ti x Hi: 58 x 6
Cartons per Pallet: 348



Unit UPC

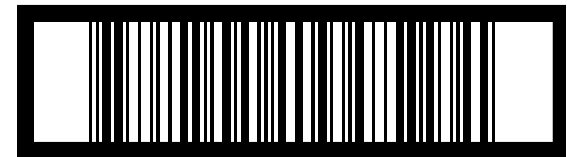

3 0 0 3 9 8 0 0 1 2 0 3 1 2
EVR IND BULK FLASHLIGHT 2AA

Case UPC

EVEREADY® Industrial Economy 2D LED Flashlight

Features & Benefits

- LED bulb produces bright white light for a variety of tasks on the job site
- Constructed from non-conductive materials
- Chemical-resistant polypropylene body resists staining and corrosion
- Convenient built-in hanging ring
- Water resistant and drop tested for reliability
- Individually labeled for sale in 12ct case
- Operates on 2D batteries (not included)



Pricing Information

Type Name:	1251L
Unit Price:	\$3.36
SRP:	\$5.99
Margin:	43.9% (\$2.63)

FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD
Light Output	Run Time	Beam Distance	Impact Resistant	Water Resistant
35 lumens	113 hours	45 meters	1 meter	IPX4

EVEREADY® Industrial Economy 2D LED Flashlight

Product Description

EVR IND BULK FLASHLIGHT 2D

Type Name	1251L
OTC Material Number	E1203401
Country of Origin	China

UNIT OF SALE INFORMATION


Unit UPC	039800120342
Unit Dimensions	7.800"H x 2.400"L x 2.400"W
Unit Volume	0.026 cu ft
Unit Weight	0.240 lbs
Unit List Price	\$3.36

CASE INFORMATION

Case UPC	30039800120343
Case Dimensions	8.250"H x 10.40"L x 7.750"W
Case Volume	0.385 cu ft
Case Weight	3.600 lbs
Units per Case	12
Case List Price	\$40.32

PALLET INFORMATION


Pallet Dimensions	46.25"H x 48.00"L x 40.00"W
Pallet Volume	51.389 cu ft
Pallet Weight	446.000 lbs
Pallet Ti x Hi:	22 x 5
Cartons per Pallet:	110

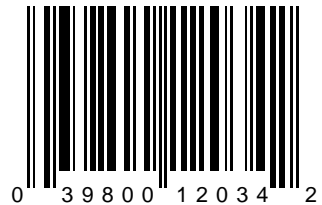

0 3 9 8 0 0 1 2 0 3 4 2

EVR IND BULK FLASHLIGHT 2D

Unit UPC

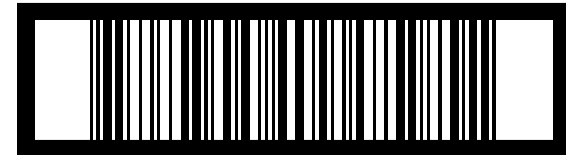

3 0 0 3 9 8 0 0 1 2 0 3 4 3

EVR IND BULK FLASHLIGHT 2D

Case UPC

EVEREADY® Industrial 2AA LED Flashlight

Features & Benefits

- LED bulb produces bright white light for a variety of tasks on the job site
- Constructed from non-conductive materials
- Chemical-resistant polypropylene body resists staining and corrosion
- Convenient built-in hanging ring
- Water resistant and drop tested for reliability
- Includes 2 EVEREADY® AA Super Heavy Duty Batteries



Pricing Information

Type Name:	EVINL21S
Unit Price:	\$4.01
SRP:	\$7.99
Margin:	49.8% (\$3.98)

FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD
Light Output	Run Time	Beam Distance	Impact Resistant	Water Resistant
30 lumens	43 hours	36 meters	1 meter	IPX4

Eveready® Industrial 2AA LED Flashlight

Product Description

EVR IND LED 2AA FLASHLIGHT

Type Name EVINL21S
OTC Material Number E1203201
Country of Origin China

UNIT OF SALE INFORMATION


Unit UPC 039800120328
Unit Dimensions 9.200"H x 1.470"L x 4.100"W
Unit Volume 0.032 cu ft
Unit Weight 0.240 lbs
Unit List Price \$4.01

CASE INFORMATION


Case UPC 30039800120329
Case Dimensions 9.500"H x 7.750"L x 5.900"W
Case Volume 0.251 cu ft
Case Weight 3.300 lbs
Units per Case 12
Case List Price \$48.12

PALLET INFORMATION

Pallet Dimensions 43.00"H x 48.00"L x 40.00"W
Pallet Volume 47.778 cu ft
Pallet Weight 578.000 lbs
Pallet Ti x Hi: 40 x 4
Cartons per Pallet: 160

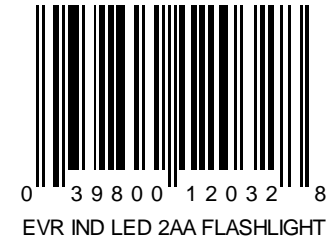

Unit UPC

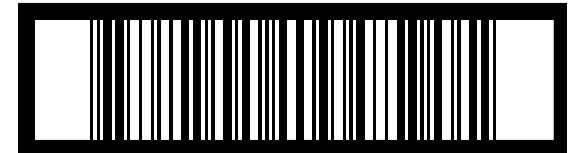

Case UPC

EVEREADY® Industrial 2D LED Flashlight

Features & Benefits

- LED bulb produces bright white light for a variety of tasks on the job site
- Constructed from non-conductive materials
- Chemical-resistant polypropylene body resists staining and corrosion
- Convenient built-in hanging ring
- Water resistant and drop tested for reliability
- Includes 2 EVEREADY® D Super Heavy Duty Batteries



Pricing Information

Type Name: EVINL25S
Unit Price: \$4.80
SRP: \$8.99
Margin: 46.6% (\$4.19)

FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD	FL 1 STANDARD
Light Output	Run Time	Beam Distance	Impact Resistant	Water Resistant
35 lumens	113 hours	45 meters	1 meter	IPX4

Eveready® Industrial 2D LED Flashlight

Product Description

Type Name	EVR IND LED 2D FLASHLIGHT
OTC Material Number	EVINL25S
Country of Origin	China

UNIT OF SALE INFORMATION


Unit UPC	039800120335
Unit Dimensions	11.10"H x 2.500"L x 6.250"W
Unit Volume	0.100 cu ft
Unit Weight	0.790 lbs
Unit List Price	\$4.80

CASE INFORMATION


Case UPC	30039800120336
Case Dimensions	11.50"H x 10.50"L x 6.250"W
Case Volume	0.437 cu ft
Case Weight	5.280 lbs
Units per Case	6
Case List Price	\$28.80

PALLET INFORMATION

Pallet Dimensions	39.50"H x 48.00"L x 40.00"W
Pallet Volume	43.889 cu ft
Pallet Weight	461.800 lbs
Pallet Ti x Hi:	26 x 3
Cartons per Pallet:	78

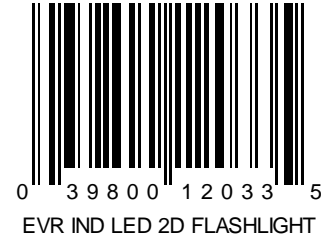

Unit UPC

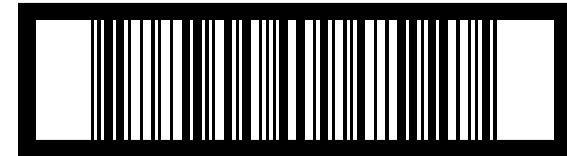

Case UPC