

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

79516-1063

Status:

Active

Overview:

Micro-Fit 3.0™ Connectors

Description:

Micro-Fit Overmolded Cable Assembly, 6 Circuit, 3.0m Length

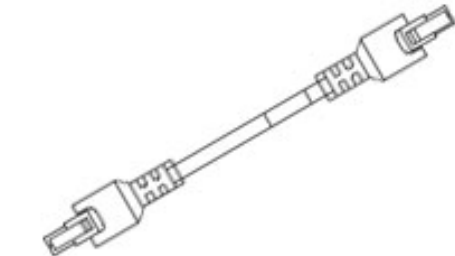


image - Reference only

Series

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General

Product Family	Cable Assemblies
Series	79516
Comments	When using 30 AWG current max per contact is 5A.
Connector to Connector	Micro-Fit-to-Micro-Fit
Overview	Micro-Fit 3.0™ Connectors
Product Name	Micro-Fit 3.0™
UPC	822348120529

Physical

Cable Length	3.0m
Circuits (Loaded)	6
Color - Resin	Black
Gender	Female-Female
Lock to Mating Part	Yes
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Polyester
Net Weight	145.700/g
Packaging Type	Bag
Pitch - Mating Interface	3.00mm
Plating min - Mating	1.016µm
Plating min - Termination	1.016µm
Single Ended	No
Wire Insulation Diameter	N/A
Wire Size AWG	26
Wire/Cable Type	Jacketed

Electrical

Current - Maximum per Contact	3A
Shielded	No
Voltage - Maximum	250V

Material Info

Reference - Drawing Numbers

Sales Drawing	SD-79516-003
---------------	--------------

EU RoHS

ELV and RoHS
Compliant

REACH SVHC

Not Reviewed
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

79516Series

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION