

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [120072-0471](#)
Status: **Active**
Overview: [Brad® Micro-Change® \(M12\) Connectors](#)
Description: Micro-Change® (M12) Single-Ended Cordset, Female - Pigtail, Straight, Dual Keyway, 5 Poles, Length 1.83m

Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR6837
UL E152210

General

Product Family Industrial Cordsets
Series [120072](#)
Connector End A Micro-Change® (M12)
Connector End B Pigtail
IP Rating IP67
NEMA Rating NEMA 6
Overview [Brad® Micro-Change® \(M12\) Connectors](#)
Product Name Micro-Change® (M12)
Type Single Ended
UPC 78678829316

Physical

Cable Diameter 5.80mm (.230")
Cable Length 1.83m
Color - Cable Jacket Yellow
Coupling Style Threaded
Gender Female-Pigtail
Keyway Dual
LED Indicator No
Material - Cable Jacket PVC
Material - Connector Body PVC
Material - Contact Brass
Material - Coupling Nut Black Epoxy Coated Zinc
Material - O-Ring Nitrile Rubber
Material - Plating Mating Gold over Nickel
Orientation Straight
Poles 5
Temperature Range - Operating -20°C to +105°C
Wire Size AWG 22
Wire/Cable Type UL 2661

Electrical

Current - Maximum per Contact 4A
Voltage - Maximum 250V

Material Info

Old Part Number 705000D02F060

Reference - Drawing Numbers

Sales Drawing SD-120072-004

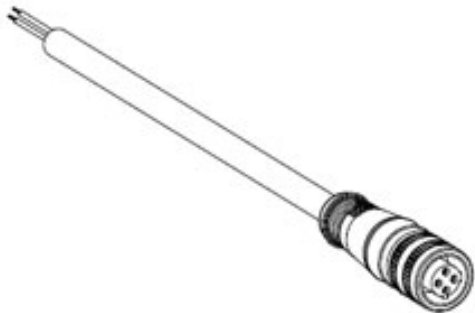


image - Reference only

Series

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Not Reviewed
Low-Halogen Status
Not Reviewed

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[120072Series](#)

This document was generated on 10/05/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION