

COMMUNICATION & CONTROL

MULTICONDUCTOR, UNSHIELDED

RUBBER

600 VOLT

CHARACTERISTICS

OPERATING TEMPERATURE:

- -20°C to 60°C

VOLTAGE RATING:


- 600 Volt

COLOR DESCRIPTION:

- Color Code: Chart H Page 376
- Jacket Color: Black

PRODUCT DESCRIPTION:

- Conductor: Stranded Tinned Copper
- Insulation: Color-Coded Rubber
- Wrap: Clear Polyester
- Jacket: Rubber

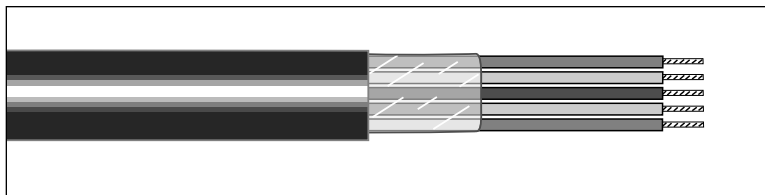

20 AWG (0,51mm²), **26/34** (26x0,16mm), Insulation Thickness: **0.020"** (0,50mm)

Alpha Part No.	No. of Cond.	Jacket Thickness		Diameter	
		Inches	mm	Inches	mm
1244	2	0.035	0,89	0.23	5,8
1245	3	0.035	0,89	0.24	6,1
1246	4	0.035	0,89	0.26	6,6
1247/6	6	0.035	0,89	0.31	7,9
1247/10	10	0.035	0,89	0.37	9,4
1247/12	12	0.035	0,89	0.39	9,9
1247/15	15	0.035	0,89	0.43	10,9

AVAILABILITY

- 100 ft (30,5m), 500 ft (152m),
1000 ft (305m) put-ups

185