




0-1/2"/0-13mm


0-1/2"/0-13mm

The 463 and 1463 Series are exactly the same, except that the 1463 Series is made from rust-resistant stainless steel. The reading surfaces are satin finished stainless steel for easy readability. Heads are available with the features below:


- Either combination ratchet and speeder for uniform pressure and quicker adjustment, or plain micrometer heads that depend on your own feel
- Ring-type lock nut for quick and sure locking at any setting
- Reverse reading, if needed
- Plain or carbide spindle faces

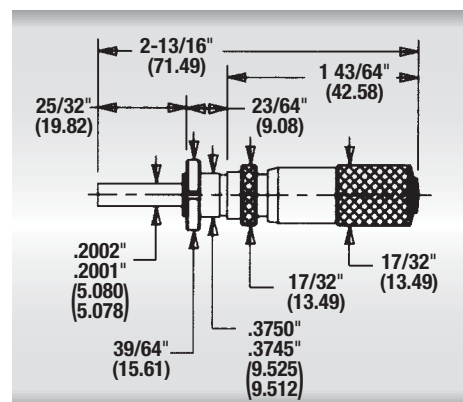

463L-38TN, 0-1/2" dimensions

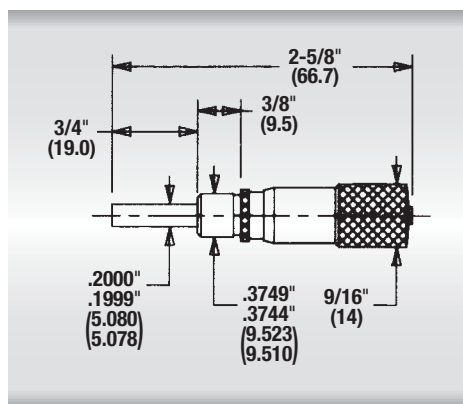

463P, 0-1/2" and 463MP (0-13mm) dimensions

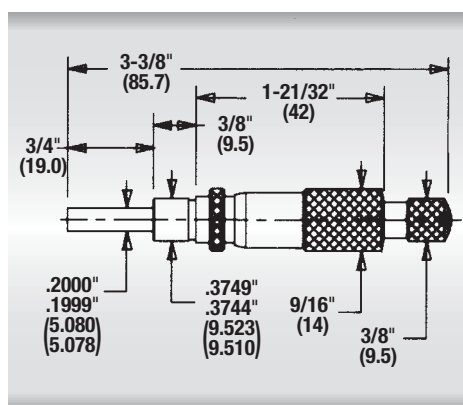

463RL, 0-1/2" and 463MRL (0-13mm) dimensions

463 & 1463 Micrometer Heads

Range	Graduation	Catalog No.	EDP	Description
0-1/2"	.001"	463P	52440	Plain
		463P-38TN	67112	Plain, 3/8" Threaded Hub and Check Nut
		463L	52442	Lock Nut
		463XL	52451	Lock Nut, Carbide Face
		463L-38TN	67113	Lock Nut, 3/8" Threaded Hub and Check Nut
		463RL	52443	Ratchet Stop, Lock Nut
		463XRL	64687	Ratchet Stop, Lock Nut, Carbide Face
		RV463RL	57073	Reverse Reading, Ratchet Stop, Lock Nut
		RV463XRL	64688	Reverse Reading, Ratchet Stop, Lock Nut, Carbide Face
	.0001"	T463P	52446	Plain
		T463L	52448	Lock Nut
		T463XL	64689	Lock Nut, Carbide Face
		T463RL	52449	Ratchet Stop, Lock Nut
		T463XRL	65052	Ratchet Stop, Lock Nut, Carbide Face
0-13mm	0.01mm	463MP	52444	Plain
		463MRL	52452	Ratchet Stop, Lock Nut
		463MXRL	64691	Ratchet Stop, Lock Nut, Carbide Face
	0.002mm	V463MRL	65053	Ratchet Stop, Lock Nut
		RV463MRL	60845	Reverse Reading, Ratchet Stop, Lock Nut
0-1/2"	.001"	1463RL	53207	Ratchet Stop, Lock Nut (Stainless)
	.0001"	T1463RL	53209	Ratchet Stop, Lock Nut (Stainless)
0-13mm	0.002mm	V1463MRL	64344	Ratchet Stop, Lock Nut (Stainless)