


low profile rectangular RFI shielding gaskets

WITH VERY HIGH BOND PRESSURE SENSITIVE ADHESIVE MOUNTING. Three sizes offer very low relaxed and compressed heights. Available in popular CuNi conductive metalized surface for most applications. Low profile with very low compression force required.

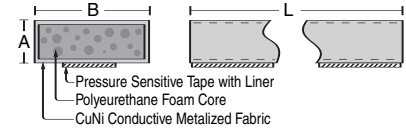

PART No.	Conductive Surface	Surface Resistivity	A		B		Length	
SG060125R-24	CuNi	0.005 - 0.010Ω/lin.in	.060	1,2	.125	3,2	24.0	610
SG060125R-48	CuNi	0.005 - 0.010Ω/lin.in	.060	1,2	.125	3,2	48.0	1220
SG125250R-24	CuNi	0.005 - 0.010Ω/lin.in	.125	3,2	.250	6,4	24.0	610
SG125250R-48	CuNi	0.005 - 0.010Ω/lin.in	.125	3,2	.250	6,4	48.0	1220
SG187375R-24	CuNi	0.005 - 0.010Ω/lin.in	.187	4,7	.375	9,5	24.0	610
SG187375R-48	CuNi	0.005 - 0.010Ω/lin.in	.187	4,7	.375	9,5	48.0	1220