




Clamping Handles

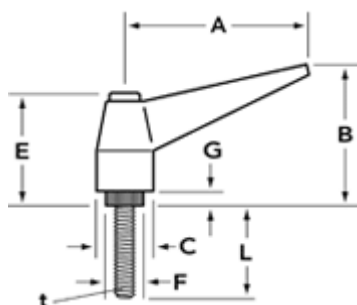

Description

PART TYPE	Plastic Clamping Handle
HANDLE LENGTH	4.09 inch (104 mm)
STUD OR INSERT	Zinc Plated Alloy Steel Stud
THREAD TYPE	English

Part Dimensions

Part Number	A in	B in	C in	D in	E in	F in	G in	L in	t Thread
05AR40S-501325	4.09	2.68	1.35	-	1.85	0.93	0.38	2.50	1/2-13