


U.S. Footprint

Number of contacts

Mounting height

9-37

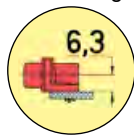

Stamped solder pins, angled with snap-in-clips and grounding board locks

D-Sub

Identification	No. of contacts	Part No.	
Performance levels Explanations see page 05.04 Other performance levels on request		Performance level 3	
		S4 ¹⁾	
Male connector metal shell with dimples		2.84 mm pitch	
	9	09 68 163 781 .	09 68 163 581 .
	15	09 68 263 781 .	09 68 263 581 .
	25	09 68 363 781 .	09 68 363 581 .
	37	09 68 463 781 .	09 68 463 581 .
Female connector metal shell		2.84 mm pitch	
	9	09 68 153 761 .	09 68 153 561 .
	15	09 68 253 761 .	09 68 253 561 .
	25	09 68 353 761 .	09 68 353 561 .
	37	09 68 453 761 .	09 68 453 561 .
Please insert digit for flange thread or fitted female screw locks			
M3 ▶ 1 ²⁾			
4-40 UNC ▶ 2			
fitted screw locks 4-40 UNC ▶ 3			

¹⁾ S4 = 0.76 µm (30 µinch) Au or PdNi equivalent

²⁾ Not normally kept in stock