


Aluminium Housed Proximity Switch - Changeover Contacts

Part Number : PRC-SA-002 Recommended Magnet PRM-SA-003

Product Data Sheet

PICTURE

DIMENSIONS

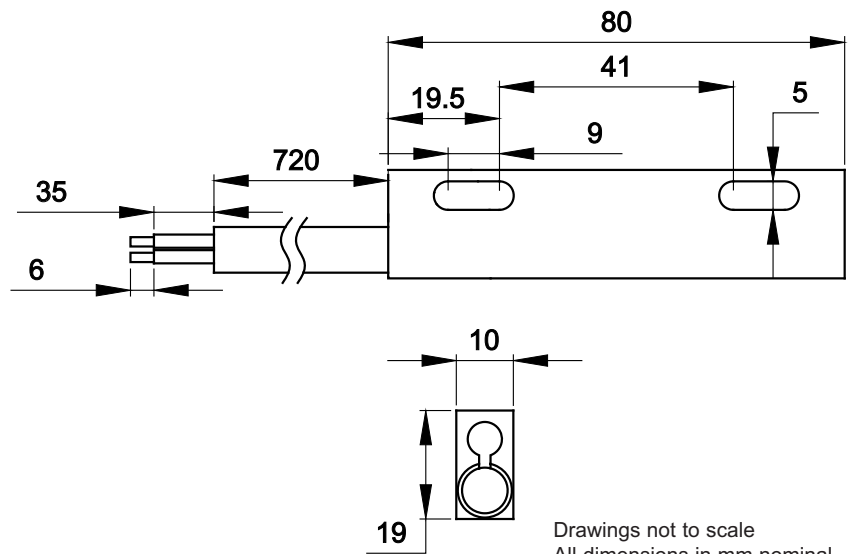

Drawings not to scale
All dimensions in mm nominal

✓ RoHS Compliant

SPECIFICATION

Contact Form / Style		Changeover
Switching voltage	Max Volts	400 AC/DC
Switching Current	Max Amps	1.0
Switching Capacity	Max W/VA	60
Carry Current	Max Amps	2.0
Switching Distance	Make	15mm (with recommended magnet)
	Break	24mm (with recommended magnet)
Contact Resistance	Max mOhms	100
Operating Temperature	Celsius	-20° to 85°
Case Material		Blue powder coated Aluminium
Cable		4 core 0.75mm ² Black PVC insulated, Br / Bl / Bla / G&Y

Applications Include

- Position sensing.
- Linear actuators.
- Security switching.
- Safety guards/devices

Options/Features

- Robust sealed switch, custom housings available.
- Normally open version available.
- Custom cable types, cable lengths, connectors or crimp terminals available.
- Hermetically sealed reed switch for long life.
- Earthed housing for added safety

Did you know we also sell?



Rev. No.

Revision Note

Date

Signature

2

Image/logo update

22-11-13

ML



ISO 9001:2008
Certificate No. FM21080

As part of the company policy of continued product improvement, specifications may change without notice. Our sales office will be pleased to help you with the latest information on this product range and the details of our full design and manufacturing service. All products are supplied to our standard conditions of sale unless otherwise agreed in writing.

Phone : +44 (0)1255 862236

www.comus-group.com

Fax: +44 (0)1255 862014

©2013 Copyright Comus Europe Ltd, Unit 7, Rice Bridge Industrial Estate, Thorpe - Le - Soken, Essex, CO16 0HL, ENGLAND.
USA: Comus International:+1 973 777 6900, Belgium: Comus Belgium BVBA: +32 (0)12 390400