


# GBC Bench Counting Scale

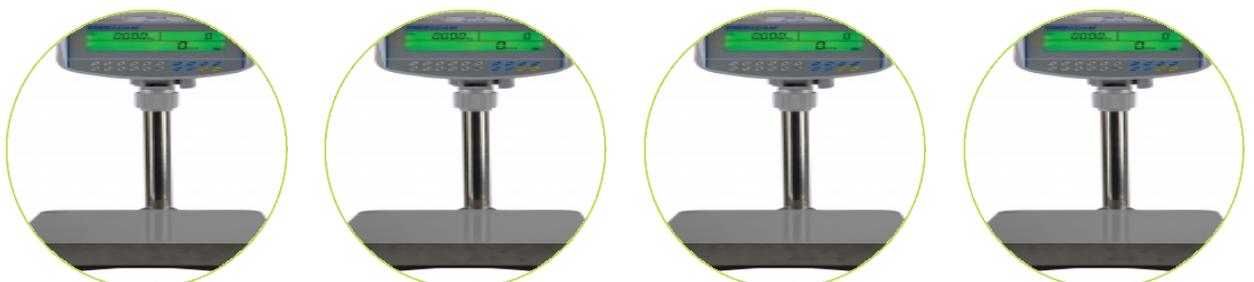

## Speed, Performance, Value - The Right Balance

- Date and time
- Selectable multi-language text for printing
- Preset counting to a value
- Large backlit LCD display
- Overload protection
- Non-slip adjustable levelling feet
- Large stainless steel platform
- Pillar mounted
- Full colour coded keypad with numeric entry
- Precision load cell technology
- Simple user-friendly operation
- Splashproof to protect from accidental spills
- Easy access to the rechargeable battery
- RS-232 bi-directional interface
- External calibration
- Rechargeable battery up to 90 hours operation
- Auto sleep / power down function to save battery life
- Low battery indication
- AC Adapter
- Grade 304 stainless steel pan
- Counting
- Parts counting



## Technical Specifications

 
Model	GBC 16	GBC 32	GBC 60
Maximum capacity	16kg	32kg	60kg
Readability	0.5g	1g	2g
Repeatability (S.D.)	1g	2g	4g
Linearity (±)	1g	2g	4g
Pan size	300x400mm		

## General Specifications

Typical stabilisation time	2-3 Sec
Operating temperature	-10°C to 40°C
Power supply	12vDC 800mA adapter / 6v 4ah rechargeable battery
Calibration	Automatic External
Display	Large LCD backlit display
Overall dimensions (wxdxh)	300x520x680mm
Dimensions notes	Shipping Weight: 16Kg Dims: 90 x 46 x 21cm
Net weight	7.6kg

## Key Accessories

- RS-232 to USB Interface Cable (must be ordered with 3074010266 R)
- AdamDU - Data Collection Program
- In-use Cover
- Adam Printer
- Thermal Paper Roll for Adam Printer
- RS-232 Cable



Adam Equipment - offices worldwide

[www.adamequipment.com](http://www.adamequipment.com)