


Capacitor, Tantalum, General Purpose Radial Conformal (Dipped), 2.2 uF, +/-20% Tol, 20V@85C, Lead Spacing=5.08 mm

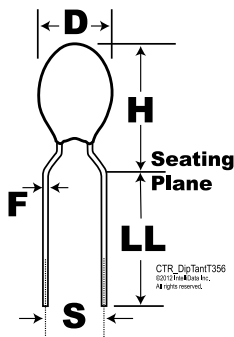

Dimensions (mm)		
Symbol	Dimension	Tolerance
D	4.5	
H	8.6	
F	0.5	+/-0.05
S	5.08	+/-0.38
LL	4.75	+/-0.81

Packaging Specifications	
Package Kind:	Bulk
Package Type:	Bag
Package Quantity:	1000

General Information

Supplier: KEMET

Specifications

Value:	2.2 uF
Voltage DC @ 85C:	20V
Voltage DC @ 125C:	13V
Tolerance:	+/-20%
Body Type:	Radial Conformal (Dipped)
Temperature Range:	-55/+125C
Application:	General Purpose
Termination Type:	Tin (Sn)
RoHS:	Yes
Leakage Current:	0.5 uA
Dissipation Factor:	5%