



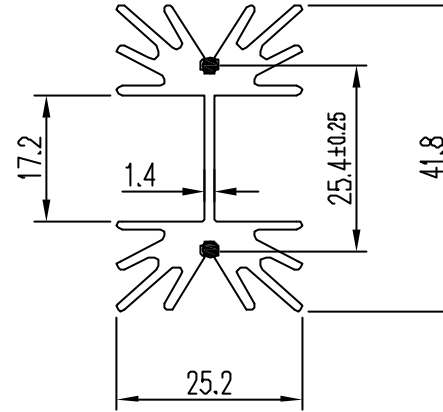

THIS DOCUMENT CONTAINS AAVID THERMALLOY'S INTELLECTUAL PROPERTY WHICH IS SUPPLIED IN CONFIDENCE; IT MUST NOT BE USED FOR ANY PURPOSE OTHER THAN WHICH IT IS SUPPLIED; IT MUST NOT BE REPRODUCED WITHOUT WRITTEN PERMISSION FROM THE OWNERS

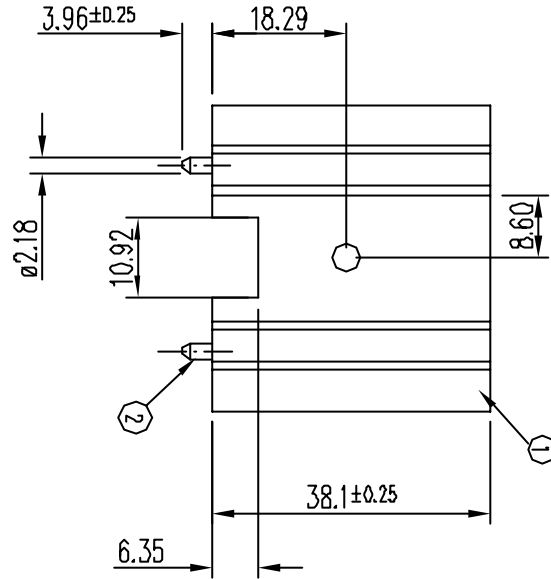

Pos.	Description	Qty	P/N
1	EXTRUSION 406610 OS097	1	406610
2	SOLDERABLE PIN	2	436502



AAVID THERMALLOY

EUROPE www.aavidthermalloy.com

Via XXV Aprile, 38
40087 Castellano - Bologna ITALY
Tel. +39 051 764011
Fax +39 051 764020

Cherry Manor
SWINDON WILTS SN4 8GN UK
Tel. +44 1793 401400
Fax +44 1793 618886

COMPANY WITH QUALITY SYSTEM CERTIFIED BY DNV ISO 9001

COMPANY WITH QUALITY SYSTEM CERTIFIED BY BSI ISO 9002

Die n.	MATERIAL Al EN AW-6060 T5 or T6								DRAWING n. 439049
Factor	GENERAL TOLERANCES Extrusion UNI EN 755								Vis. n.
Perim.	Machining UNI EN 22768-m								Description:
Area	FINISH BLACK ANODIZE								HTSK-AL-406610 OS097-36-B
Weight									Format
Note:	Note note note note	Drawn	M. Gallozzi	B	11Nov07	Change profile /Cambio profilo	EDN	Scale	1:1
		Check		A	30Oct06	ORIGINAL		By	A4
				REV	Date	Revision description			

