


## Black Box Products

---

### KVM > Cables

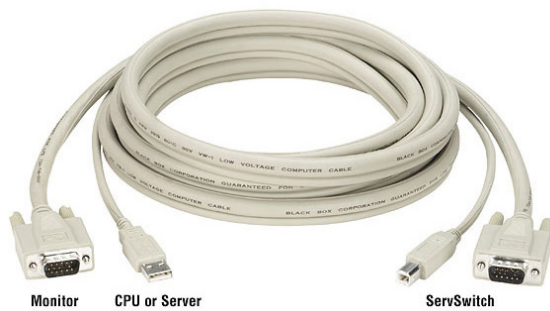

### ServSwitch USB CPU/Server Cables, 12-ft. (3.6-m)

Cables for ServSwitch USB or USB Plus.

EHN810-0012

---

Extended Double Diamond™ Warranty Available  
(Lifetime)

#### Product Highlights

- This zip-cord style cable features two cables in one: a video cable and a USB cable.
- Use these cables for connecting USB-enabled CPUs and servers to the ServSwitch™ USB and the ServSwitch USB Plus.
- The cables feature molded plastic hoods. The USB cable features a foil shield. The video cable includes a braid and foil shield.

## Details

### Description

ServSwitch USB CPU/Server Cables, 12-ft. (3.6-m)

### Quick Facts

- This zip-cord style cable features two cables in one: a video cable and a USB cable.
- Use these cables for connecting USB-enabled CPUs and servers to the ServSwitch™ USB and the ServSwitch USB Plus.
- The cables feature molded plastic hoods. The USB cable features a foil shield. The video cable includes a braid and foil shield.

### Further Details

- Distance is limited by the USB specification.
- Four cable lengths available in 4- to 16-foot (1.2- to 4.8-m) lengths.

These cables are for connecting USB-enabled CPUs and servers to the ServSwitch USB and the ServSwitch USB Plus. They're available in 4- to 16-foot (1.2- to 4.8-m) lengths. Distance is limited by the USB specification.

## Tech Spec

### Technical Specifications for RJ-11 Flat-Satin Telephone Cable, 4-Wire, Crossed-Pinning, 4-ft. (1.2-m):

Hood Assembly	Molded plastic
Jacket Assembly	PVC
Shielding	USB: Foil;
RGB video	Braid and foil
Wire Gauge	USB: 26 AWG stranded copper;
RGB	24 RGB coax
Fido Protection	Lifetime

NOTE: Technical specification weight is the unit weight. It is not the packaged shipping weight.