

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [50-37-5063](#)
Status: **Active**
Overview: [SPOX™ Wire-to-Board Connectors](#)
Description: 2.50mm Pitch SPOX™ Wire-to-Board Crimp Housing, Friction Lock, 6 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-5264-001 \(PDF\)](#)
[Packaging Specification SPK-5264-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E29179

General

Product Family Crimp Housings
Series [5264](#)
Application Signal, Wire-to-Board
MolexKits Yes
Overview [SPOX™ Wire-to-Board Connectors](#)
Product Name SPOX™
UPC 800753578371

Physical


Circuits (maximum) 6
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Net Weight 330.500/mg
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.50mm
Polarized to Mating Part Yes
Stackable No
Temperature Range - Operating -40°C to +105°C

Material Info

Old Part Number 5264-06

Reference - Drawing Numbers

Packaging Specification SPK-5264-001
Product Specification PS-5264-001, RPS-5264-001, RPS-5264-002, RPS-5264-003, RPS-5264-004, RPS-5264-005, RPS-5264-006
Sales Drawing SD-5264-N

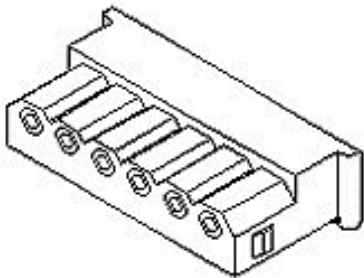

Series

image - Reference only

EU RoHS

**ELV and RoHS
Compliant**
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[5264Series](#)

Mates With

[5267](#) vertical shrouded PCB header, [5268](#)
right angle shrouded PCB header

Use With

[5263](#)