


“Bolt-On” Washer Thermocouple Assemblies

**WT Series
300 mm**




- ✓ For M3.5 (#6), M4 (#8), M4.5 (#10), and M6 (1/4") Screw Sizes
- ✓ New Rugged Design
- ✓ Stocked with Stripped End Leads
- ✓ Glass Rated to 480°C (900°F) PFA Rated to 260°C (500°F)
- ✓ Inquire with Sales about Kapton Insulation and Custom Lengths or Sizes
- ✓ Made from 20 AWG Solid Wire
- ✓ Grounded Junction

Easily mounts to a variety of surfaces.

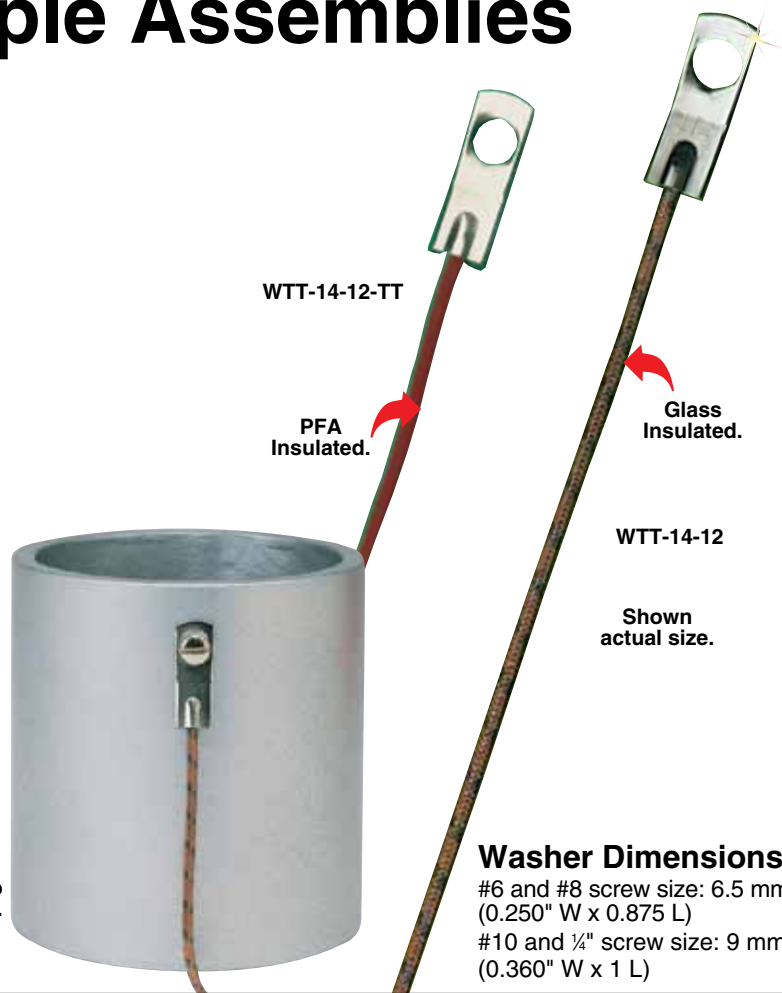

Washer Dimensions

#6 and #8 screw size: 6.5 mm W x 22 L (0.250" W x 0.875 L)
#10 and 1/4" screw size: 9 mm W x 25 L (0.360" W x 1 L)

 

To Order Visit newportUS.com/wt for Pricing and Details

Model No. 300 mm (12") L	Model No. 600 mm (24") L	Model No. 900 mm (36") L	Model No. 1500 mm (60") L	Washer Hole Diameter mm (inches)	Nominal Screw Size	
					American	Metric
GLASS INSULATED						
WT(*)-6-12	WT(*)-6-24	WT(*)-6-36	WT(*)-6-60	3.68 (0.145)	#6	M3.5
WT(*)-8-12	WT(*)-8-24	WT(*)-8-36	WT(*)-8-60	4.32 (0.170)	#8	M4
WT(*)-10-12	WT(*)-10-24	WT(*)-10-36	WT(*)-10-60	4.95 (0.195)	#10	M4.5
WT(*)-14-12	WT(*)-14-24	WT(*)-14-36	WT(*)-14-60	6.60 (0.260)	¼"	M6
PFA INSULATED						
WT(*)-6-12-TT	WT(*)-6-24-TT	WT(*)-6-36-TT	WT(*)-6-60-TT	3.68 (0.145)	#6	M3.5
WT(*)-8-12-TT	WT(*)-8-24-TT	WT(*)-8-36-TT	WT(*)-8-60-TT	4.32 (0.170)	#8	M4
WT(*)-10-12-TT	WT(*)-10-24-TT	WT(*)-10-36-TT	WT(*)-10-60-TT	4.95 (0.195)	#10	M4.5
WT(*)-14-12-TT	WT(*)-14-24-TT	WT(*)-14-36-TT	WT(*)-14-60-TT	6.60 (0.260)	¼"	M6

* Specify thermocouple Type: **J**, **K**, **T** or **E**. Stripped leads are standard. To order other terminations, add suffix “**-L**” to model number for #10 spade lugs and additional cost. For standard OSTW male connector, add suffix “**-OSTW-M**” to model number and additional cost or add suffix “**-OSTW-F**” to model number for female and additional cost. For molded version of standard male round pin connector, add suffix “**-LRTC**” to model number and additional cost. For miniature SMPW male connector, add suffix “**-SMPW-M**” to model number and additional cost, or add suffix “**-SMPW-F**” to model number for female and additional cost. For molded version of miniature male connector, add suffix “**-SRTC**” to model number and additional cost.

To order with lead lengths over 60", change “**60**” in model number to desired length in inches, and add cost per additional foot to the 60" price.

Ordering Example: **WTJ-6-12**, washer thermocouple, Type J, #6 screw, 300 mm (12") length, glass braid insulated wire.