

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [54596-1710](#)
Status: **Active**
Overview: Mini Mi II™
Description: MINI MI2 REC. ASSY (SN)

Documents:

3D Model	Product Specification PS-54596-020 (PDF)
Drawing (PDF)	Product Specification PS-54596-021 (PDF)
Product Specification PS-54596-005 (PDF)	Product Specification PS-54596-022 (PDF)
Product Specification PS-54596-006 (PDF)	Product Specification PS-54596-023 (PDF)
Product Specification PS-54596-007 (PDF)	Product Specification PS-55448-001 (PDF)
Product Specification PS-54596-018 (PDF)	Product Specification PS-55482-006 (PDF)
Product Specification PS-54596-019 (PDF)	RoHS Certificate of Compliance (PDF)

General

Product Family	IDT and Solder Connectors
Series	54596
Crimp Quality Equipment	Yes
Overview	<u>Mini Mi II™</u>
Product Name	Mini Mi II™
UPC	800753280946

Physical

Circuits (Loaded)	17
Circuits (maximum)	17
Color - Resin	Natural
Gender	Female
Glow-Wire Compliant	No
Lock to Mating Part	None
Material - Metal	Phosphor Bronze
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Material - Resin	Nylon
Net Weight	493.800/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	1.25mm
Plating min - Mating	0.914µm
Plating min - Termination	0.914µm
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Termination Interface: Style	IDT or Pierce
Wire Insulation Diameter	0.80-0.90mm
Wire Size AWG	26, 28

Electrical

Current - Maximum per Contact	1.5A
Voltage - Maximum	100V

Material Info

Reference - Drawing Numbers

Product Specification	PS-54596-005, PS-54596-006, PS-54596-007, PS-54596-018, PS-54596-019, PS-54596-020, PS-54596-021, PS-54596-022, PS-54596-023, PS-55448-001, PS-55482-006, RPS-54596-012,
-----------------------	--

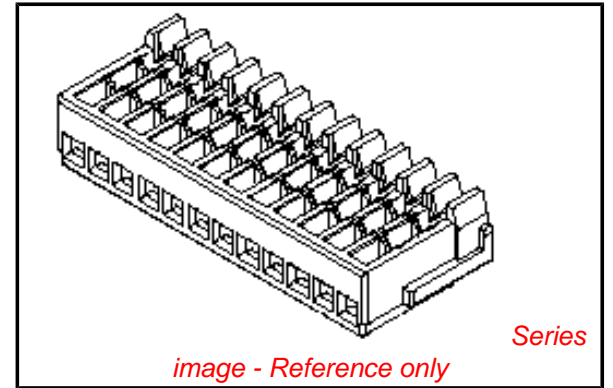


image - Reference only

EU RoHS

ELV and RoHS Compliant
REACH SVHC Contains SVHC: No
Low-Halogen Status Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

[54596Series](#)

Mates With

[55451](#) , [55447](#) , [55454](#) , [55659](#) , [55456](#) , [55482](#) , [55450](#)

Application Tooling | FAQ

Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global

Description	Product #
IDT System Hand Crimper	0621009800

Japan

Description	Product #
Fully-Automated IDT Machine (XELOM-PLUS)	0578008300
Fully-Automated IDT Machine (XELOM-PLUS)	0578008400

Sales Drawing

RPS-54596-013, RPS-54596-014, RPS-54596-016,
RPS-54596-017, RPS-54596-022, RPS-54596-023,
RPS-54596-024, RPS-54596-025, RPS-54596-026,
RPS-54596-027, RPS-55448-004
SD-54596-004

IDT Bench-Top Terminator	<u>0578277100</u>
Hand Crimper	<u>0578345000</u>

This document was generated on 09/06/2012

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION