

Caps Fingergrip for Holder FEU, FAU, FAC



250 VAC · 20 A (UL/CSA)



### Standards

- IEC 60127-6
- UL 4248-1 / UL 512
- CSA C22.2 no. 39

### References

Mating Cap to [FAC](#); [FAU](#); [FEU](#)



### Weblinks

[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)

### Technical Data

Fuse-Link	5 x 20 or 6.3 x 32 mm
Rated Voltage	250 VAC
Rated current	10 A (VDE), 20 A (UL/CSA)
Degree of Protection	IP 40
Admissible Ambient Air Temp.	-40 °C to 85 °C
Material: Cap	Thermoset
Storage Conditions	0 °C to 60 °C, max. 70% r.h.

### Dimension

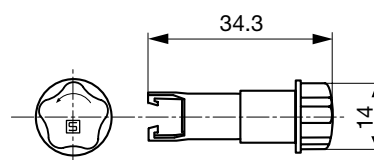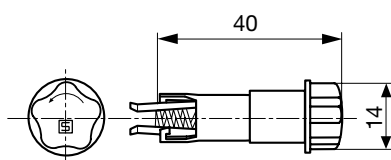

### All Variants

Cap	Fuse-Link	Degree of Protection	Order Number
Fingergrip	6.3 x 32mm	IP 40	0031.1667
Fingergrip	5 x 20mm	IP 40	0031.1741

Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

### Packaging Unit

Plastic Bag (100 pcs.)