

Cartridge Fuse, 6.3x32 mm, low resistance, up to 30 A

new



UL 248-14 · 250VAC · Time-Lag T



Description

- Up to 30 A, low resistance
- Ceramic Tube

Standards

- UL 248-14
- CSA C22.2 no. 248.14

Approvals

- UL File Number: E184831

Applications

- Single-phase high current applications up to 30 A
- Industrial electronic


References

Pigtail Type [SUT 6.3x32 Pigtail](#)
Corresponding Fuseholder [CQP](#)

Weblinks


[pdf-datasheet](#), [html-datasheet](#), [General Product Information](#), [Approvals](#), [CE declaration of conformity](#), [RoHS](#), [CHINA-RoHS](#), [e-Shop](#), [SCHURTER-Stock-Check](#), [Distributor-Stock-Check](#), [Detailed request for product](#)

Technical Data

Rated Voltage	250VAC
Rated current	12 - 30A
Breaking Capacity	500A
Characteristic	Time-Lag T
Admissible Ambient Air Temp.	-40 °C to 85 °C
Climatic Category	40/085/21 acc. to IEC 60068-1
Material: Tube	Ceramic
Material: Endcaps	Nickel-Plated Brass
Material: Filler	Sand
Unit Weight	2.8 g
Storage Conditions	0 °C to 60 °C, max. 70% r.h.
Product Marking	 Type, Current, Rated voltage, Approvals

Dimension

6.3 mm

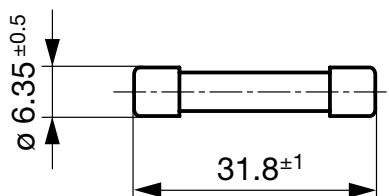


Pre-Arcing Time





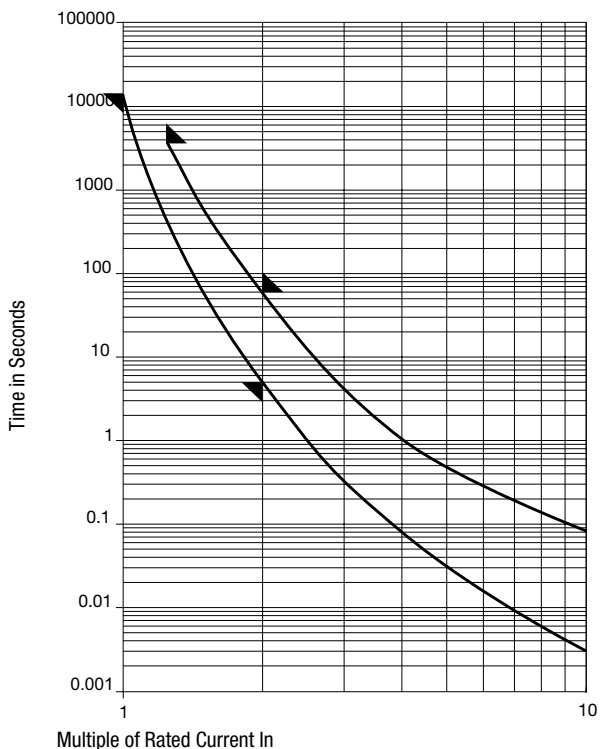

Rated Current In 1.0 x In min. 1.35 x In max. 2.0 x In min. 2.0 x In max.

12 A - 30 A	4 h	60 min	5 s	60 s
-------------	-----	--------	-----	------

Time-Current-Curves



All Variants

Rated Current [A]	Rated Voltage [VAC]	Breaking Capacity	Voltage Drop 1.0 In typ. [mV]	Cold Resistance typ. [mΩ]	Melting I ² t 10.0 Intyp. [A ² s]	 Order Number
12	250	1)	78	5.6	72	● 8020.0603 
15	250	1)	81	4.7	152	● 8020.0604 
20	250	1)	87	3.6	750	● 8020.0605 
25	250	1)	62	2.1	1010	● 8020.0606 
30	250	1)	64	1.8	2050	● 8020.0607 

 Most Popular.

Availability for all products can be searched real-time: <http://www.schurter.com/en/Stock-Check/Stock-Check-SCHURTER>

1) 500 A @ 250 VAC, 10 kA @ 125 VAC

Packaging Unit	xxxx.xxxx	Small Box Pack (10 pcs.)
	xxxx.xxxx.G	Bulk (1000 pcs.)