

# Socket VHDCI, 68Way




**RoHS  
Compliant**

## Specifications:

Current Rating	: 0.3A
No. of Ways	: 68
Pitch Spacing	: 0.8mm
Insulation Resistance Min	: 500MΩ
Contact Resistance Max	: 50mΩ
Dielectric Withstanding Voltage	: 250V AC for one minute
Operating Temperature	: -25°C to +85°C

## Materials:

Housing	: Thermoplastic with G/F reinforced
Cover	: Thermoplastic with G/F reinforced
Contact	: Phosphor bronze, gold over nickel
Bracket	: Zinc alloy, nickel plated
Harpoon	: Phosphor bronze, tin over nickel

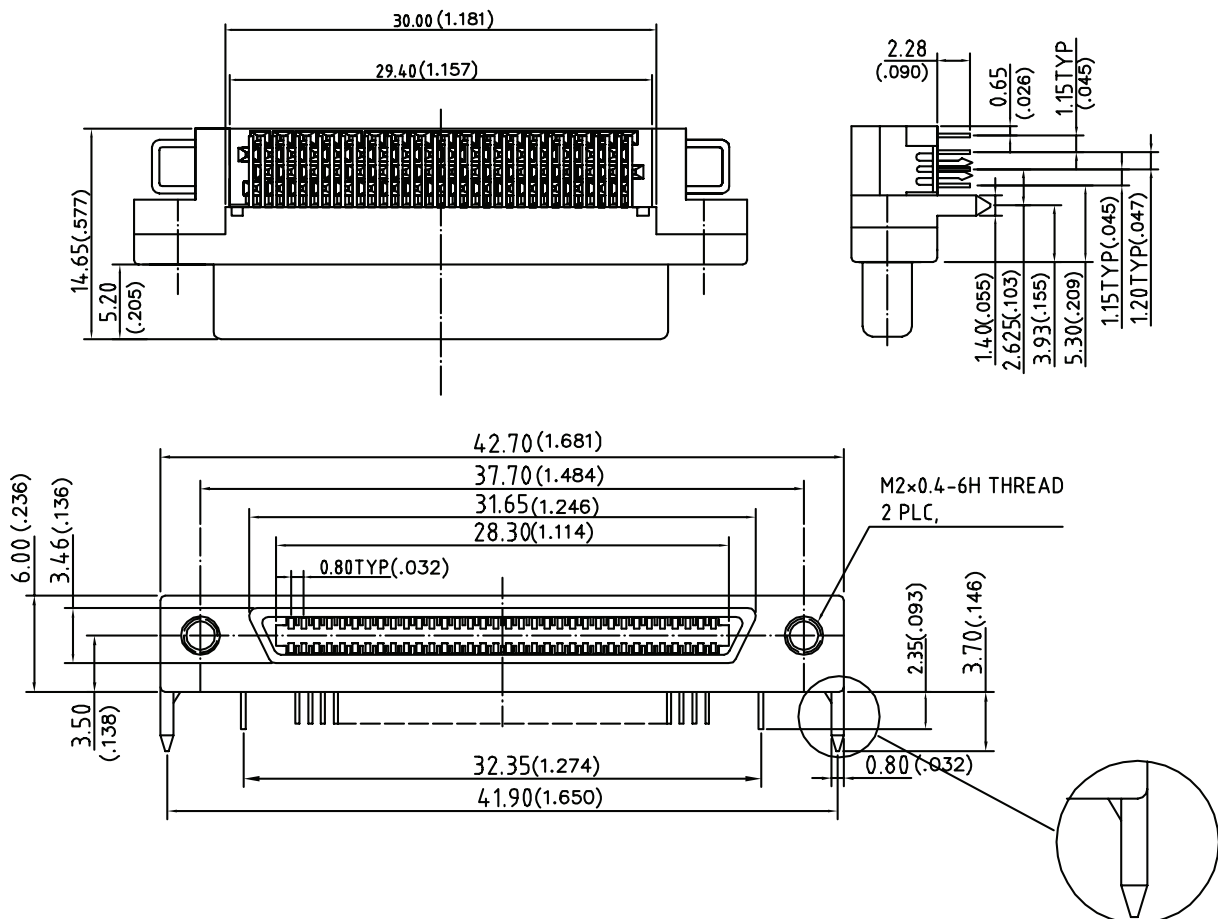

Dimensions : Millimetres (Inches)

www.element14.com  
www.farnell.com  
www.newark.com



