

Self Extinguishing - Polyethylene Terminal Blocks

Material Specification

Applicable to all terminal blocks on this page.

Terminal block housing:

Self extinguishing polyethylene.

Colour:

White.

Terminal insert:

Brass.

Terminal screw:

Chrome plated steel.

Fire Performance

Flammability:

UL94-V2.

Maximum working temp:

80°C

Continuous working temp:

80°C

Approvals

See pages CO21-22

Screw Size

1275: M 2.5

1276-18: M 3


1277: M 3.5

1278: M 4

Cat Ref.	Pack
1275	10




1275 - Level Base

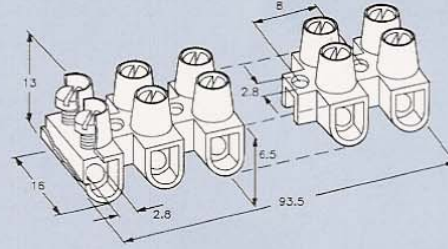

Cat Ref.	Pack
1276-18	10




1276-18 - Level Base

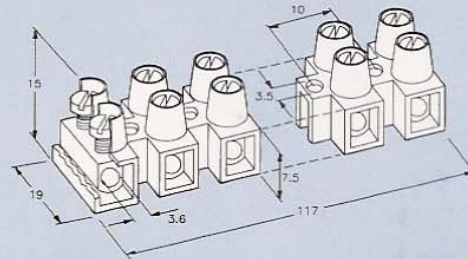

Cat Ref.	Pack
1277	10




1277 - Level Base

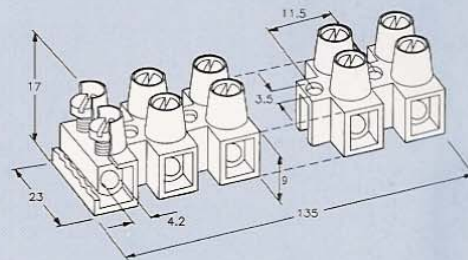

Cat Ref.	Pack
1278	10



1278 - Level Base

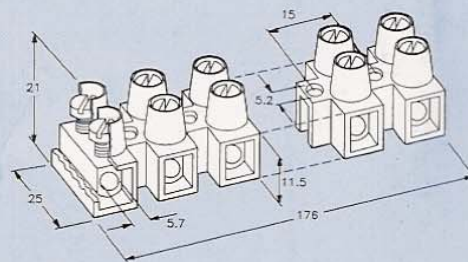

Catalogue Ref.	Application	Applicable Standard	Wire Capacity	Rating	Voltage
1275	Domestic Appliances	EN 60 335 Part 1: 1988	1.5mm ²	5A	250V
1276-18	Domestic Appliances	EN 60 335 Part 1: 1988	2.5mm ²	10A	250V
1277	Domestic Appliances	EN 60 335 Part 1: 1988	4.0mm ²	15A	250V
1278	Domestic Appliances	EN 60 335 Part 1: 1988	6.0mm ²	30A	250V

Cut & marked version of these terminal block and connector products are available to special order.

All dimensions given in millimetres