

PRODUCT RANGE (RATINGS @ 85°C)				
TYPE	CONTINUOUS		TRANSIENT	
	RMS VOLTAGE (VOLTS)	DC VOLTAGE (VOLTS)	ENERGY (10/1000ms) (JOULES)	PEAK CURRENT (8/20ms) (AMPS)
DVS 24	30	38	8.8	1000
DVS 48	60	81	20	4500
DVS 110	150	200	80	6500
DVS 240	275	369	140	6500

**SPECIFICATION**

LINE FREQUENCY DC TO 440HZ


TEMPERATURE RANGE -25C TO +85C

WIRE GAUGE 12 AWG


MOUNTING EN 50 022 RAIL (TOP HAT)

SCREW TERMINALS 2.5sq.mm (12 AWG)

**ELECTRICAL CONNECTION**

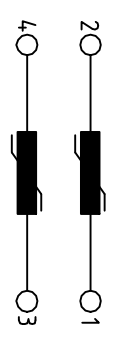

**EXAMPLE**

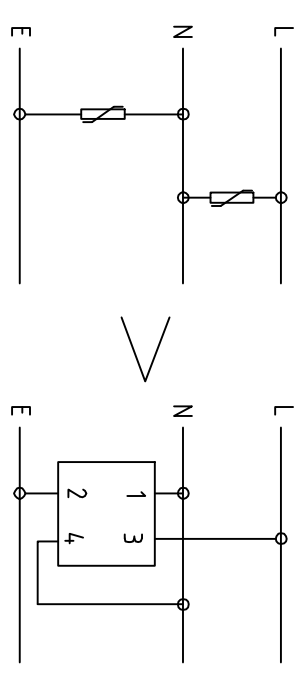

ALL DIMENSIONS IN MM / ANGLES IN DECIMAL DEGREES

DrngNo DVS-GS

TITLE DIMENSIONS FOR DVS24,48,110,240



GENERAL SPECIFICATION FOR DVS

CUSTOMER FILTER REF