


SPECIFICATION

RATED VOLTAGE	440V
CURRENT	8A AT 40 Deg. C
FREQUENCY	50/60Hz
TEMPERATURE RANGE	-25 TO 85 Deg. C
LEAKAGE CURRENT	6.6mA AT 250V 50Hz
TEST VOLTAGE	2kV DC
TERMINATIONS	5 WAY WAGO 236-505
TOTAL POWER DISSIPATION	8.5W

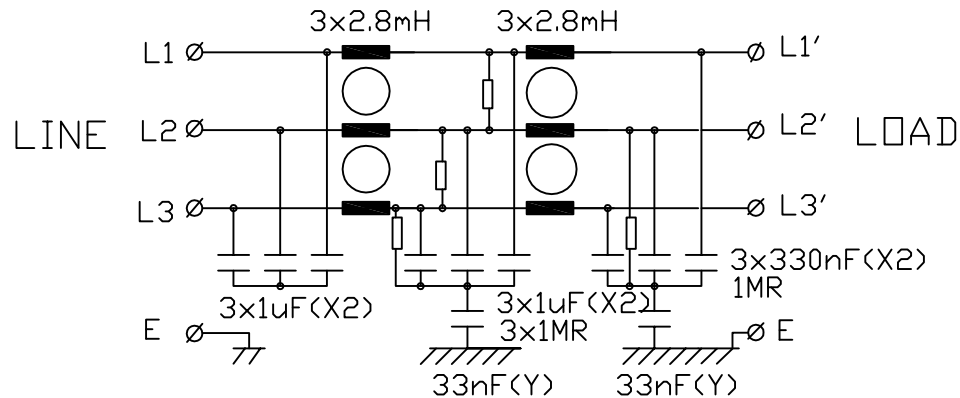

MINIMUM INSERTION LOSS

Frequency Hz	30k	100k	150k	300k	10M
Common Mode dB	20	62	76	>85	>85
Differential dB		30	44	>54	>54

DrgNo MDF308-GS

TITLE THREE PHASE 440V 8A 50/60HZ MAINS FILTER

ALL DIMENSIONS IN MM
ANGLES IN DECIMAL DEGREES

ROXBURGH EMC  ISSUE 3

GENERAL SPECIFICATION
FOR MDF308

CUSTOMER

REFERENCE

Aprvd Date 10/03/03

Aprvd By JRT

Drwn by SW

Scale: NTS

Sheet 1 / 1