

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [50-57-9004](#)
Status: **Active**
Overview: [SL™ Modular Connectors](#)
Description: [SL™ Crimp Housing, Single Row, Version A, Non-polarized, 4 Circuits](#)

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-70058 \(PDF\)](#)
[Product Specification PS-70400 \(PDF\)](#)
[Product Specification PS-71851 \(PDF\)](#)
[Test Summary TS-70058-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series [70066](#)
Application Signal, Wire-to-Board
Comments Version A
Overview [SL™ Modular Connectors](#)
Product Name SL™
UPC 800753578180

Physical

Circuits (maximum) 4
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Keying to Mating Part None
Lock to Mating Part No
Material - Resin Polyester Alloy
Net Weight 0.029/g
Number of Rows 1
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 2.54mm
Stackable Yes
Temperature Range - Operating -40°C to +105°C

Electrical


Current - Maximum per Contact 3A

Material Info

Old Part Number 70066-0003

Reference - Drawing Numbers

Product Specification PS-70058, PS-70400, PS-71851
Sales Drawing SD-70066-0001-0024
Test Summary TS-70058-001

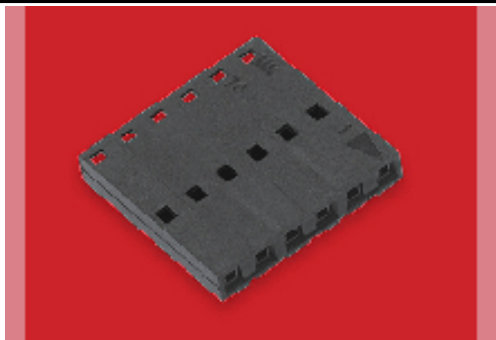

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[70066Series](#)

Mates With
[42375](#) , [42377](#) , [70280](#) , [70287](#) , [71308](#) ,
[70543](#) , [70553](#)

Use With
SL™ Crimp Terminal [70058](#) , [71851](#)