

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19199-0009](#)
Status: **Active**
Overview: [Splices](#)
Description: Butt - Window Splice for 14-16 AWG Wire

Documents:

[Drawing \(PDF\)](#) [Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)

General

Product Family	Splices
Series	19199
Comments	Mil Spec M7928/5-4
Crimp Quality Equipment	Yes
Mil-Spec	M7928/5-4
Overview	Splices
Product Name	Butt - Window
UPC	800753046825

Physical

Barrel Type	Closed
Color - Resin	Blue
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.528/g
Packaging Type	Bag
Temperature Range - Operating	-55°C to +105°C
Wire Insulation Diameter	4.32mm max.
Wire Size AWG	14, 16
Wire Size mm ²	1.30 - 2.00

Electrical


Voltage - Maximum	300V
-------------------	------

Material Info

Old Part Number	WB-841
-----------------	--------

Reference - Drawing Numbers

Product Specification	PS-19902-011, PS-19902-013
Sales Drawing	SD-19199-003

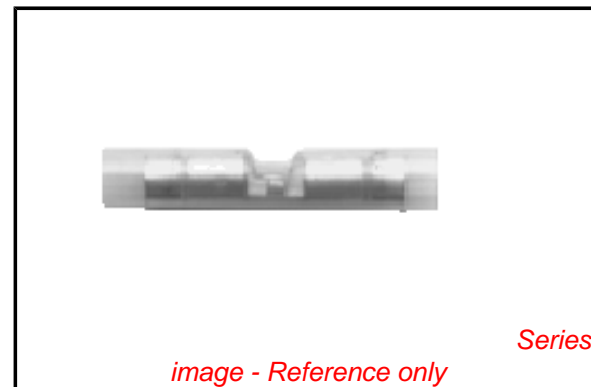

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
 For a multiple part number RoHS Certificate of
 Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
 non-product compliance questions.

Search Parts in this Series

[19199Series](#)