




Equal tee. All ends for copper.

K618



Size	Pattern No.	Pack 1 Qty	Pack 2 Qty	Code	Barcode	Price (£) ex VAT
6mm	K618	5	250	41234K	5022050072313	£18.09
8mm	K618	5	200	41235K	5022050072436	£16.46
10mm	K618	5	100	41236K	5022050072559	£18.32
12mm	K918	5	100	43237K	5022050104991	£18.32
15mm	KS618	5	75	61238K	5022050124500	£5.03
18mm	K918	5	50	43239K	5022050105240	£22.56
22mm	KS618	5	40	61240K	5022050124623	£8.45
28mm	K618	5	25	61241K	5022050124746	£37.40
35mm	K918	1	12	43242K	5022050105578	£72.90
42mm	K918	1	10	43243K	5022050105691	£114.64
54mm	K918	1	5	43244K	5022050105813	£184.17

K618

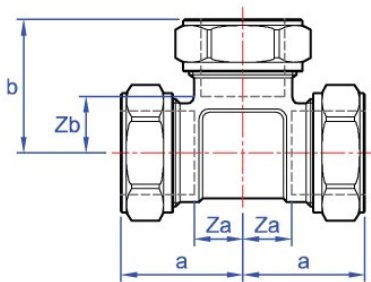

Code	Description	a	b	za	zb
41234K	6mm K618	22	22	9	9
41235K	8mm K618	25	25	11	11
41236K	10mm K618	26	26	10	10
43237K	12mm K918	29	29	14	13
61238K	15mm KS618	32	32	10	11
43239K					
61240K	22mm KS618	37	37	13	15
61241K	28mm K618	41	41	16	15
43242K	35mm K918	50	50	25	25
43243K	42mm K918	55	55	26	26
43244K					

*Pegler Yorkshire reserve the right to change specifications*

**Pegler Yorkshire Kuterlite Guarantee - Terms and Conditions**

Products are subject to a guarantee that is between Pegler Yorkshire and the final purchaser of the product. When correctly assembled with the stated tubes and pipe the length of guarantee is as follows:

*Kuterlite fittings and valves installed with specified tubes and pipes with the exception of those listed below - 25 years.*

*Kuterlite Flexifit flexible connectors - 10 years*

*Kuterlite 600/900 fittings and valves installed with XPress Carbon Steel System tube in sizes up to 28mm - 10 years*

*Kuterlite 600/900 fittings and valves installed with other manufacturers carbon steel tube to DIN 2394/NEN 1982 in sizes up to 28mm - 5 years*

The guarantee is subject to proof of purchase being supplied.

This guarantee does not affect any statutory rights the consumer may have in law.

The guarantee covers manufacturing or material defects when installed in accordance with our instructions on specified tube materials and applications, and does not cover parts subject to normal wear and tear.

This product range has been designed for the use of homeowners, domestic and commercial applications and therefore the Guarantee is subject to the product being properly selected for their intended service conditions.

The guarantee is not applicable where the product is fitted contrary to the conditions in the fitting instructions.

This is reinforced where valves are covered by the European Pressure Equipment Directive (PED97/23/EC) where Installation, Operating and Maintenance Instructions are supplied with each product and/or carton.

Provided it is installed correctly and receives adequate preventative maintenance it should give years of trouble-free service.

Abusive behaviour and accidental damage to the product are not covered by this guarantee.

The extent of this liability is limited to the cost of the replacement of the defective item and not to installation or consequential damages.

Size	-15°C (Min)	30°C	90°C	120°C (Max)
6mm to 10mm	70 bar*	70 bar	40 bar	25 bar
12mm to 28mm	20 bar*	20 bar	10 bar	7 bar
35mm to 54mm	16 bar*	16 bar	7 bar	5 bar

**Care**

No regular aesthetic care is required for this product

**Maintenance**

No regular maintenance is required for this product.

For any further help please contact the Service Support Team on: 0800 1560050.