

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

502351-0400

Status:


Active

Overview:

DuraClik™ Connector System

Description:

DuraClik™ Wire-to-Board Receptacle Housing, Single Row, 4 Circuits

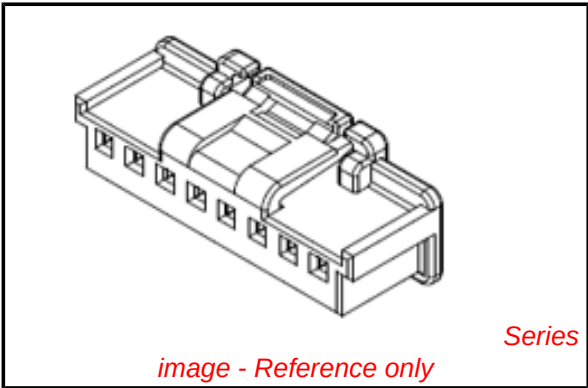

Documents:	
3D Model	Product Specification PS-502351-002 (PDF)
Drawing (PDF)	Packaging Specification PK-502351-001 (PDF)
Product Specification PS-502351-001 (PDF)	RoHS Certificate of Compliance (PDF)
General	
Product Family	Crimp Housings
Series	502351
Application	Signal, Wire-to-Board
Comments	Molex part has an inner-locking system versus an outer-locking system. Molex Part with tail protection feature.
Overview	DuraClik™ Connector System
Product Name	DuraClik™
UPC	800756666853
Physical	
Circuits (maximum)	4
Color - Resin	White
Gender	Receptacle
Glow-Wire Compliant	No
Keying to Mating Part	Yes
Lock to Mating Part	Yes
Net Weight	205.000/mg
Number of Rows	1
Packaging Type	Bag
Panel Mount	No
Pitch - Mating Interface	2.00mm
Polarized to Mating Part	Yes
Temperature Range - Operating	-40°C to +105°C
Electrical	
Current - Maximum per Contact	3A
Material Info	
Reference - Drawing Numbers	
Packaging Specification	PK-502351-001
Product Specification	PS-502351-001, PS-502351-002, RPS-502351-001, RPS-502351-003, RPS-502351-004, RPS-502351-005, RPS-502351-006-JP, RPS-502351-008-JP, RPS-502351-009-JP, RPS-502351-011-JP
Sales Drawing	SD-502351-001

EU RoHS

ELV and RoHS Compliant

REACH SVHC

Contains SVHC: No

Low-Halogen Status

Not Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
502351Series

Mates With
560020 , 502352 2.00mm Pitch DuraClik™ Wire-to-Board Header

Use With
560085 DuraClik™ Crimp Terminal AWG 22-26. 50212 2.00mm Pitch Crimp Terminal AWG 24-30