


# LCR CAPACITORS

LCR  
POLYPROPYLENE  
MOTOR RUN CAPACITOR  
TYPE : MR / P / 250 V

THESE METALLISED POLYPROPYLENE CAPACITORS ARE PARTICULARLY SUITABLE FOR AC VOLTAGES.

THESE CAPACITORS ARE CONSTRUCTED USING METALLISED POLYPROPYLENE FILM, HOUSED IN A PLASTIC CASE FILLED WITH POLYURETHANE RESIN.

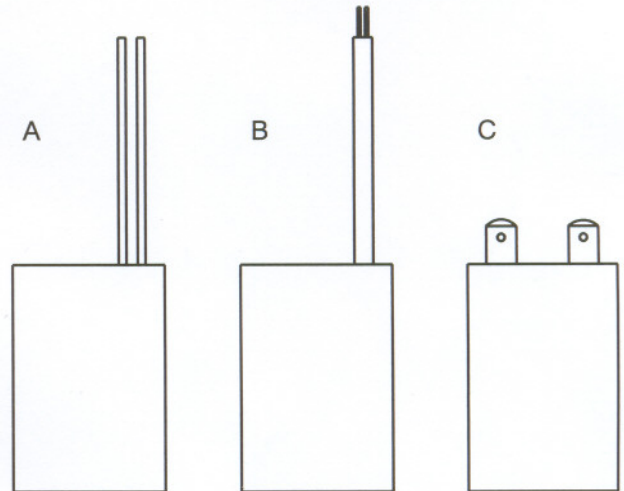

A STUDDED VERSION IS AVAILABLE ON REQUEST

## CHARACTERISTICS

CAPACITANCE	1 UF - 180 UF
CAPACITANCE TOLERANCE	5% OR 10%
RATED VOLTAGE	250V AC 50 / 60 Hz
TEMPERATURE RANGE	- 25°C TO + 85°C
POWER FACTOR	0.001 @ 1 K Hz
INSULATION RESISTANCE	1000 Ohms, farad

### TERMINATIONS

- A TWIN PVC INSULATED FLEXIBLE COPPER CONDUCTORS
- B TWIN MAINS CABLE, SHEATHED
- C DECK. WITH 6.3MM DOUBLE AMP TAG

CASE DIAMETER. 30MM - 50MM M8 X 12 STUD  
CASE DIAMETER. 51MM - 76MM M12 X 16 STUD

CAPACITY ( UF )	DIAMETER & LENGTH(MM)	ORDER CODE
1 - 6	30 X 56	MR/P/250/?UF/?A.B.C
6.1 - 10	30 X 75	MR/P/250/?UF/?A.B.C
10.1 - 16	35 X 75	MR/P/250/?UF/?A.B.C
16.1 - 22	35 X 98	MR/P/250/?UF/?A.B.C
22.1 - 30	40 X 98	MR/P/250/?UF/?A.B.C
30.1 - 40	45 X 98	MR/P/250/?UF/?A.B.C
40.1 - 50	50 X 98	MR/P/250/?UF/?A.B.C
50.1 - 90	63.5 X 98	MR/P/250/?UF/?A.B.C
90.1 - 135	63.5 X 123	MR/P/250/?UF/?A.B.C
135 - 180	76 X 123	MR/P/250/?UF/?A.B.C

## LCR CAPACITORS (EU) LTD

UNIT 18 , RASSAU INDUSTRIAL ESTATE , EBBW VALE , GWENT , NP23 5SD  
TEL. 01495 307070 FAX . 01495 306965