


Capacitor, ceramic, 2.2 uF, +/-10% Tol, 25V, X8L dielectric

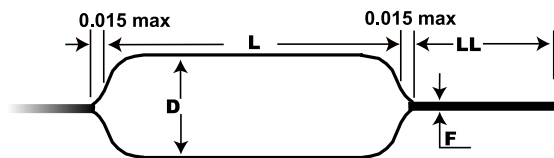

Dimensions (in)		
Symbol	Dimension	Tolerance
D	0.15	MAX
L	0.24	MAX
LL	1	MIN

General Information	
Supplier:	KEMET

Specifications	
Capacitance:	2.2 uF
Temperature Coefficient:	X8L
Temperature Range:	-55°C to 150°C
Application:	Automotive
Voltage:	25V
Tolerance:	+/- 10%
Body Type:	Axial Conformal
Lead Type:	Standard Leads
Termination Type:	Tin (Sn)

Packaging Specifications	
Package Kind:	T&R
Package Type:	Standard
Package Quantity:	2500