


Capacitor, ceramic, 0.047 uF, +/-10% Tol, 100V, Ultra-Stable X8R dielectric

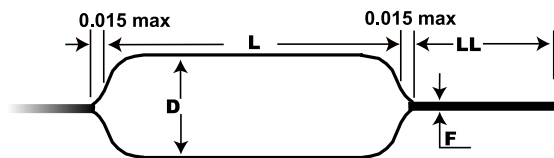

Dimensions (in)		
Symbol	Dimension	Tolerance
D	0.15	MAX
L	0.24	MAX
LL	1	MIN

General Information	
Supplier:	KEMET

Specifications	
Capacitance:	0.047 uF
Temperature Coefficient:	Ultra-Stable X8R
Temperature Range:	-55°C to 150°C
Application:	Automotive
Voltage:	100V
Tolerance:	+/- 10%
Body Type:	Axial Conformal
Lead Type:	Standard Leads
Termination Type:	Tin Sn

Packaging Specifications	
Package Kind:	T&R
Package Type:	Standard
Package Quantity:	2500