

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [02-09-2105](#)
Status: **Active**
Description: Board-In Crimp Terminal, Series 4706, Male, Tin (Sn) Plated Brass Contact, 16-18 AWG, 11.20mm Terminal Progression


Documents:
[Drawing \(PDF\)](#) [RoHS Certificate of Compliance \(PDF\)](#)
[Product Specification PS-4706-001 \(PDF\)](#)

General
Product Family Crimp Terminals
Series [4706](#)
Application Signal
Comments Progression 11.20mm
Crimp Quality Equipment Yes
Product Name Board-In Stand Alone Terminal
UPC 800753615403

Physical
Gender Male
Material - Metal Brass
Material - Plating Mating Tin
Material - Plating Termination Tin
Net Weight 0.085/g
Packaging Type Reel
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 3.05mm max.
Wire Size AWG 16, 18
Wire Size mm² N/A

Material Info
Old Part Number 4706-(P909)

Reference - Drawing Numbers
Product Specification PS-4706-001
Sales Drawing SD-4706

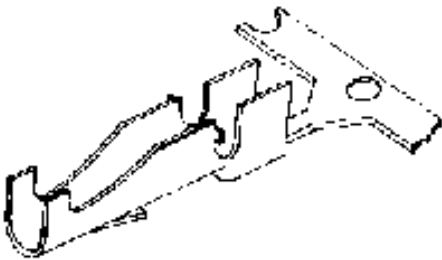

Series
image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Low-Halogen



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
4706Series

Application Tooling | FAQ
Tooling specifications and manuals are found by selecting the products below. Crimp Height Specifications are then contained in the Application Tooling Specification document.

Global	
Description	Product #
Hand Crimp Tool for Board-In Terminal, 16-18 AWG	0011010065
Mini-Mac™ Applicator for Board-In Crimp Terminals	0638934200
Terminator Die	0011402042
Terminator Die - Overlap Insulation Crimp	0011402044

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION