

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [43914-1101](#)
Status: **Active**
Overview: Mini-Fit Sr.™ Power Connectors
Description: 10.00mm Pitch Mini-Fit Sr.™ Receptacle Housing, Dual Row, 6 Circuits

Documents:
[3D Model](#)
[Drawing \(PDF\)](#)
[Product Specification PS-42815-001 \(PDF\)](#)
[Test Summary TS-42815-001 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

CSA LR19980
UL E29179

General

Product Family Crimp Housings
Series [43914](#)
Application Power, Wire-to-Board, Wire-to-Wire
Overview [Mini-Fit Sr.™ Power Connectors](#)
Product Name Mini-Fit Sr.™
UPC 800753933651

Physical

Circuits (maximum) 6
Color - Resin Black
Flammability 94V-0
Gender Female
Glow-Wire Compliant No
Material - Resin Polyester
Net Weight 10.238/g
Number of Rows 2
Packaging Type Bag
Panel Mount No
Pitch - Mating Interface 10.00mm
Stackable No
Temperature Range - Operating -40°C to +105°C


Electrical

Current - Maximum per Contact 50A

Material Info

Reference - Drawing Numbers

Product Specification PS-42815-001, RPS-42815-001, RPS-42815-011,
RPS-42815-012, RPS-42815-013, RPS-42815-014,
RPS-42815-015
Sales Drawing SD-43914-002
Test Summary TS-42815-001

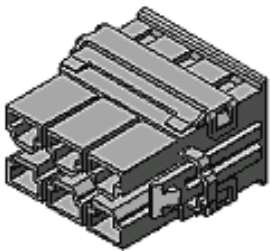

Series

image - Reference only

EU RoHS
ELV and RoHS
Compliant
REACH SVHC
Contains SVHC: No
Low-Halogen Status
Not Low-Halogen

China RoHS



Need more information on product environmental compliance?
Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)
Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series
[43914Series](#)

Mates With
[43915](#) , [43938](#)

Use With
[42815](#) Female Terminal and [43980](#) TPA Clip