

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

39530-0012

Status:

Active

Overview:

Eurostyle™ Terminal Blocks

Description:

5.08mm Pitch Eurostyle™ Horizontal Plug, 12 Circuits

Documents:

3D Model

Drawing (PDF)

Product Specification PS-39500-001 (PDF)

RoHS Certificate of Compliance (PDF)


General	
Product Family	Terminal Blocks
Series	39530
Application	N/A
Component Type	Plug
Overview	Eurostyle™ Terminal Blocks
Product Name	ESE, Eurostyle™Pluggable
Type	Euro Block
UPC	822350531375

Physical	
Circuits (Loaded)	12
Entry Angle	Vertical
Lock to Mating Part	Yes
Number of Rows	1
Orientation	Horizontal
Panel Mount	No
Pitch - Mating Interface	5.08mm
Pitch - Termination Interface	5.08mm
Polarized to Mating Part	Yes
Stackable	No
Temperature Range - Operating	-40°C to +105°C
Wire Size AWG	12, 14, 16, 18, 20, 22, 24, 26
Wire Size mm²	0.13 - 3.31

Electrical	
Current - Maximum per Contact	18A
Voltage - Maximum	300V

Material Info

Reference - Drawing Numbers	
Product Specification	PS-39500-001, RPS-39500-001
Sales Drawing	SD-39530-001

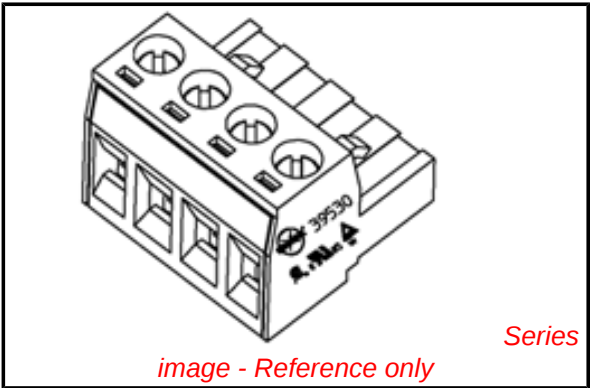

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Low-Halogen

China RoHS



Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

39530Series

Mates With

39531 Vertical PCB Header, 39532 Horizontal PCB Header, 39538 Dual Level PCB Header, Open Ends, Most 5.08mm Pitch Industry Standard PCB Headers

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION