

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

19160-0041

Status:

Active

Overview:

Splices

Description:

Twist Lock Splice for 14-22 AWG Wire

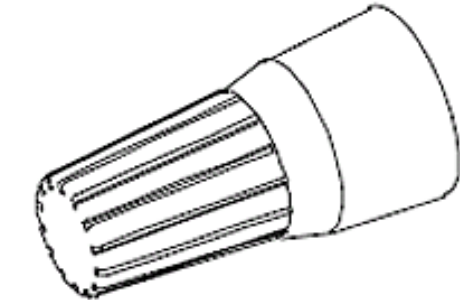


image - Reference only

Series

Documents:

Drawing (PDF)

Product Specification PS-19902-013 (PDF)

RoHS Certificate of Compliance (PDF)

Agency Certification

CSA	LR700095
UL	E32244

General

Product Family	Splices
Series	19160
Crimp Quality Equipment	Yes
Mil-Spec	N/A
MolexKits	Yes
Overview	Splices
Product Name	Closed-End Twist Lock
UPC	800753110458

Physical

Barrel Type	Closed
Color - Resin	Orange
Flammability	94V-2
Insulation	Nylon (PA)
Material - Metal	Copper
Material - Plating Mating	Tin
Material - Plating Termination	Tin
Net Weight	1.341/g
Packaging Type	Bag
Temperature Range - Operating	105°C
Wire Insulation Diameter	9.91mm max.
Wire Size AWG	14, 16, 18, 20, 22
Wire Size mm²	0.35 - 2.00

Electrical

Voltage - Maximum	600V
-------------------	------

Material Info

Old Part Number	TL-O
-----------------	------

Reference - Drawing Numbers

Product Specification	PS-19902-013
Sales Drawing	SD-19160-005

EU RoHS	China RoHS
---------	------------

Compliance Status

Not Reviewed

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

Need more information on product environmental compliance?

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

19160Series