



Cable Cutter, for 2/0 and Smaller Cable

Catalog # 35-052




Features


- Drop-forged high carbon steel construction
- Precision ground, hardened cutting edges provide accurate cuts without cable distortion
- Designed for maximum leverage
- Cuts 2/0 and smaller aluminum and copper cables
- Vinyl coated, comfort-grip handles
- Lifetime guarantee



Cable Cutters

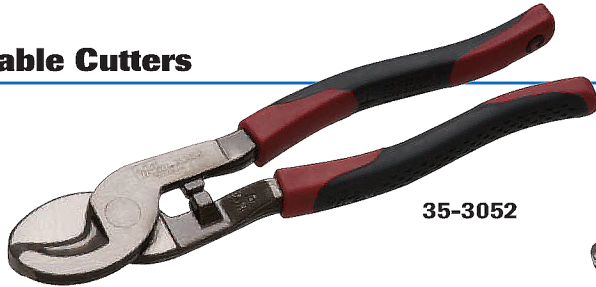

35-3052

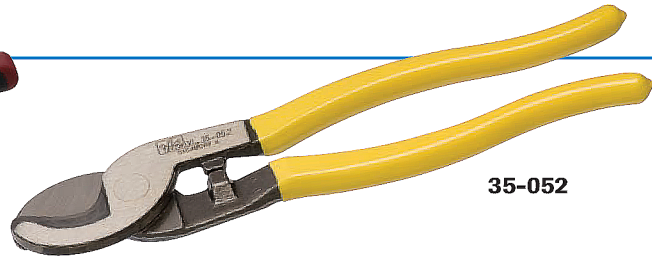

35-052




- Drop-forged, high-carbon steel construction
- Precision-ground, hardened cutting edges provide accurate cuts without cable distortion
- Designed for maximum leverage with minimum effort
- Cuts 2/0 copper and 4/0 aluminum (not for use on ACSR)
- Vinyl-coated, comfort-grip handles

| Description (Smart-Grip™ Handles) | Cat. No. |
|-----------------------------------|----------|
| 9-1/2 in. Cable Cutter | 35-3052 |
| Description (Dipped Handles) | Cat. No. |
| 9-1/2 in. Cable Cutter | 35-052 |

Multi-Crimp Tools



30-3429

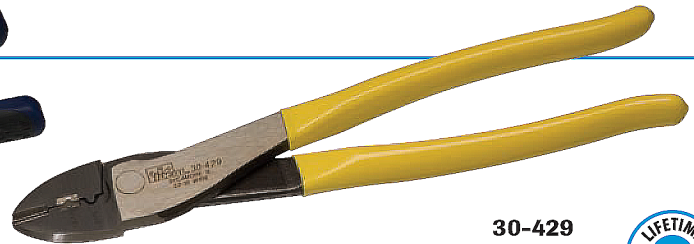

30-429



- Crimps bare or insulated terminals and splices on 10 – 22 AWG wire
- Knife-to-anvil blades never need resharpener
- Excellent leverage for easy crimping and cutting
- Drop-forged, high-carbon steel construction
- Vinyl-coated handles provide a solid, comfortable grip

| Description (Smart-Grip™ Handles) | Cat. No. |
|-----------------------------------|----------|
| 9-3/4 in. Multi-Crimp Tool | 30-3429 |
| Description (Dipped Handles) | Cat. No. |
| 9-3/4 in. Multi-Crimp Tool | 30-429 |

Crimp Tool

- Crimps all IDEAL crimp sleeves
- Excellent leverage for right-angle, double-indent crimps
- Cuts and twists wire
- Vinyl-coated handles provide a solid, comfortable grip

| Description | Cat. No. |
|-------------------------|----------|
| Crimp Tool - 10-1/4 in. | 30-425 |

