

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number: [19067-0104](#)
Status: **Active**
Overview: [Solderless Terminals](#)
Description: NylaKrimp™ Funnel Entry Ring Tongue Terminal for 1/0 AWG Wire, Stud Size 5/16" (M8)

Documents:

[Drawing \(PDF\)](#)
[Product Specification PS-19902-011 \(PDF\)](#)
[Product Specification PS-19902-013 \(PDF\)](#)
[Product Specification PS-19902-016 \(PDF\)](#)
[RoHS Certificate of Compliance \(PDF\)](#)

Agency Certification

UL E32244

General

Product Family Ring and Spade Terminals
Series [19067](#)
Crimp Quality Equipment Yes
Mil-Spec N/A
Overview [Solderless Terminals](#)
Product Name NylaKrimp™
Type Ring
UPC 800753066908

Physical

Barrel Type Closed - Brazed
Flammability 94V-2
Insulation Nylon (PA)
Material - Plating Mating Tin
Net Weight 23.932/g
Packaging Type Bag
Plating min - Mating 2.540µm
Plating min - Termination 2.540µm
Stud Size 5/16" (M8)
Termination Interface: Style Crimp or Compression
Wire Insulation Diameter 17.27mm max.
Wire Size AWG 1

Material Info

Old Part Number H-981-56

Reference - Drawing Numbers

Product Specification PS-19902-011, PS-19902-013, PS-19902-016
Sales Drawing SD-19067-007

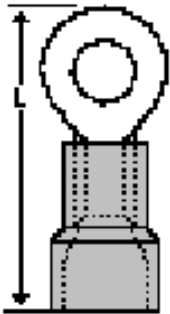


image - Reference only

Series

EU RoHS

**ELV and RoHS
Compliant**

REACH SVHC

**Contains SVHC: No
Low-Halogen Status
Low-Halogen**

China RoHS



**Need more information on product
environmental compliance?**

Email productcompliance@molex.com
For a multiple part number RoHS Certificate of
Compliance, [click here](#)

Please visit the [Contact Us](#) section for any
non-product compliance questions.

Search Parts in this Series

[19067Series](#)

Application Tooling | FAQ

*Tooling specifications and manuals are
found by selecting the products below.
Crimp Height Specifications are then
contained in the Application Tooling
Specification document.*

Global

Description	Product #
Putt Pump Dieless Head System	0192860065
Manual Putt Pump Hydraulic System, Die set required	0192860117
Die Set (large) for the HHLS Hydraulic Crimper	0192890011