

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION

Part Number:

25001-0706

Status:

Active

Overview:

Ribbon Cable Jumpers

Description:


2.54mm Pitch Board-to-Board Ribbon Cable Jumper - 26 AWG, Stranded Topcoat, 7 Circuits, Strip and Retain, 0.152m Length

Documents:

Drawing (PDF)

RoHS Certificate of Compliance (PDF)

General	
Product Family	Cable
Series	25001
Crimp Quality Equipment	Yes
Geographic Area	Asia
Overview	Ribbon Cable Jumpers
Product Name	Ribbon
UPC	800754968744
Physical	
Cable Length	0.152m
Circuits (Loaded)	7
Circuits (maximum)	7
Insulation	PVC
Packaging Type	Bag
Pitch - Termination Interface	2.54mm
Temperature Range - Operating	-20°C to +105°C
Wire Size AWG	26
Wire/Cable Type	(7x34) Stranded, Topcoat
Electrical	
Current - Maximum per Contact	N/A
Voltage - Maximum	300V
Material Info	
Reference - Drawing Numbers	
Sales Drawing	SD-25001-001

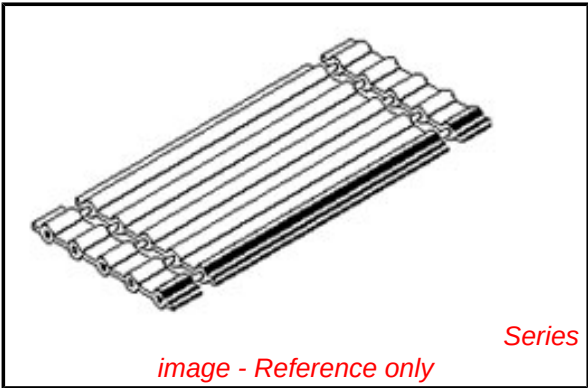

EU RoHS

ELV and RoHS

Compliant

REACH SVHC

Not Reviewed

Low-Halogen Status

Not Reviewed

China RoHS

Need more information on product environmental compliance?

Email productcompliance@molex.com

For a multiple part number RoHS Certificate of Compliance, [click here](#)

Please visit the [Contact Us](#) section for any non-product compliance questions.

Search Parts in this Series

25001Series

This document was generated on 10/09/2014

PLEASE CHECK WWW.MOLEX.COM FOR LATEST PART INFORMATION